

# カバー取手

## COVER PULLS



**A-178**  
亜鉛合金製

### 特徴 Feature

PAT.PEND.

- A-178-0・A-178-1・A-178-2・A-178-3は表と裏両面からねじ止めできます。
- カバーは取付け後にセットして下さい。
- A-178-4・A-178-5・A-178-6・A-178-7は裏側よりねじ止めして下さい。

- Installed with screws both on the front and back of the panel for A-178-0/1/2/3.
- Cover is set up after installation.
- Installed with screws on the back of the panel for A-178-4/5/6/7.

- 仕様 ●材 質：本体／亜鉛合金(ZDC)  
カバー／ABS樹脂(ブラック)
- 表面仕上：本体／クロムめっき(MZCr)
- 用途 ●大型から小型までの冷蔵庫・冷凍冷蔵ショーケース・各種ショーケース
- 納期 ●標準在庫品
- 備考 ●特別な表面処理はご相談下さい。
- 抗菌タイプも製作致します。
- ⚠ 樹脂カバー取付け後は、樹脂カバーを外さないで下さい。再取付けはできません。

- Specifications ●Material: Main body: Zinc alloy (ZDC)  
Cover: ABS resin (black)
- Finish: Main body: Chrome plating (MZCr)
- Specific-use ●Large to small-sized refrigerators, cold storage or other showcases
- ⚠ Do not remove the resin cover once it has been fitted. Once removed, it cannot be replaced.





A-178-1

A-178-3



A-178-5

■裏表、両面から  
ねじ止めできます。  
Can be installed with screws  
in the front or back of the panel.  
A-178-0・A-178-1  
A-178-2・A-178-3

■裏側から  
ねじ止めます。  
Installed with screws  
in the back of the panel.  
A-178-4・A-178-5  
A-178-6・A-178-7

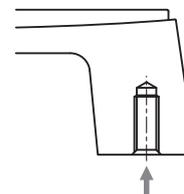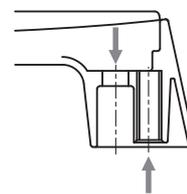

- カバーは取付け後にワンタッチでセット
- Cover is set up by one-touch after installation.

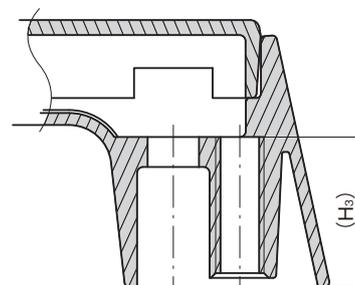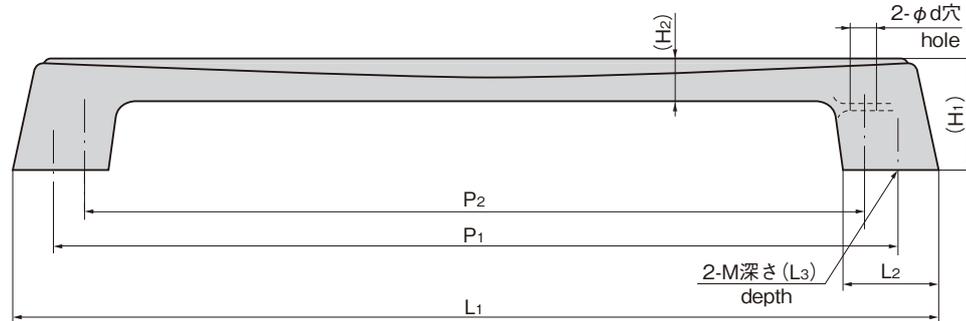

- 木ねじ・タッピンねじに最適
- Optimum to screw nails and tapping screws

商品番号 Product No.	RoHS	CAD	L <sub>1</sub>	L <sub>2</sub>	(L <sub>3</sub> )	W	(H <sub>1</sub> )	(H <sub>2</sub> )	(H <sub>3</sub> )	P <sub>1</sub>	P <sub>2</sub>	φd	M	使用荷重 N Working load	製品質量(g) Mass	コード Code	単価 Price	量販価格 Bulk Price	
																	数量 Quantity	単価 Price	
A-178-0	●	2D/3D	351	36		27.5				321	299		M8		430	00486	¥2,300	5個～	¥2,208
A-178-1	●	2D/3D	318	35	22					288	266	8.5	M8	490	387	00487	¥2,100	10個～	¥2,016
A-178-2	●	2D/3D	268	35		26.5	44.5	17.5	25	238	216		M8		340	00488	¥2,000	12個～	¥1,920
A-178-3	●	2D/3D	218	34						188	166		M8		290	00489	¥1,800	15個～	¥1,728
A-178-4	●	2D/3D	146	23	18	17	36	11		120			M6	392	125	00490	¥1,200	15個～	¥1,152
A-178-5	●	2D/3D	136	23						110			M6		120	00491	¥1,000	15個～	¥960
A-178-6	●	2D/3D	120	20	12	16	30	9		100			M5	294	95	00492	¥850	15個～	¥816
A-178-7	●	2D/3D	90	15		14	27.5			68			M5		55	00493	¥700	15個～	¥672

●: RoHS指令対応品 ▲: RoHS指令に対応可能です。

※大量のご注文は更にお安くなります。

クレモン

ローラー  
締め

特装密閉  
ハンドル

フリーザー  
密閉

平面  
スイング

ギア式

平面  
ハンドル

ポップ  
ハンドル

リフト  
ハンドル

アジャスト  
ハンドル

ラッチ式

スナッチ

リンク

フック式

ロック  
ハンドル

L 型  
ハンドル

T 型  
ハンドル

丸型  
小型

押ボタン

取手

つまみ

止め金  
ロッド棒

ジョイント  
リンク

ワイヤ