



AGE06010B

Lead wire UL1007 AWG26

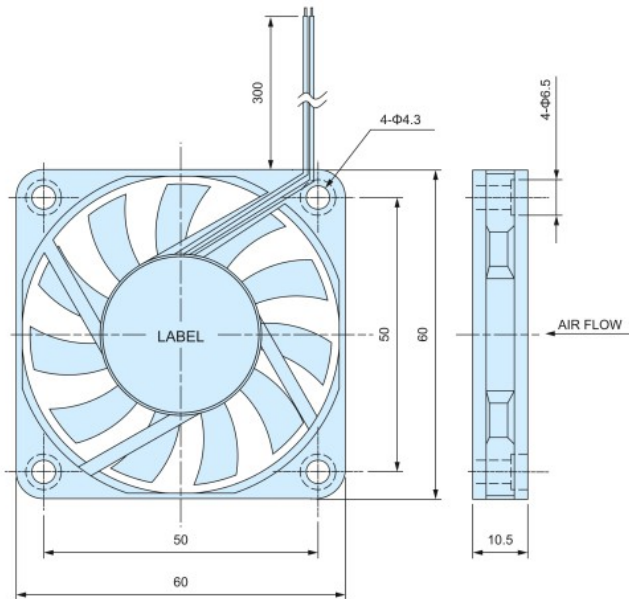

AGE08020B

Lead wire UL1007 AWG28

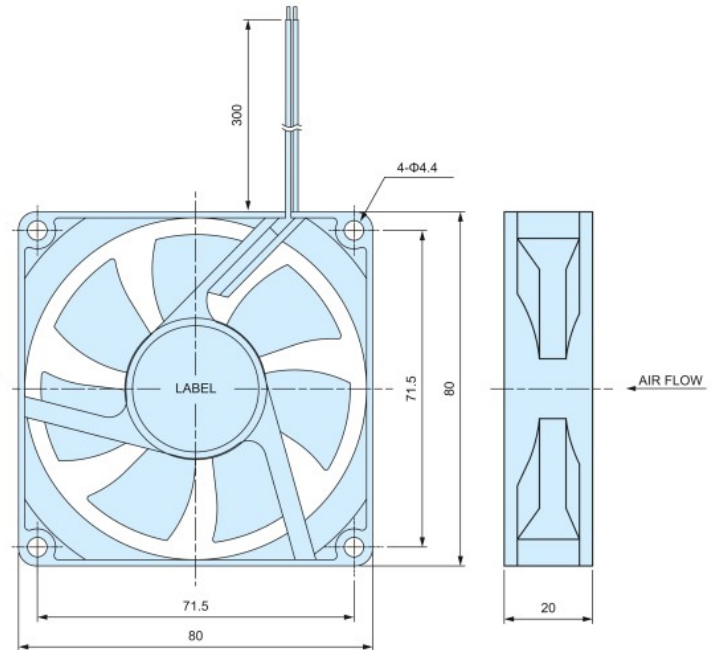

Product no. / Dimensions

Product no.	Outer dimensions (mm)	Rated voltage (V)	Voltage range (V)	Rated current (A)	Rated input (W)	Max airflow (m3/min)	Max static pressure (pa)	Rotation speed (min-1)	Operating temperature	Life expectancy (H)
NEW AGE02510B	25.0 x 25.0 x 10.0	DC 5	4.5 ~ 5.5	0.12	0.6	0.04	18.6	7,000	-10°C ~ +50°C	70,000
NEW AGE03010B	30.0 x 30.0 x 10.5	DC12	7.0 ~ 13.2	0.05	0.6	0.08	22.4	6,000	-10°C ~ +50°C	70,000
NEW AGE04010B	40.0 x 40.0 x 10.0	DC12	7.0 ~ 13.2	0.09	1.08	0.13	13.9	4,000	-10°C ~ +50°C	70,000
NEW AGE05010B	50.0 x 50.0 x 10.0	DC12	7.0 ~ 13.2	0.07	0.84	0.3	34.9	5,500	-10°C ~ +50°C	70,000
NEW AGE06010B	60.0 x 60.0 x 10.5	DC12	7.0 ~ 13.2	0.3	3.6	0.4	20.4	3,500	-10°C ~ +50°C	70,000
NEW AGE08020B	80.0 x 80.0 x 20.0	DC12	7.0 ~ 13.2	0.07	0.84	0.78	22.4	2,400	-10°C ~ +50°C	70,000


■ Life expectancy is measured under normal operational conditions.

HF-G SERIES


FAN GUARD




■ DXF/DWG/PDF drawings available on our website.

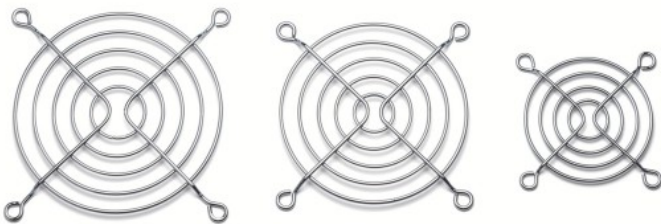

■ Material : Steel wire

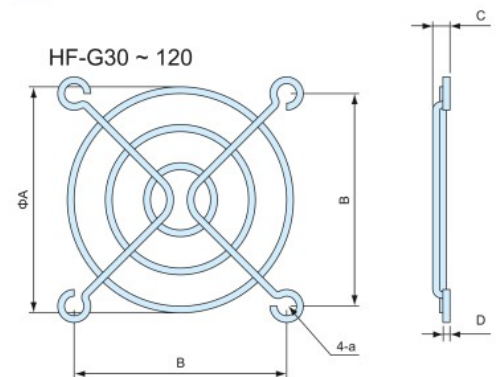

HF-G172

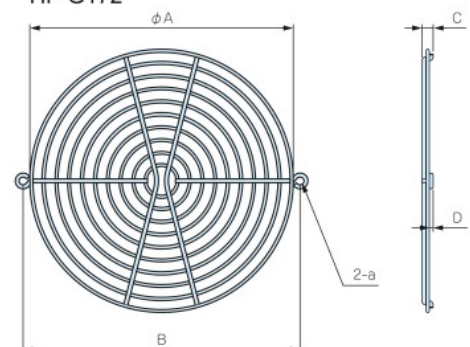

Product no. / Dimensions

■ Shape vary by model.

Product no.	A	B	C	D	a	Surface finish
HF-G 30	26	24	3	1.6	M3	Chorome plated
HF-G 40	29	32	5	1.6	M3 and M4	Nickel chrome plated
HF-G 50	41	40	5	1.6	M3 and M4	Nickel chrome plated
HF-G 60	53	50	4.5	1.6	M4	Nickel chrome plated
HF-G 80	76	71.5	5	1.8	M4	Nickel chrome plated
HF-G 90	90	82.5	5.5	1.8	M4	Nickel chrome plated
HF-G120	115	104.8	3.6	1.8	M4	Nickel chrome plated
NEW HF-G172	154	162	6.5	2.3	M4	Nickel chrome plated