 



Prices displayed include 8% tax.



Stock 38,650 Items

## Surface Plate Stand

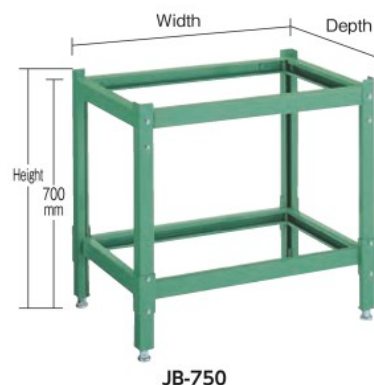

JB-750

- Features**
- A standard angle specification.
  - Table of surface plate for general scribing work.
- Use**
- Base of the surface plate for machine finishing.
- Specs**
- Collapsible type
  - Allowable weight: 300kg
  - Knock-Down
  - Adjuster screw size: M16 x 2.0
- Materials**
- Steel
- Origin**
- Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | W x D x H (mm)  | Load Bearing Surface Plate Dimension (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|-----------------|-------------------------------------------|-------------|-------------|
| ★467-0612  | JB-501   | ¥51,137           | ¥55,240          | 510 x 510 x 725 | 500 x 500                                 | 1           | 13.5        |
| ★467-0621  | JB-600   | ¥57,682           | ¥62,310          | 610 x 460 x 725 | 600 x 450                                 | 1           | 14.5        |
| ★467-0639  | JB-601   | ¥64,551           | ¥69,730          | 610 x 610 x 725 | 600 x 600                                 | 1           | 15.5        |
| ★467-0647  | JB-750   | ¥63,559           | ¥68,660          | 760 x 510 x 725 | 750 x 500                                 | 1           | 15.5        |
| ★467-0655  | JB-900   | ¥69,780           | ¥75,380          | 910 x 610 x 725 | 900 x 600                                 | 1           | 17.0        |
| ★467-0663  | JB-901   | ¥86,156           | ¥93,070          | 910 x 910 x 725 | 900 x 900                                 | 1           | 19.5        |

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

## Surface Plate Stand



JB-1000  
(surface plate is sold separately)

- Features**
- A standard angle specification.
  - Table of surface plate for general scribing work.
- Use**
- Base of the surface plate for machine finishing.
- Specs**
- Finished goods
  - Allowable weight: 800kg
  - Adjuster screw size: M16 x 2.0
- Materials**
- Steel
- Origin**
- Japan

Order Unit: 1 Piece | Factory direct | No freight charge | Excluding remote islands | (Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | W x D x H (mm)    | Load Bearing Surface Plate Dimension (mm) | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|-------------------|-------------------------------------------|-------------|-------------|
| ★467-0582  | JB-1000  | ¥134,535          | ¥145,330         | 1010 x 760 x 700  | 1000 x 750                                | 1           | 42          |
| ★467-0591  | JB-1001  | ¥148,558          | ¥160,480         | 1010 x 1010 x 715 | 1000 x 1000                               | 1           | 61          |
| ★467-0604  | JB-1200  | ¥148,558          | ¥160,480         | 1210 x 910 x 715  | 1200 x 900                                | 1           | 61          |

Contact us: 0120-509-849 <http://www.orange-book.com/>

## Drawings and CAD data can be downloaded.



For products with these labels attached in the Orange Book, their detailed information can be viewed on <http://www.orange-book.com/>.



\*The page is a sample image



Click to download CAD data from the manufacturer's website.

The Orange-Book.Com website and various materials are in Japanese.