



Stock 38,650 Items

Engraving Pen



TR-B

- Features**
- Nylon resin is used for body.
 - **Inscribe letters by vibration.**
- Specs**
- Electricity consumption: 7W
 - Power: AC100V (50/60Hz)
 - Power cord length: 2m
- Accessories**
- Template 1 sheet
 - Core
- Origin**
- Japan

Marking Propriety Table

Item No.	Plastic	Glass	Non-ferrous Metal	Soft Iron Material	Hardened Steel	Stainless Steel	Carbide
TR-B	○	○	○	○	x	○	x

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Core (mm)	Dimension (mm) W x H	Total Length (mm)	SPQ (piece)	Weight (g)
229-6021	TR-B	¥7,415	¥8,010	Φ3.4	47 x 45.5	163.8	10	295

Replacement Core

Materials • Carbide Alloy (equivalent to JIS K20)

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	SPQ (piece)	Weight (g)
449-9671	TRBC-S	¥1,053	¥1,300	10	3

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Electric Pencil

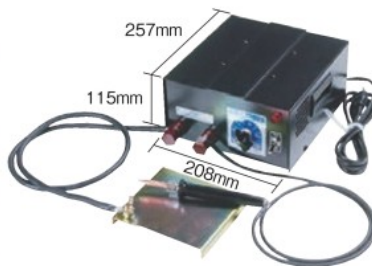

TEP-A

- Features**
- A special copper alloy that is superior in heat resistance, wear resistance and conductivity is used for pen tip.
 - **Can be marked on metal with iron as its principal component.**
- Specs**
- Electricity consumption: 420W
 - Power: AC100V (50/60Hz)
 - Power cord length: 1.6m
- Accessories**
- Pen Tip (TEPC-DP), Polar Plate, 2 Pieces WCT145Q Codes (approx. 1m), 1 piece 85Q Code (approx. 1m)
- Origin**
- Japan

Order Unit: 1 Set

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Rated Voltage (V)	Rated Frequency (Hz)	Rated Ampere (A)	Dimension (mm) W x D x H	SPQ (set)	Weight (kg/set)
328-8447	TEP-A	¥55,080	¥68,000	100	50/60	4.2	208 x 257 x 115	1	9.5

Pen Tip

Item No.	TEPC-DP	TEPC-TP
Materials	Copper Alloy	Tungsten

Order Unit: 1 Piece



TEPC-DP (pen tip/copper alloy) TEP-TP (pen tip/tungsten)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Core (mm)	SPQ (piece)	Weight (g)
449-9689	TEPC-DP	¥1,377	¥1,700	Φ7.0	10	13
449-9697	TEPC-TP	¥2,025	¥2,500	Φ3.0	10	10

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 1,843 Items

Metal Stamp machine (emboss type)



MEHT187

- Features**
- Handy type marking machine which can easily engrave characters and symbols on aluminum or stainless steel tapes.
 - The character size is 4.8mm sq.
- Use**
- Use the stamped tape as a bundle wire with MLT stainless steel band, flag type, or by winding it.
- Accessories**
- Aluminum tape 1 roll, stainless steel tape 1 roll
- Origin**
- USA



Panduit Corp. Japan Branch

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	W x L (mm)	SPQ (piece)	Weight (kg)
438-2587	MEHT187	¥185,143	-	256.5 x 176.5	1	1.02

Tape for Stamp

(Price revision date: Aug. 2015)

Order Unit: 1 Bag



METS3-X (tape for stamp)

Order Code	Item No.	Price (per bag)	MSRP (per bag)	W x L (mm x m)	Materials	Q'ty Per Bag (roll)	SPQ (bag)	Weight (g/bag)
438-2609	METS3-X	¥49,788	-	12.7 x 6.4	316 Stainless Steel	10	4	882
438-2617	METS4-X	¥26,475	-	12.7 x 6.4	304 Stainless Steel	10	4	825
438-2595	META-X	¥15,398	-	12.7 x 4.9	Aluminum	10	4	304

Contact us: 03-6863-6060 <http://www.panduit.co.jp/>