

Single Stamps (numbers)

Stock 823Items

4-1903

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items



Single Marking Stamp Numerical



Features • The engraving is deeper than other companies' product and the beautiful letters are stamped because the shank is also thick and it is a very long-lasting stamp.

Materials • Carbon Steel (S45C) Tip
Quenching

Origin • Japan

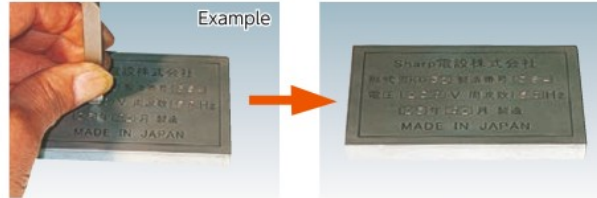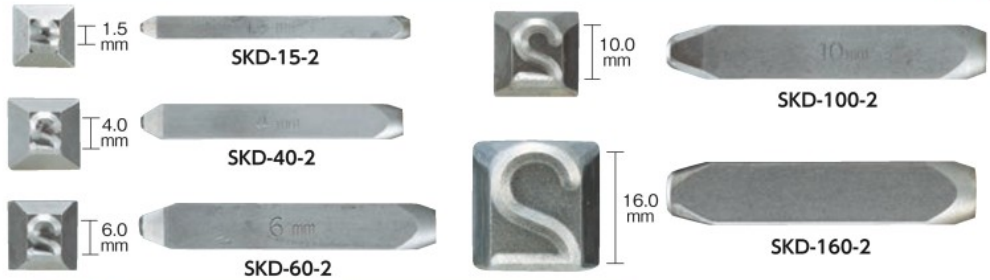

Warning
• Number 6 and 9 are shared. TN is (dot).

("X", "Y", "B" etc. characters with lines at the center of the stamp may be difficult to capture the lines at the center due to the characteristics of the production method.)

Order Unit: 1 Piece (Price revision date: Jan, 2018) TRUSCO NAKAYAMA CORPORATION Order Unit: 1 Piece (Price revision date: Jan, 2018)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Characters	Dimension (mm)	SPQ (piece)	Weight (g)	Order Code	Item No.	Price (per piece)	MSRP (per piece)	Characters	Dimension (mm)	SPQ (piece)	Weight (g)
228-4936	SKD-15-1	¥537	¥580	1	1.5	1	20	228-5681	SKD-50-6	¥620	¥670	6	5.0	1	60
228-4944	SKD-15-2	¥537	¥580	2	1.5	1	20	228-5690	SKD-50-7	¥620	¥670	7	5.0	1	60
228-4952	SKD-15-3	¥537	¥580	3	1.5	1	20	228-5703	SKD-50-8	¥620	¥670	8	5.0	1	60
228-4961	SKD-15-4	¥537	¥580	4	1.5	1	20	228-5711	SKD-50-0	¥620	¥670	0	5.0	1	60
228-4979	SKD-15-5	¥537	¥580	5	1.5	1	20	228-5720	SKD-50-TN	¥620	¥670	-	5.0	1	60
228-4987	SKD-15-6	¥537	¥580	6	1.5	1	20	228-5835	SKD-60-1	¥778	¥840	1	6.0	1	110
228-4995	SKD-15-7	¥537	¥580	7	1.5	1	20	228-5851	SKD-60-2	¥778	¥840	2	6.0	1	110
228-5002	SKD-15-8	¥537	¥580	8	1.5	1	20	228-5860	SKD-60-3	¥778	¥840	3	6.0	1	110
228-5011	SKD-15-0	¥537	¥580	0	1.5	1	20	228-5886	SKD-60-4	¥778	¥840	4	6.0	1	110
228-5029	SKD-15-TN	¥537	¥580	-	1.5	1	20	228-5908	SKD-60-5	¥778	¥840	5	6.0	1	110
228-5134	SKD-20-1	¥537	¥580	1	2.0	1	20	228-5924	SKD-60-6	¥778	¥840	6	6.0	1	110
228-5142	SKD-20-2	¥537	¥580	2	2.0	1	20	228-5941	SKD-60-7	¥778	¥840	7	6.0	1	110
228-5151	SKD-20-3	¥537	¥580	3	2.0	1	20	228-5967	SKD-60-8	¥778	¥840	8	6.0	1	110
228-5169	SKD-20-4	¥537	¥580	4	2.0	1	20	228-5975	SKD-60-0	¥778	¥840	0	6.0	1	110
228-5177	SKD-20-5	¥537	¥580	5	2.0	1	20	228-5991	SKD-60-TN	¥778	¥840	-	6.0	1	110
228-5185	SKD-20-6	¥537	¥580	6	2.0	1	20	228-6106	SKD-80-1	¥1,065	¥1,150	1	8.0	1	110
228-5193	SKD-20-7	¥537	¥580	7	2.0	1	20	228-6114	SKD-80-2	¥1,065	¥1,150	2	8.0	1	110
228-5207	SKD-20-8	¥537	¥580	8	2.0	1	20	228-6122	SKD-80-3	¥1,065	¥1,150	3	8.0	1	110
228-5215	SKD-20-0	¥537	¥580	0	2.0	1	20	228-6131	SKD-80-4	¥1,065	¥1,150	4	8.0	1	110
228-5223	SKD-20-TN	¥537	¥580	-	2.0	1	20	228-6149	SKD-80-5	¥1,065	¥1,150	5	8.0	1	110
228-5339	SKD-25-1	¥537	¥580	1	2.5	1	20	228-6157	SKD-80-6	¥1,065	¥1,150	6	8.0	1	110
228-5347	SKD-25-2	¥537	¥580	2	2.5	1	20	228-6165	SKD-80-7	¥1,065	¥1,150	7	8.0	1	110
228-5355	SKD-25-3	¥537	¥580	3	2.5	1	20	228-6173	SKD-80-8	¥1,065	¥1,150	8	8.0	1	110
228-5363	SKD-25-4	¥537	¥580	4	2.5	1	20	228-6181	SKD-80-0	¥1,065	¥1,150	0	8.0	1	110
228-5371	SKD-25-5	¥537	¥580	5	2.5	1	20	228-6190	SKD-80-TN	¥1,065	¥1,150	-	8.0	1	110
228-5380	SKD-25-6	¥537	¥580	6	2.5	1	20	228-6203	SKD-100-1	¥1,472	¥1,590	1	10.0	1	180
228-5398	SKD-25-7	¥537	¥580	7	2.5	1	20	228-6211	SKD-100-2	¥1,472	¥1,590	2	10.0	1	180
228-5401	SKD-25-8	¥537	¥580	8	2.5	1	20	228-6220	SKD-100-3	¥1,472	¥1,590	3	10.0	1	180
228-5410	SKD-25-0	¥537	¥580	0	2.5	1	20	228-6238	SKD-100-4	¥1,472	¥1,590	4	10.0	1	180
228-5428	SKD-25-TN	¥537	¥580	-	2.5	1	20	228-6246	SKD-100-5	¥1,472	¥1,590	5	10.0	1	180
228-5436	SKD-30-1	¥573	¥620	1	3.0	1	40	228-6254	SKD-100-6	¥1,472	¥1,590	6	10.0	1	180
228-5444	SKD-30-2	¥573	¥620	2	3.0	1	40	228-6262	SKD-100-7	¥1,472	¥1,590	7	10.0	1	180
228-5452	SKD-30-3	¥573	¥620	3	3.0	1	40	228-6271	SKD-100-8	¥1,472	¥1,590	8	10.0	1	180
228-5461	SKD-30-4	¥573	¥620	4	3.0	1	40	228-6289	SKD-100-0	¥1,472	¥1,590	0	10.0	1	180
228-5479	SKD-30-5	¥573	¥620	5	3.0	1	40	228-6297	SKD-100-TN	¥1,472	¥1,590	-	10.0	1	180
228-5487	SKD-30-6	¥573	¥620	6	3.0	1	40	228-6572	SKD-130-1	¥1,740	¥1,880	1	13.0	1	180
228-5495	SKD-30-7	¥573	¥620	7	3.0	1	40	228-6581	SKD-130-2	¥1,740	¥1,880	2	13.0	1	180
228-5509	SKD-30-8	¥573	¥620	8	3.0	1	40	228-6599	SKD-130-3	¥1,740	¥1,880	3	13.0	1	180
228-5517	SKD-30-0	¥573	¥620	0	3.0	1	40	228-6602	SKD-130-4	¥1,740	¥1,880	4	13.0	1	180
228-5525	SKD-30-TN	¥573	¥620	-	3.0	1	40	228-6611	SKD-130-5	¥1,740	¥1,880	5	13.0	1	180
228-5533	SKD-40-1	¥602	¥650	1	4.0	1	60	228-6629	SKD-130-6	¥1,740	¥1,880	6	13.0	1	180
228-5541	SKD-40-2	¥602	¥650	2	4.0	1	60	228-6637	SKD-130-7	¥1,740	¥1,880	7	13.0	1	180
228-5550	SKD-40-3	¥602	¥650	3	4.0	1	60	228-6645	SKD-130-8	¥1,740	¥1,880	8	13.0	1	180
228-5568	SKD-40-4	¥602	¥650	4	4.0	1	60	228-6653	SKD-130-0	¥1,740	¥1,880	0	13.0	1	180
228-5576	SKD-40-5	¥602	¥650	5	4.0	1	60	228-6661	SKD-130-TN	¥1,740	¥1,880	-	13.0	1	180
228-5584	SKD-40-6	¥602	¥650	6	4.0	1	60	228-6670	SKD-160-1	¥3,786	¥4,090	1	16.0	1	250
228-5592	SKD-40-7	¥602	¥650	7	4.0	1	60	228-6688	SKD-160-2	¥3,786	¥4,090	2	16.0	1	250
228-5606	SKD-40-8	¥602	¥650	8	4.0	1	60	228-6696	SKD-160-3	¥3,786	¥4,090	3	16.0	1	250
228-5614	SKD-40-0	¥602	¥650	0	4.0	1	60	228-6700	SKD-160-4	¥3,786	¥4,090	4	16.0	1	250
228-5622	SKD-40-TN	¥602	¥650	-	4.0	1	60	228-6718	SKD-160-5	¥3,786	¥4,090	5	16.0	1	250
228-5631	SKD-50-1	¥620	¥670	1	5.0	1	60	228-6726	SKD-160-6	¥3,786	¥4,090	6	16.0	1	250
228-5649	SKD-50-2	¥620	¥670	2	5.0	1	60	228-6734	SKD-160-7	¥3,786	¥4,090	7	16.0	1	250
228-5657	SKD-50-3	¥620	¥670	3	5.0	1	60	228-6742	SKD-160-8	¥3,786	¥4,090	8	16.0	1	250
228-5665	SKD-50-4	¥620	¥670	4	5.0	1	60	228-6751	SKD-160-0	¥3,786	¥4,090	0	16.0	1	250
228-5673	SKD-50-5	¥620	¥670	5	5.0	1	60	228-6769	SKD-160-TN	¥3,786	¥4,090	-	16.0	1	250

Contact us: 0120-509-849 <http://www.orange-book.com/>

Hammers • Punches

Single-Ended Hammers

Double-Ended Hammers

Combination Hammers

Shock-Less Hammers

Resin Hammers • Rubber Hammers

Nonferrous Hammers

Stainless Steel Hammers

Wood Hammers

Stone Hammers

Welding Hammers

Sheet Metal Hammers

Claw Hammers

Centering Hammers

Hammers for Woodwork

Hammers for Electric Work

Test Hammers

Wedges

Grip Tapes

Bars

Chisels

Stamps

Date Marks

Industrial Stamps

Punches