

Prices displayed include 8% tax.

TRUSCO **Stock 38,650 Items**


Toggle Latch (latch type, steel) RoHS



- Specs**
- Main Body Mounting Hole/Receiving Hole Dimension: 3.0mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Trivalent Chrome-plated Finishing
- Origin**
- Japan



P-36

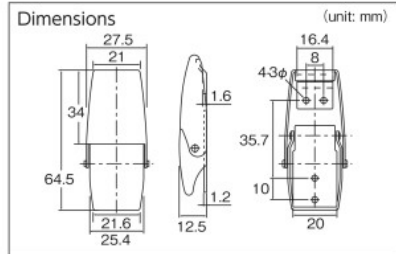

TRUSCO **Stock 38,650 Items**


Toggle Latch (latch type, steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 3.2mm
 - Receiving Hole Dimension: 3.0mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Trivalent Chrome-plated Finishing
- Origin**
- Japan



P-239

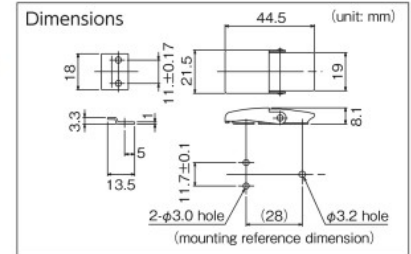

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8321	P-36	¥1,602	¥1,730	2	10	90

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
778-7162	P-239	¥741	¥800	2	10	41

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**


Draw Latch (latch, spring type, stainless steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 3.5mm
 - Receiving Hole Dimension: 3.8mm
- Materials**
- Stainless Steel (SUS304)
- Origin**
- Japan



P-406SUS

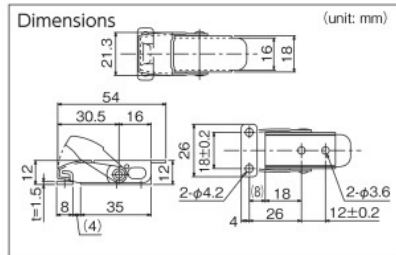

TRUSCO **Stock 38,650 Items**


Draw Latch (locking type, stainless steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 3.5mm
 - Receiving Hole Dimension: 5.2mm
- Materials**
- Stainless Steel (SUS304)
 - Surface Treatment: Bright Finishing
- Origin**
- Japan



P-90SUS

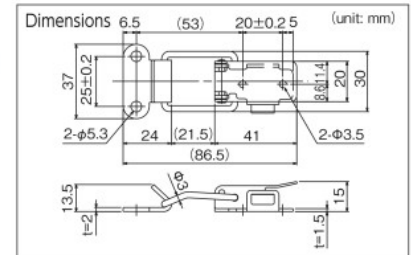

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
778-7197	P-406SUS	¥2,777	¥3,000	2	10	77

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
384-0034	P-90SUS	¥2,610	¥2,820	2	10	71

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Rotating Fastener (steel) RoHS



- Specs**
- Body Mounting Hole/Receiving Hole Dimension: 4.2mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Trivalent Chrome-plated Finishing
- Origin**
- Japan



P-100H





P-110H

Item No.	Key Hole Diameter (mm)
P-100H	8.0
P-110H	7.0

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	SPQ (piece)	Weight (g)
778-7120	P-100H	¥2,092	¥2,260	10	100
778-7154	P-110H	¥1,592	¥1,720	10	53

Contact us: 0120-509-849 <http://www.orange-book.com/>

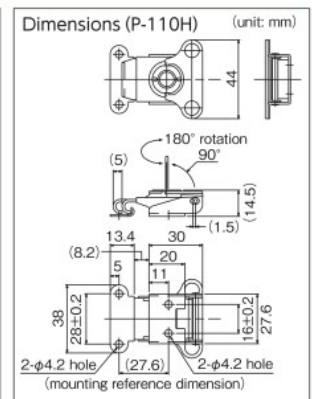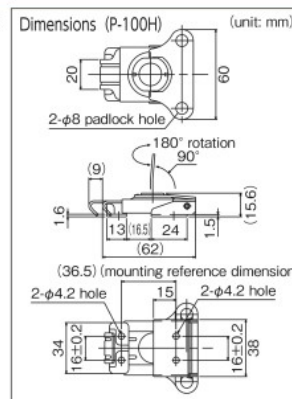

TRUSCO NAKAYAMA CORPORATION