

Pan Head Machine Screws

Stock
792Items

2-445

Prices displayed include 8% tax.



Stock
38,650
Items

Pan Head Machine Screw (full thread type)



B01 Type
(steel)




B05 Type
(stainless steel)

Features • A common machine screw with cross recess.
Origin • -



Dimensions

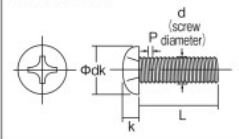

Basic Dimension

Nominal Designation of Thread (d)	Thread Pitch P	Cross Recess Number	Head Outer Diameter (unit: mm)	
			dk	k
M2	0.40	1	3.5	1.3
M2.6	0.45	1	4.5	1.7
M3	0.50	2	5.5	2.0
M4	0.70	2	7.0	2.6
M5	0.80	2	9.0	3.3
M6	1.00	3	10.5	3.9
M8	1.25	3	14.0	5.2

Compatible Screwdriver	
M2/M2.6	Plus No. 1
M3 to M5	Plus No. 2
M6/M8	Plus No. 3

Steel Specs • Tensile Strength Rank: 4.8 (min tensile strength/proof stress) Materials • Low Carbon Steel (SWCH) • Surface Treatment: Unichrome Plated Finishing

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
212-5251	B01-0303	¥602	¥650	M3 x 3	310	10	124.0
212-5269	B01-0304	¥602	¥650	M3 x 4	400	10	168.0
158-9938	B01-0305	¥602	¥650	M3 x 5	400	10	183.6
158-9946	B01-0306	¥602	¥650	M3 x 6	400	10	200.8
158-9954	B01-0308	¥602	¥650	M3 x 8	360	10	211.3
158-9962	B01-0310	¥602	¥650	M3 x 10	360	10	241.9
158-9971	B01-0312	¥602	¥650	M3 x 12	300	10	227.4
158-9989	B01-0315	¥602	¥650	M3 x 15	300	10	267.0
159-0006	B01-0320	¥602	¥650	M3 x 20	240	10	263.2
159-0014	B01-0325	¥602	¥650	M3 x 25	220	10	288.2
159-0022	B01-0330	¥602	¥650	M3 x 30	180	10	274.1
159-0031	B01-0335	¥602	¥650	M3 x 35	130	10	225.5
159-0049	B01-0340	¥602	¥650	M3 x 40	115	10	224.0
212-5315	B01-0350	¥602	¥650	M3 x 50	90	10	207.0
159-0057	B01-0405	¥602	¥650	M4 x 5	270	10	243.0
159-0065	B01-0406	¥602	¥650	M4 x 6	270	10	268.3
159-0073	B01-0408	¥602	¥650	M4 x 8	270	10	308.8
159-0081	B01-0410	¥602	¥650	M4 x 10	250	10	323.7
159-0090	B01-0412	¥602	¥650	M4 x 12	250	10	361.2
159-0103	B01-0415	¥602	¥650	M4 x 15	200	10	320.0
159-0111	B01-0416	¥602	¥650	M4 x 16	190	10	331.5
159-0138	B01-0420	¥602	¥650	M4 x 20	170	10	347.6
159-0146	B01-0425	¥602	¥650	M4 x 25	140	10	338.8
159-0154	B01-0430	¥602	¥650	M4 x 30	120	10	335.5
159-0162	B01-0435	¥602	¥650	M4 x 35	105	10	332.9
159-0171	B01-0440	¥602	¥650	M4 x 40	90	10	319.1
159-0189	B01-0445	¥602	¥650	M4 x 45	85	10	333.2
159-0197	B01-0450	¥602	¥650	M4 x 50	70	10	300.7
159-0219	B01-0460	¥602	¥650	M4 x 60	50	10	245.0
159-0235	B01-0470	¥602	¥650	M4 x 70	35	10	196.0

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-0243	B01-0475	¥602	¥650	M4 x 75	30	10	180.0
212-5358	B01-0505	¥602	¥650	M5 x 5	140	10	238.0
159-0251	B01-0506	¥602	¥650	M5 x 6	150	10	270.0
159-0260	B01-0508	¥602	¥650	M5 x 8	160	10	337.9
159-0278	B01-0510	¥602	¥650	M5 x 10	160	10	376.4
159-0286	B01-0512	¥602	¥650	M5 x 12	150	10	389.1
159-0294	B01-0515	¥602	¥650	M5 x 15	130	10	364.0
159-0316	B01-0520	¥602	¥650	M5 x 20	120	10	426.9
159-0324	B01-0525	¥602	¥650	M5 x 25	100	10	416.0
159-0332	B01-0530	¥602	¥650	M5 x 30	80	10	380.9
159-0341	B01-0535	¥602	¥650	M5 x 35	70	10	375.4
159-0359	B01-0540	¥602	¥650	M5 x 40	65	10	387.8
159-0367	B01-0545	¥602	¥650	M5 x 45	60	10	394.1
159-0375	B01-0550	¥602	¥650	M5 x 50	55	10	394.4
159-0430	B01-0610	¥602	¥650	M6 x 10	100	10	392.6
159-0448	B01-0612	¥602	¥650	M6 x 12	100	10	427.0
159-0456	B01-0615	¥602	¥650	M6 x 15	90	10	429.0
159-0472	B01-0620	¥602	¥650	M6 x 20	80	10	451.5
159-0481	B01-0625	¥602	¥650	M6 x 25	65	10	422.7
159-0499	B01-0630	¥602	¥650	M6 x 30	60	10	441.7
159-0502	B01-0635	¥602	¥650	M6 x 35	55	10	452.2
159-0511	B01-0640	¥602	¥650	M6 x 40	50	10	454.0
159-0537	B01-0650	¥602	¥650	M6 x 50	40	10	432.0
159-0553	B01-0660	¥602	¥650	M6 x 60	25	10	315.5
159-0588	B01-0675	¥602	¥650	M6 x 75	18	10	256.0
159-0596	B01-0812	¥602	¥650	M8 x 12	40	10	372.4
159-0600	B01-0815	¥602	¥650	M8 x 15	35	10	312.0
159-0626	B01-0820	¥602	¥650	M8 x 20	33	10	389.7
159-0634	B01-0825	¥602	¥650	M8 x 25	33	10	441.2
159-0642	B01-0830	¥602	¥650	M8 x 30	30	10	447.9

Stainless Steel Specs • Tensile Strength Rank: Equivalent to A2-50

Materials • Stainless Steel (SUS304 equivalent material)

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
212-5404	B05-0203	¥879	¥950	M2 x 3	150	10	18.0
212-5412	B05-0204	¥879	¥950	M2 x 4	160	10	23.0
212-5421	B05-0205	¥879	¥950	M2 x 5	160	10	25.9
212-5439	B05-0206	¥879	¥950	M2 x 6	160	10	28.6
212-5447	B05-0208	¥879	¥950	M2 x 8	160	10	34.4
212-5455	B05-0210	¥879	¥950	M2 x 10	150	10	37.5
212-5463	B05-0212	¥879	¥950	M2 x 12	140	10	40.0
212-5480	B05-0215	¥879	¥950	M2 x 15	130	10	44.2
212-5510	B05-0220	¥879	¥950	M2 x 20	110	10	47.0
212-5528	B05-0225	¥879	¥950	M2 x 25	100	10	51.7
212-5536	B05-2604	¥879	¥950	M2.6 x 4	170	10	44.2
212-5544	B05-2605	¥879	¥950	M2.6 x 5	170	10	47.6
212-5552	B05-2606	¥879	¥950	M2.6 x 6	170	10	56.1
212-5561	B05-2608	¥879	¥950	M2.6 x 8	160	10	62.4
212-5579	B05-2610	¥879	¥950	M2.6 x 10	150	10	67.5
212-5609	B05-2615	¥879	¥950	M2.6 x 15	120	10	69.6
212-5650	B05-0304	¥879	¥950	M3 x 4	210	10	84.0
159-0740	B05-0305	¥879	¥950	M3 x 5	230	10	105.5
159-0758	B05-0306	¥879	¥950	M3 x 6	220	10	110.4
159-0766	B05-0308	¥879	¥950	M3 x 8	220	10	129.1
159-0774	B05-0310	¥879	¥950	M3 x 10	190	10	127.6
159-0782	B05-0312	¥879	¥950	M3 x 12	170	10	128.8
159-0791	B05-0315	¥879	¥950	M3 x 15	150	10	135.0
159-0812	B05-0320	¥879	¥950	M3 x 20	125	10	137.1
159-0821	B05-0325	¥879	¥950	M3 x 25	105	10	137.5
159-0839	B05-0330	¥879	¥950	M3 x 30	90	10	137.0
159-0847	B05-0335	¥879	¥950	M3 x 35	60	10	104.1
159-0855	B05-0340	¥879	¥950	M3 x 40	55	10	107.1
212-5692	B05-0350	¥879	¥950	M3 x 50	45	10	108.0
212-5706	B05-0405	¥879	¥950	M4 x 5	165	10	148.5
159-0863	B05-0406	¥879	¥950	M4 x 6	150	10	149.1
159-0871	B05-0408	¥879	¥950	M4 x 8	135	10	154.4
159-0880	B05-0410	¥879	¥950	M4 x 10	130	10	168.3
159-0898	B05-0412	¥879	¥950	M4 x 12	120	10	173.4
159-0901	B05-0415	¥879	¥950	M4 x 15	105	10	178.5
159-0910	B05-0416	¥879	¥950	M4 x 16	100	10	174.5

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Qty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-0928	B05-0420	¥879	¥950	M4 x 20	90	10	184.0
159-0936	B05-0425	¥879	¥950	M4 x 25	75	10	181.5
159-0944	B05-0430	¥879	¥950	M4 x 30	65	10	181.7
159-0952	B05-0435	¥879	¥950	M4 x 35	55	10	174.4
159-0961	B05-0440	¥879	¥950	M4 x 40	50	10	177.3
159-0979	B05-0445	¥879	¥950	M4 x 45	40	10	156.8
159-0987	B05-0450	¥879	¥950	M4 x 50	35	10	150.4
159-0995	B05-0506	¥879	¥950	M5 x 6	75	10	142.5
159-1002	B05-0508	¥879	¥950	M5 x 8	72	10	152.0
159-1011	B05-0510	¥879	¥950	M5 x 10	70	10	164.7
159-1029	B05-0512	¥879	¥950	M5 x 12	65	10	168.6
159-1037	B05-0515	¥879	¥950	M5 x 15	55	10	165.0
159-1045	B05-0516	¥879	¥950	M5 x 16	55	10	169.1
159-1053	B05-0520	¥879	¥950	M5 x 20	50	10	177.9
159-1061	B05-0525	¥879	¥950	M5 x 25	45	10	187.2
159-1070	B05-0530	¥879	¥950	M5 x 30	35	10	166.6
159-1088	B05-0535	¥879	¥950	M5 x 35	32	10	171.6
159-1096	B05-0540	¥879	¥950	M5 x 40	27	10	161.1
159-1100	B05-0545	¥879	¥950	M5 x 45	23	10	151.0
159-1118	B05-0550	¥879	¥950	M5 x 50	22	10	157.7
212-7008	B05-0608	¥879	¥950	M6 x 8	45	10	161.1
159-1126	B05-0610	¥879	¥950	M6 x 10	40	10	157.0
159-1134	B05-0612	¥879	¥950	M6 x 12	40	10	170.8
159-1142	B05-0615	¥879	¥950	M6 x 15	33	10	141.9
159-1169	B05-0620	¥879	¥950	M6 x 20	27	10	152.3
159-1177	B05-0625	¥879	¥950	M6 x 25	25	10	162.5
159-1185	B05-0630	¥879	¥950	M6 x 30	22	10	161.9
159-1193	B05-0635	¥879	¥950	M6 x 35	21	10	172.6
159-1207	B05-0640	¥879	¥950	M6 x 40	18	10	163.4
159-1223	B05-0650	¥879	¥950	M6 x 50	15	10	162.0
159-1231	B05-0815	¥879	¥950	M8 x 15	19	10	171.0
159-1258	B05-0820	¥879	¥950	M8 x 20	17	10	200.7
159-1266	B05-0825	¥879	¥950	M8 x 25	15	10	200.5
159-1274	B05-0830	¥879	¥950	M8 x 30	13	10	233.0
159-1291	B05-0840	¥879	¥950	M8 x 40	11	10	198.5