

Pan Head Washer Built-in Screws

The number next to the logo mark indicates items in stock for each brand.

Screws • Bolts • Nuts

Hexagon Bolts

Hexagon Socket Head Cap Screws

Hexagon Socket Set Screws

Wing Bolts

Decoration Screws, Nuts

Nuts

Caps for Screw

Washers

Small Screws

Mischiefous Prevention Screws

Drill Screws

Tapping Screws

Wood Screws

Nails




Stock 38,650 Items

Pan Head Screw with Captive Washer (steel, with round washer)



B50 Type

- Features** • Saves you the trouble of setting washers and spring washers.
Specs • Tensile Strength Rank: 4.8
 • With spring washer, round washer (P-3 type)
Materials • Low Carbon Steel (SWCH)
 • **Surface Treatment: Hexavalent Chromate Finishing**
Origin • Japan

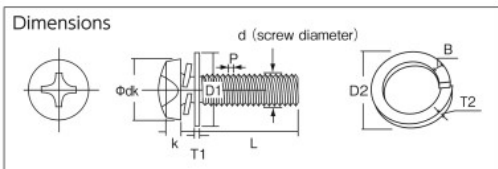

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-4214	B50-0306	¥602	¥650	M3 x 6	180	10	90.3
159-4222	B50-0308	¥602	¥650	M3 x 8	175	10	102.7
159-4231	B50-0310	¥602	¥650	M3 x 10	165	10	110.8
159-4249	B50-0312	¥602	¥650	M3 x 12	160	10	121.2
159-4257	B50-0315	¥602	¥650	M3 x 15	150	10	132.0
159-4273	B50-0320	¥602	¥650	M3 x 20	130	10	142.6
159-4303	B50-0406	¥602	¥650	M4 x 6	100	10	99.4
159-4311	B50-0408	¥602	¥650	M4 x 8	135	10	154.4
159-4320	B50-0410	¥602	¥650	M4 x 10	130	10	168.3
159-4338	B50-0412	¥602	¥650	M4 x 12	130	10	187.8
159-4346	B50-0415	¥602	¥650	M4 x 15	120	10	200.4
159-4362	B50-0420	¥602	¥650	M4 x 20	110	10	224.9
159-4371	B50-0425	¥602	¥650	M4 x 25	95	10	229.9

Basic Dimension (unit: mm)

Nominal Designation of Thread (d)	Thread Pitch (P)	Pan Head		Plain Washer		Spring Lock Washer (no. 2)	
		dk	k	D1	T1	D2	B x T2
M3	0.5	5.5	2.0	8.0	0.5	5.5	1.1 x 0.7
M4	0.7	7.0	2.6	10.0	0.8	7.0	1.4 x 1.0
M5	0.8	9.0	3.3	12.0	0.8	8.5	1.7 x 1.3
M6	1.0	10.5	3.9	13.0	1.0	11.5	2.7 x 1.5

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-4389	B50-0430	¥602	¥650	M4 x 30	90	10	251.6
159-4401	B50-0440	¥602	¥650	M4 x 40	60	10	212.7
159-4419	B50-0508	¥602	¥650	M5 x 8	85	10	179.5
159-4427	B50-0510	¥602	¥650	M5 x 10	85	10	200.0
159-4435	B50-0512	¥602	¥650	M5 x 12	85	10	220.4
159-4443	B50-0515	¥602	¥650	M5 x 15	75	10	221.2
159-4460	B50-0520	¥602	¥650	M5 x 20	67	10	238.3
159-4478	B50-0525	¥602	¥650	M5 x 25	65	10	270.4
159-4486	B50-0530	¥602	¥650	M5 x 30	60	10	285.7
159-4516	B50-0610	¥602	¥650	M6 x 10	55	10	215.9
159-4524	B50-0612	¥602	¥650	M6 x 12	55	10	234.8
159-4532	B50-0615	¥602	¥650	M6 x 15	50	10	239.0
159-4559	B50-0620	¥602	¥650	M6 x 20	45	10	253.9

Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Pan Head Screw with Captive Washer (steel, with small round washer)



B51 Type

- Features** • Saves you the trouble of setting washers and spring washers.
Specs • Tensile Strength Rank: 4.8
 • With spring washer, small round washer (P-4 type)
Materials • Low Carbon Steel (SWCH)
 • **Surface Treatment: Hexavalent Chromate Finishing**
Origin • Japan

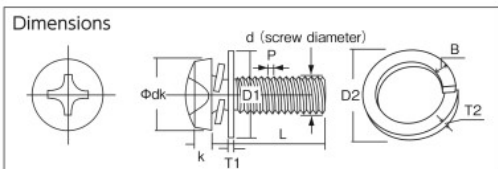

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
212-7067	B51-0306	¥602	¥650	M3 x 6	180	10	99.3
212-7075	B51-0308	¥602	¥650	M3 x 8	170	10	99.7
212-7091	B51-0310	¥602	¥650	M3 x 10	165	10	110.8
212-7113	B51-0312	¥602	¥650	M3 x 12	160	10	121.2
212-7121	B51-0315	¥602	¥650	M3 x 15	150	10	130.5
212-7229	B51-0406	¥602	¥650	M4 x 6	100	10	99.4
212-7237	B51-0408	¥602	¥650	M4 x 8	130	10	148.7
212-7245	B51-0410	¥602	¥650	M4 x 10	130	10	168.3
212-7253	B51-0412	¥602	¥650	M4 x 12	125	10	180.6
212-7261	B51-0415	¥602	¥650	M4 x 15	105	10	173.2

Basic Dimension (unit: mm)

Nominal Designation of Thread (d)	Thread Pitch (P)	Pan Head		Plain Washer		Spring Lock Washer (no. 2)	
		dk	k	D1	T1	D2	B x T2
M3	0.5	5.5	2.0	6.0	0.5	5.5	1.1 x 0.7
M4	0.7	7.0	2.6	8.0	0.5	7.0	1.4 x 1.0
M5	0.8	9.0	3.3	10.0	0.8	8.5	1.7 x 1.3
M6	1.0	10.5	3.9	11.5	0.8	11.5	2.7 x 1.5

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
212-7318	B51-0420	¥602	¥650	M4 x 20	95	10	99.2
212-7369	B51-0430	¥602	¥650	M4 x 30	75	10	209.7
212-7377	B51-0508	¥602	¥650	M5 x 8	80	10	168.9
212-7385	B51-0510	¥602	¥650	M5 x 10	80	10	188.2
212-7393	B51-0512	¥602	¥650	M5 x 12	80	10	207.5
212-7407	B51-0515	¥602	¥650	M5 x 15	70	10	206.5
212-7431	B51-0520	¥602	¥650	M5 x 20	65	10	231.2
212-7466	B51-0610	¥602	¥650	M6 x 10	50	10	496.3
212-7482	B51-0615	¥602	¥650	M6 x 15	45	10	213.7
212-7512	B51-0620	¥602	¥650	M6 x 20	40	10	225.7

Contact us: 0120-509-849 <http://www.orange-book.com/>