


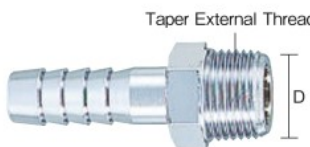
Prices displayed include 8% tax.



Stock
38,650
Items

Hose Nipple

Com Drawing



HN-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa


Materials


- Main Body: Brass (C3604)
- Chrome plated finish

Origin

- Japan

Example

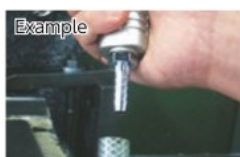




Stock
38,650
Items

Stainless Steel Hose Nipple

Com Drawing

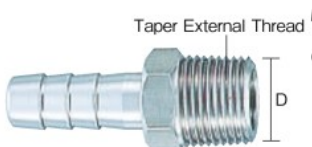

SHN-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa


Materials

- Main Body: Stainless Steel (SUS304)
- Chrome plated finish

Origin

- Japan

Example



Order Unit: 1 Bag


Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter D	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-8994	HN-107	¥ 694	¥ 750	R1/8	7.0	5	60
177-9001	HN-209	¥ 926	¥ 1,000	R1/4	9.0	5	90
177-9010	HN-310	¥ 1,509	¥ 1,630	R3/8	10.5	5	140
177-9028	HN-414	¥ 1,869	¥ 2,020	R1/2	14.0	5	250
177-9036	HN-620	¥ 2,027	¥ 2,190	R3/4	20.5	3	294

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter D	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9192	SHN-107	¥ 3,315	¥ 3,580	R1/8	7.0	5	100
177-9206	SHN-209	¥ 3,315	¥ 3,580	R1/4	9.0	5	150
177-9214	SHN-310	¥ 3,471	¥ 3,750	R3/8	10.5	5	132
177-9222	SHN-414	¥ 3,036	¥ 3,280	R1/2	14.0	3	150
177-9231	SHN-620	¥ 3,406	¥ 3,680	R3/4	20.5	2	176


Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock
38,650
Items

Nipple Hose Joint

Com Drawing



NHJ-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa


Materials


- Main Body: Brass (C3604)
- Chrome plated finish

Origin

- Japan

Example

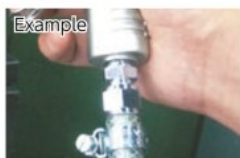




Stock
38,650
Items

Nipple

Com Drawing

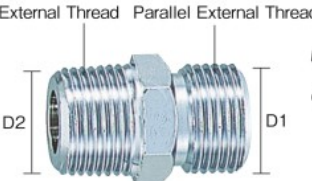

TN-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa


Materials

- Main Body: Brass (C3604)
- Chrome plated finish

Origin

- Japan

Example

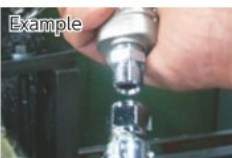

Order Unit: 1 Bag


Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter D	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9249	NHJ-107	¥ 1,361	¥ 1,470	R1/8	7.0	5	100
177-9257	NHJ-209	¥ 1,565	¥ 1,690	R1/4	9.0	5	190
177-9265	NHJ-310	¥ 1,500	¥ 1,620	R3/8	10.5	3	174
177-9273	NHJ-414	¥ 2,175	¥ 2,350	R1/2	14.0	2	216
177-9281	NHJ-620	¥ 1,740	¥ 1,880	R3/4	20.5	1	198

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter		Q'ty Per Bag (piece)	Weight (g/bag)
				D1	D2		
177-9141	TN-107	¥ 685	¥ 740	G1/8	R1/8	5	50
177-9150	TN-209	¥ 759	¥ 820	G1/4	R1/4	5	80
177-9168	TN-310	¥ 1,157	¥ 1,250	G3/8	R3/8	5	150
177-9176	TN-414	¥ 1,120	¥ 1,210	G1/2	R1/2	3	162
177-9184	TN-620	¥ 1,444	¥ 1,560	G3/4	R3/4	2	200


Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock
38,650
Items

Y Type Hose Joint

Com Drawing



YHJ-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa


Materials

- Main Body: Brass (C3604, C3771)
- Chrome plated finish

Origin

- China

Example





Stock
38,650
Items

Hose Joint

Com Drawing



HJ-310

Specs

- Working Fluid: Water, Air, Oil
- Fluid Temperature: -50 to 150°C
- Working Pressure: 3.45MPa

Materials

- Main Body: Brass (C3604)
- Chrome plated finish

Origin

- Japan

Example



Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9044	YHJ-209	¥ 990	¥ 1,070	9.0	1	126
177-9052	YHJ-310	¥ 1,638	¥ 1,770	10.5	1	152

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter (thread)	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9095	HJ-107	¥ 703	¥ 760	G1/8	7.0	5	50
177-9109	HJ-209	¥ 842	¥ 910	G1/4	9.0	5	110
177-9117	HJ-310	¥ 1,203	¥ 1,300	G3/8	10.5	5	140
177-9125	HJ-414	¥ 1,545	¥ 1,670	G1/2	14.0	3	162
177-9133	HJ-620	¥ 1,722	¥ 1,860	G3/4	20.5	2	196

Contact us: 0120-509-849 <http://www.orange-book.com/>