


Pipe Joints

The number next to the logo mark indicates items in stock for each brand.

TRUSCO Stock **38,650** Items

3-Way Hose

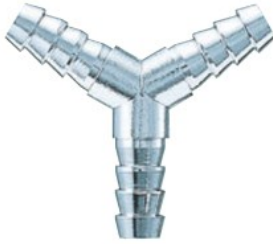

MH-310

- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: -50 to 150°C
 - Working Pressure: 3.45MPa
- Materials**
- Main Body: Brass (C3771)
 - Chrome plated finish
- Origin**
- China



Example

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9061	MH-209	¥2,231	¥2,410	9.0	5	240
177-9079	MH-310	¥1,574	¥1,700	10.5	3	168
177-9087	MH-414	¥842	¥910	14.0	1	67

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

Hose Couplings



HT-310

- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: -50 to 150°C
 - Working Pressure: 3.45MPa
- Materials**
- Main Body: Brass (C3604)
 - Chrome plated finish
- Origin**
- Japan



Example

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Connection Port Diameter (horse nipple outer diameter) (mm)	Q'ty Per Bag (piece)	Weight (g/bag)
177-9290	HT-107	¥833	¥900	7.0	5	50
177-9303	HT-209	¥954	¥1,030	9.0	5	80
177-9311	HT-310	¥1,250	¥1,350	10.5	5	100
177-9320	HT-414	¥1,250	¥1,350	14.0	3	120
177-9338	HT-620	¥1,638	¥1,770	20.5	2	176

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock **38,650** Items

Coupling for Braided Hose



TBJ-6

- Features**
- Coupling for braided hose
 - Compatible for RoHS directive (low cadmium brass).
- Specs**
- Working Fluid: Water, Air
 - Fluid Temperature: 0 to 70°C
 - Working Pressure: 1.0MPa
- Materials**
- Brass (low cadmium type)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Connection Port Diameter (mm)	Connection Port Diameter (horse nipple outer diameter) (mm)	SPQ (piece)	Weight (g)
496-4136	TBJ-6	¥583	¥630	R1/4	6.0	20	25
496-4144	TBJ-8	¥630	¥680	R1/4	8.0	20	25
496-4152	TBJ-9	¥676	¥730	R3/8	9.0	10	35
496-4055	TBJ-10	¥703	¥760	R3/8	10.0	10	35
496-4063	TBJ-12	¥1,018	¥1,100	R1/2	12.0	10	65
496-4071	TBJ-15	¥1,111	¥1,200	R1/2	15.0	10	75

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Connection Port Diameter (mm)	Connection Port Diameter (horse nipple outer diameter) (mm)	SPQ (piece)	Weight (g)
496-4080	TBJ-19	¥1,759	¥1,900	R3/4	19.0	10	135
496-4098	TBJ-25	¥2,777	¥3,000	R1	25.0	4	260
496-4101	TBJ-32	¥5,091	¥5,500	R1 1/4	32.0	2	345
496-4110	TBJ-38	¥6,295	¥6,800	R1 1/2	38.0	2	405
496-4128	TBJ-50	¥8,702	¥9,400	R2	50.0	2	710

Contact us: 0120-509-849 <http://www.orange-book.com/>

SANPLATEC Stock **273** Items

"PP Tube Connector Taper Type"



- Features**
- Resin connector with excellent cost performance.
 - Optimum for connecting tubes.
 - Strong, and autoclave is also possible.
- Specs**
- Applicable Fluid: Hydrochloric Acid, Phosphoric Acid
 - Working Temperature Range: -10 to 121°C
- Materials**
- Polypropylene (PP)
- Origin**
- Japan

Order Unit: 1 Set

SANPLATEC Co.Ltd.

Order Code	Item No.	Price (per set)	MSRP (per set)	Type	Total Length (mm)	Applicable Tube Inner Diameter (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (g/set)
419-5566	3532	¥194	¥180	I Type	47.0	3 to 5	10	1	13.4
419-5558	3531	¥216	¥200	I Type	70.3	5 to 8	10	1	31.5
419-5540	3530	¥270	¥250	I Type	75.3	8 to 10	10	1	51.0
419-5582	3534	¥216	¥200	Different Diameter Type	62.0	3 to 5/5 to 8	10	1	23.4
419-5574	3533	¥302	¥280	Different Diameter Type	80.0	5 to 8/8 to 13	10	1	57.7
419-5647	3540	¥302	¥280	T Type	52.0	3 to 5	10	1	19.2
419-5639	3539	¥324	¥300	T Type	78.0	5 to 8	10	1	47.7
419-5621	3538	¥378	¥350	T Type	85.0	8 to 10	10	1	85.4
419-5612	3537	¥302	¥280	Y Type	52.0	3 to 5	10	1	23.2
419-5604	3536	¥378	¥350	Y Type	83.0	5 to 8	10	1	61.3
419-5591	3535	¥410	¥380	Y Type	90.0	8 to 10	10	1	99.5

Contact us: 06-6353-5141 <http://www.sanplatec.co.jp/>

