

Monkey Wrenches

Wrenches • Spanners • Pullers

Power Wrenches

Ratchet Wrenches

Combination Ratchet Wrenches

Piping Ratchet Wrenches

Flat Ratchet Wrenches

Offset Wrenches

Gear Wrenches

Slogging Wrenches

Flare Nut Wrenches

Crow Foot Wrenches

Monkey Wrenches

Spanners

Combination Spanners

Hook Spanners

Special Purpose Spanners

Gear Pullers

Bearing Pullers

TRUSCO Stock **38,650** Items

Adjustable Wrench

Comeco Chemical Content Inspection **Com** Drawing

- Features**
- Has a scale that understands the opening dimension.
- Origin**
- China



TRM-200



Example

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (kg)
253-4541	TRM-150	¥ 972	¥1,050	158	20	5	0.14
253-4550	TRM-200	¥1,333	¥1,440	208	24	5	0.24
253-4568	TRM-250	¥1,666	¥1,800	258	29	5	0.42
253-4576	TRM-300	¥2,268	¥2,450	308	34	5	0.67
253-4584	TRM-375	¥4,953	¥5,350	385	45	2	1.27
253-4592	TRM-450	¥8,517	¥9,200	450	55	1	2.01

Contact us: 0120-509-849 <http://www.orange-book.com/>

The number next to the logo mark indicates items in stock for each brand.

SAFETY TOOLS Stock **50** Items

Titanium Alloy Monkey Wrench

- Features**
- The specific gravity of titanium alloy is approx. 4.4 that is lighter by approx. 60% than iron.
 - It is more excellent in corrosion resistance than stainless steel or platinum.
 - Since it is non-magnetic, it is not affected by magnetic force and it does not affect electronics equipment as well.
- Materials**
- Titanium alloy (TC11)
- Origin**
- China



5101-1006

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
856-2140	5101-1002	¥43,999	¥47,530	150	18	1	80
856-2141	5101-1004	¥48,849	¥52,770	200	24	1	170
856-2142	5101-1006	¥56,293	¥60,810	250	30	1	260
856-2143	5101-1008	¥73,974	¥79,910	300	36	1	435

Contact us: 0120-509-849 <http://bestsafetytools.com/>

GEDORE Stock **1,637** Items

Adjustable Wrench

- Features**
- Has a scale that understands the opening dimension.
 - It is robust because it is made of carefully forged steel.
- Materials**
- Chrome Vanadium Steel (Cr-V)
 - Surface treatment: Chrome plating
- Origin**
- China



6380990

GEDORE Werkzeugfabrik GmbH & Co. KG


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
855-4245	6380990	¥1,458	—	155	20	1	145
855-4246	6381020	¥1,962	—	205	25	1	270
855-4247	6381100	¥2,512	—	255	30	1	420
855-4248	6381290	¥3,459	—	305	36	1	785

Contact us: 03-3433-9841 <http://www.orange-book.com/>

GEDORE Stock **1,637** Items

Adjustable Wrench

- Features**
- It has impact resistance.
 - The surface is treated with manganese phosphate.
- Materials**
- Chrome Vanadium Steel (Cr-V)
 - Surface treatment: Chrome plating
- Origin**
- China

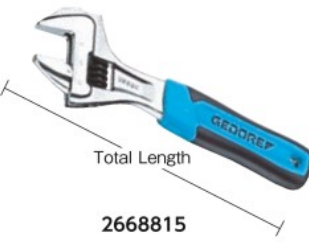

2668815

GEDORE Werkzeugfabrik GmbH & Co. KG

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
855-3968	2668815	¥1,520	—	153.0	20	1	160
855-3918	1966294	¥2,006	—	206.5	25	1	340
855-3920	2171023	¥2,507	—	254.5	30	1	251
855-3969	2668874	¥3,379	—	305.0	36	1	780

Contact us: 03-3433-9841 <http://www.orange-book.com/>

LOBTEX Stock **1,809** Items

Adjustable Wrench

- Features**
- A super long seller, powerful type adjustable wrench of 80 years or more since its release.
 - Can correspond to multiple size bolts and nuts with 1 piece.
- Origin**
- Japan



M250

(Price revision date: Jan, 2016) LOBTEX Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (kg)
125-0027	M100	¥ 2,370	¥ 2,510	110	13	6	0.05
125-0035	M150	¥ 2,301	¥ 2,440	160	20	6	0.12
125-0043	M200	¥ 2,525	¥ 2,670	206	24	6	0.25
125-0051	M250	¥ 3,234	¥ 3,420	258	29	6	0.44
125-0060	M300	¥ 4,239	¥ 4,490	304	34	6	0.70
125-0078	M375	¥ 8,046	¥ 8,510	385	44	2	1.35
125-0086	M450	¥11,286	¥11,940	465	53	1	1.90
125-0094	M600	¥20,757	¥21,960	615	67	1	3.40

Contact us: 072-980-1111 <http://www.lobtex.co.jp/>

STONE Stock **2,937** Items

"Adjustable Wrench"

- Features**
- It can be used according to the size of the bolt/nut by adjusting opening/closing of the mouth in combination of a worm and a rack.
 - Scale is pre-equipped so that it can easily match the size of the bolt/nut.
- Materials**
- Structural Steel
- Origin**
- Japan



MW-250

TONE CO. LTD.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
436-2888	MW-100	¥ 2,376	¥ 2,965	110	14.5	6	50
436-2896	MW-150	¥ 2,376	¥ 2,965	160	21.5	6	120
436-2900	MW-200	¥ 2,515	¥ 3,135	208	25.5	6	240
436-2918	MW-250	¥ 3,155	¥ 3,935	258	30.5	6	400
436-2926	MW-300	¥ 4,150	¥ 5,175	304	35.5	6	650
436-2934	MW-375	¥ 8,447	¥10,530	385	45.5	1	1200
436-2942	MW-450	¥11,841	¥14,760	465	54.5	1	2100

Contact us: 0721-56-1850 <http://www.tonetool.co.jp/>