

Prices displayed include 8% tax.

TRUSCO
 Stock 38,650 Items

Wide Adjustable Wrench



- Features
- Possible to work in a narrow space.
 - **Since the jaw shaft does not protrude, it does not get in the way when working in the limited space.**
 - **With a scale.**
- Materials
- Main Body: Chrome Vanadium Steel (Cr-V)
 - Lower Jaw: Chrome Vanadium Steel (Cr-V)
 - Worm: Medium Carbon Steel
 - Pin: Chromium Molybdenum Steel
- Origin
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (kg)
445-6785	TWM15-100	¥ 1,666	¥ 1,800	108	17.0	20	0.055
445-6793	TWM15-150	¥ 1,759	¥ 1,900	157	23.9	20	0.120
445-6807	TWM15-200	¥ 1,916	¥ 2,070	206	28.6	10	0.240
445-6815	TWM15-250	¥ 2,481	¥ 2,680	254	32.8	10	0.400
445-6823	TWM15-300	¥ 3,610	¥ 3,900	304	38.0	5	0.650
445-6831	TWM15-375	¥ 5,869	¥ 6,340	381	50.0	5	1.340
445-6840	TWM15-450	¥ 9,155	¥ 9,890	460	60.0	5	1.920
445-6858	TWM15-600	¥ 16,751	¥ 18,095	612	70.0	1	3.020

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO
 Stock 38,650 Items

"Ultra Wide Adjustable Wrench"



- Features
- **Multiple sizes of bolt and nut can be tightened with its wide opening.**
 - With soft grips you can work gentle and stable on your hands.
- Materials
- Main Body: Chrome Vanadium Steel (Cr-V)
 - Lower Jaw: Chrome Vanadium Steel (Cr-V)
 - Worm: Medium Carbon Steel
 - Pin: Chromium Molybdenum Steel
- Origin
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (kg)
445-6742	TUWM-34	¥ 2,200	¥ 2,377	166	34	10	0.170
445-6751	TUWM-38	¥ 2,647	¥ 2,860	214	38	10	0.286
445-6769	TUWM-50	¥ 3,703	¥ 4,000	265	50	10	0.535
445-6777	TUWM-60	¥ 5,580	¥ 6,028	312	60	5	0.840

Contact us: 0120-509-849 <http://www.orange-book.com/>

SUPER TOOL
 Stock 2,429 Items

"Super Wide Adjustable Angle Wrench"



- Features
- Wide opening that has never been before.
 - **Super wide, thin, and lightweight type.**
 - The strength has cleared JIS H class.
 - With a grip that is gentle to hands.
- Materials
- Special Alloy Steel
- Origin
- China

Order Unit: 1 Piece


(Price revision date: Apr, 2015) SUPER TOOL Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
449-3737	MWG38	¥ 2,633	¥ 2,830	210	38	6	290
449-3745	MWG50	¥ 3,375	¥ 3,630	260	50	6	390

Contact us: 0120-86-4859 <http://www.supertool.co.jp/>


TOP
 Stock 1,160 Items

"Thin Type Exact Wrench"

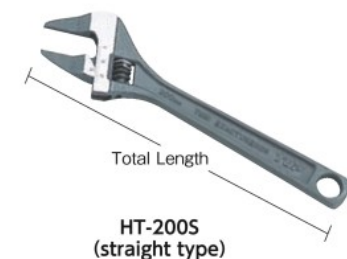

- Features
- Backlashless adjustable wrench without wobbling worm, so once you adjust the mouth width you can work with sense of spanner.
 - The tip thickness is 4.5mm.
 - **With a scale.**
- Materials
- Chrome Vanadium Steel (Cr-V)
- Origin
- Japan

Item No.	Type	Tip Part Thickness
HT-200S	Straight	4.5±0.5mm
HT-150B	Bent	3.7±0.3mm
HT-200B	Bent	4.5±0.5mm

 

Order Unit: 1 Piece

(Price revision date: Apr, 2016) TOP KOGYO Co.Ltd

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	SPQ (piece)	Weight (g)
248-7594	HT-200S	¥ 3,394	¥ 4,400	218	24	6	230
248-7608	HT-150B	¥ 3,317	¥ 4,300	168	20	6	135
248-7616	HT-200B	¥ 3,549	¥ 4,600	216	24	6	235

Contact us: 0256-33-1681 <http://www.toptools.co.jp/>