

Combination Spanners

The number next to the logo mark indicates items in stock for each brand.

Power Wrenches

Ratchet Wrenches

Combination Ratchet Wrenches

Piping Ratchet Wrenches

Flat Ratchet Wrenches

Offset Wrenches

Gear Wrenches

Slugging Wrenches

Flare Nut Wrenches

Crow Foot Wrenches

Monkey Wrenches

Spanners

Combination Spanners

Hook Spanners

Special Purpose Spanners


Gear Pullers

Bearing Pullers



Stock 38,650 Items

Combination Spanner

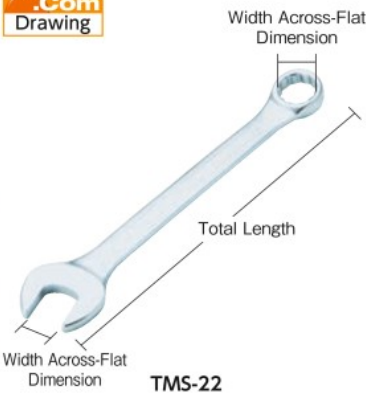

- Features**
- The finish side is beautiful, the touch is good and there is a heavy feeling.
 - Surface treatment is trivalent chromium plating.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan




The bent angle of the handle is 15°

TRUSCO NAKAYAMA CORPORATION


Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
416-0304	TMS-055	¥ 296	¥ 320	5.5	93	10	11
416-0312	TMS-06	¥ 296	¥ 320	6.0	100	10	15
416-0321	TMS-07	¥ 296	¥ 320	7.0	110	10	18
416-0339	TMS-08	¥ 296	¥ 320	8.0	120	10	23
416-0347	TMS-09	¥ 306	¥ 330	9.0	130	10	31
416-0355	TMS-10	¥ 334	¥ 360	10.0	140	10	34
416-0363	TMS-11	¥ 361	¥ 390	11.0	150	10	47
416-0371	TMS-12	¥ 370	¥ 400	12.0	160	10	53
416-0380	TMS-13	¥ 407	¥ 440	13.0	170	10	65
416-0398	TMS-14	¥ 426	¥ 460	14.0	180	10	82
416-0401	TMS-15	¥ 509	¥ 550	15.0	190	10	92
416-0410	TMS-16	¥ 528	¥ 570	16.0	200	10	103
416-0428	TMS-17	¥ 537	¥ 580	17.0	210	10	123
416-0436	TMS-18	¥ 620	¥ 670	18.0	220	10	137
416-0444	TMS-19	¥ 648	¥ 700	19.0	230	10	158
416-0452	TMS-21	¥ 750	¥ 810	21.0	250	10	196
416-0461	TMS-22	¥ 814	¥ 880	22.0	260	10	217
416-0479	TMS-24	¥ 897	¥ 970	24.0	280	10	277
416-0487	TMS-26	¥ 1,185	¥ 1,280	26.0	295	5	307
416-0495	TMS-27	¥ 1,306	¥ 1,410	27.0	310	5	383
416-0509	TMS-30	¥ 1,630	¥ 1,760	30.0	340	5	495
416-0517	TMS-32	¥ 1,916	¥ 2,070	32.0	360	5	547

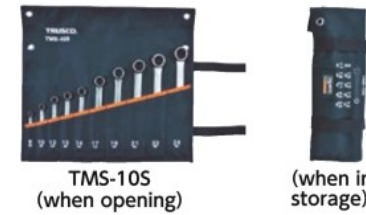

TMS-10S (when opening)

(when in storage)

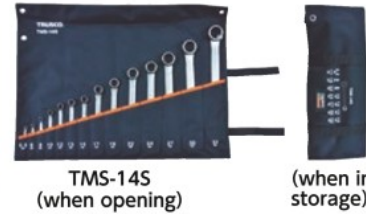

TMS-14S (when opening)

(when in storage)

Set Accessories • Storage Pouch

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
416-0525	TMS-10S	¥ 5,397	¥ 5,830	8, 10, 12, 13, 14, 17, 19, 21, 22, 24	10	1	1.52
416-0533	TMS-14S	¥ 9,202	¥ 9,940	5.5, 6, 8, 10, 12, 13, 14, 17, 19, 22, 24, 27, 30, 32	14	1	2.88

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Combination Spanner

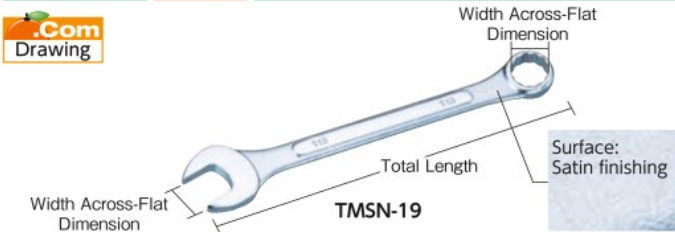

- Features**
- The spanner and the box end wrench with the same diameter are integrated, and the spanner is suitable for quick turning and the box end wrench is suitable for final fastening work.
 - The bent angle of the box end handle part is 15°.
- Materials**
- Chrome Vanadium Steel (Cr-V)
 - Surface treatment: Nickel chrome plating, satin finishing
- Origin**
- Taiwan

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)	Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width Across-Flat Dimension (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
488-8227	TMSN-055	¥ 241	¥ 260	5.5	93	10	16	488-8405	TMSN-22	¥ 713	¥ 770	22.0	260	5	244
488-8235	TMSN-06	¥ 241	¥ 260	6.0	93	10	16	488-8413	TMSN-24	¥ 768	¥ 830	24.0	309	5	351
488-8243	TMSN-07	¥ 241	¥ 260	7.0	98	10	19	488-8421	TMSN-26	¥ 1,027	¥ 1,110	26.0	332	5	415
488-8251	TMSN-08	¥ 241	¥ 260	8.0	103	10	26	488-8430	TMSN-27	¥ 1,138	¥ 1,230	27.0	358	5	523
488-8260	TMSN-09	¥ 278	¥ 300	9.0	116	10	31	488-8448	TMSN-30	¥ 1,407	¥ 1,520	30.0	380	5	650
488-8278	TMSN-10	¥ 278	¥ 300	10.0	123	10	39	488-8456	TMSN-32	¥ 1,657	¥ 1,790	32.0	418	5	808
488-8294	TMSN-11	¥ 306	¥ 330	11.0	131	10	41	488-8464	TMSN-33	¥ 2,203	¥ 2,380	33.0	460	2	1180
488-8308	TMSN-12	¥ 306	¥ 330	12.0	143	10	54	488-8472	TMSN-34	¥ 2,203	¥ 2,380	34.0	460	2	1010
488-8316	TMSN-13	¥ 352	¥ 380	13.0	147	10	56	488-8481	TMSN-35	¥ 2,222	¥ 2,400	35.0	460	2	990
488-8324	TMSN-14	¥ 370	¥ 400	14.0	168	10	89	488-8499	TMSN-36	¥ 2,694	¥ 2,910	36.0	485	2	1270
488-8341	TMSN-15	¥ 444	¥ 480	15.0	189	10	119	488-8502	TMSN-38	¥ 2,694	¥ 2,910	38.0	485	2	1210
488-8359	TMSN-16	¥ 444	¥ 480	16.0	196	10	133	488-8511	TMSN-41	¥ 3,629	¥ 3,920	41.0	539	2	1750
488-8367	TMSN-17	¥ 444	¥ 480	17.0	207	10	146	488-8529	TMSN-46	¥ 3,999	¥ 4,320	46.0	610	2	1900
488-8375	TMSN-18	¥ 528	¥ 570	18.0	220	10	154	488-8537	TMSN-50	¥ 4,666	¥ 5,040	50.0	610	2	2420
488-8383	TMSN-19	¥ 528	¥ 570	19.0	230	10	184	488-8545	TMSN-55	¥ 8,628	¥ 9,320	55.0	665	1	3900
488-8391	TMSN-21	¥ 648	¥ 700	21.0	242	5	205	488-8553	TMSN-60	¥ 11,238	¥ 12,140	60.0	760	1	5530

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (kg/set)
488-8286	TMSN-10S	¥ 4,860	¥ 5,250	8, 10, 12, 13, 14, 17, 19, 21, 22, 24	10	1	1.65
488-8332	TMSN-14S	¥ 8,285	¥ 8,950	5.5, 6, 8, 10, 12, 13, 14, 17, 19, 22, 24, 27, 30, 32	14	1	3.50

Contact us: 0120-509-849 <http://www.orange-book.com/>