

Ball-Point Hexagonal Wrenches

Stock 1,057 Items

4-727

Prices displayed include 8% tax.



Stock 38,650 Items


Angled Ball-Point Type Hexagonal Wrench



- A hex key that is made by turning 30° and considers usability.
- It has strong durability and abrasion resistance due to the special processing technology.
- Final tightening can be done with ball point.
- Japan

Warning

- When performing the final tightening with the ball point, please use a pipe handle for the hex key.

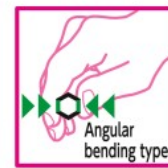

Since the surface receives the force, it can turn easily.



It's necessary to turn while putting strength on the corner.

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
489-5479	TBRK-15	¥ 546	¥ 590	1.5	15	81	10	1.5
489-5487	TBRK-20	¥ 555	¥ 600	2.0	16	91	10	2.5
489-5495	TBRK-25	¥ 593	¥ 640	2.5	18	106	10	5.0
489-5509	TBRK-30	¥ 630	¥ 680	3.0	20	123	10	8.0
489-5517	TBRK-40	¥ 759	¥ 820	4.0	24	143	10	17.0
489-5525	TBRK-50	¥ 824	¥ 890	5.0	27	163	10	30.0
489-5533	TBRK-60	¥ 944	¥ 1,020	6.0	31	185	10	49.0
489-5541	TBRK-80	¥ 1,278	¥ 1,380	8.0	34	210	10	99.0
489-5461	TBRK-100	¥ 1,666	¥ 1,800	10.0	38	235	10	173.0

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
489-5550	TBRK-9S	¥ 7,258	¥ 7,840	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	5	410

Handle Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
837-1271	TBRK-9HS	¥ 8,794	¥ 9,500	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10, TPH-3	10	5	610

Pipe Handle

- By using the triple handle, it is possible to continuously do from quick turn to the final tightening with the Ball-point.
- Allows easy final tightening with its always easy to turn handle directions (5 directions) insertion holes.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	SPQ (piece)	Weight (g)
837-1272	TPH-3	¥ 1,944	¥ 2,100	275	10	210

Contact us: 0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Ball-Point Hexagonal Wrench Set



- It is stored in a holder convenient for carrying around and storage.
- The hardness is HRC52 to 56.
- Chrome Vanadium Steel
- Holder
- Japan

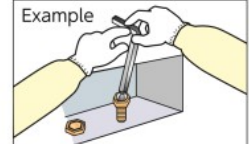

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
125-2631	GB7-2510	¥ 2,416	¥ 2,610	2.5, 3, 4, 5, 6, 8, 10	7	5	340

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Ball-Point Hexagonal Wrench (with magic ring)

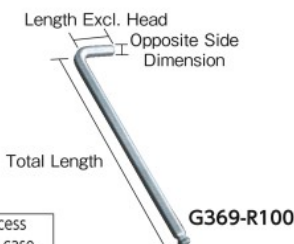

- Since the mechanical spring steel ring is attached to the Ball-point part, it catches the hexagon screws and keep it attached. (patented: Japanese patent no.3151178)
- Chrome vanadium steel to HRC57 to 60 chrome plated.
- Germany

Warning

- Magiclean ring attachment comes from dimensions of 3mm or more.

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
125-3638	G369-R30	¥ 611	¥ 660	3	20	128	10	9
125-3646	G369-R40	¥ 630	¥ 680	4	25	142	10	19
125-3654	G369-R50	¥ 676	¥ 730	5	28	163	10	33
125-3662	G369-R60	¥ 768	¥ 830	6	32	184	10	54
125-3671	G369-R80	¥ 1,111	¥ 1,200	8	36	206	10	104
125-3689	G369-R100	¥ 1,416	¥ 1,530	10	40	231	5	184

Set Accessories

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
125-3051	G369-9S	¥ 7,915	¥ 8,550	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	5	430

Contact us: 0120-509-849 <http://www.orange-book.com/>