

# Ball-Point Hexagonal Wrenches (short below head)

The number next to the logo mark indicates items in stock for each brand.

Screwdrivers - Hexagonal Wrenches

Grip Screwdrivers

Screwdrivers with Plastic Handle

Stubby Screwdrivers

Screwdrivers with Wood Handle

Precision Screwdrivers

Electric Detection Screwdrivers

Interchangeable Screwdrivers

Ratchet Screwdrivers

Offset Ratchet Screwdrivers

Socket Screwdrivers

Impact Drivers (Manual Type)

Hexagon Driver

Hex Lobe Screwdrivers

Special-Purpose Screwdrivers

Ball-Point Hexagonal Wrenches

Hexagonal Wrenches

Hex Lobe Wrenches

**TRUSCO** Stock 38,650 Items

## Ball-Point Hexagonal Wrench (with catcher ball)



- Features**
- Since the length excluding head is about 1/2 of the standard type, you can work even in a narrow place.
  - Ball-point type with a catch ball at the tip, boasts excellent usability in narrow place. (3mm or more)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
304-2782	TTVS-15	¥ 602	¥ 650	1.5	4.5	50	10	0.7
304-2791	TTVS-20	¥ 602	¥ 650	2.0	4.5	56	10	1.6
304-2804	TTVS-25	¥ 630	¥ 680	2.5	5.5	63	10	2.8
304-2812	TTVS-30	¥ 658	¥ 710	3.0	7.0	71	10	4.6
304-2821	TTVS-40	¥ 685	¥ 740	4.0	8.0	80	10	9.5
304-2839	TTVS-50	¥ 741	¥ 800	5.0	9.0	90	10	16.0
304-2847	TTVS-60	¥ 944	¥ 1,020	6.0	12.0	100	10	26.0
304-2855	TTVS-80	¥ 1,157	¥ 1,250	8.0	15.0	112	10	55.0
304-2863	TTVS-100	¥ 1,666	¥ 1,800	10.0	17.5	125	10	95.0

Set Accessories • Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
302-2129	TTVS-9S	¥ 7,359	¥ 7,950	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	5	245


Contact us: 0120-509-849 <http://www.orange-book.com/>

**Warning**

- The opposite side dimension 1.5, 2, 2.5mm does not have catch ball.

**TRUSCO** Stock 38,650 Items

## Long Ball-Point Hexagonal Wrench (with catcher ball)

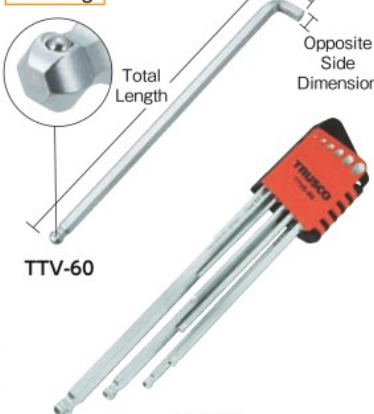

- Features**
- Since the length excluding head is about 1/2 of the standard type, you can work even in a narrow place.
  - Ball-point type with a catch ball at the tip, boasts excellent usability in narrow place. (3mm or more)
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
301-9012	TTV-15	¥ 658	¥ 710	1.5	4.5	90	10	1.3
301-9021	TTV-20	¥ 658	¥ 710	2.0	4.5	100	10	2.7
301-9039	TTV-25	¥ 676	¥ 730	2.5	5.5	112	10	5.0
301-9047	TTV-30	¥ 703	¥ 760	3.0	7.0	126	10	8.0
301-9055	TTV-40	¥ 750	¥ 810	4.0	8.0	142	10	16.0
301-9063	TTV-50	¥ 842	¥ 910	5.0	9.0	160	10	25.0
301-9071	TTV-60	¥ 1,074	¥ 1,160	6.0	12.0	180	10	48.0
301-9080	TTV-80	¥ 1,342	¥ 1,450	8.0	15.0	200	10	90.0
301-9098	TTV-100	¥ 1,926	¥ 2,080	10.0	17.5	224	10	160.0

Set Accessories • Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
301-9101	TTV-9S	¥ 9,072	¥ 9,800	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	5	395


Contact us: 0120-509-849 <http://www.orange-book.com/>

**Warning**

- The opposite side dimension 1.5, 2, 2.5mm does not have catch ball.

**TRUSCO** Stock 38,650 Items

## "Short Neck 100°" Long Ball-Point Hexagonal Wrench (with catcher ball)

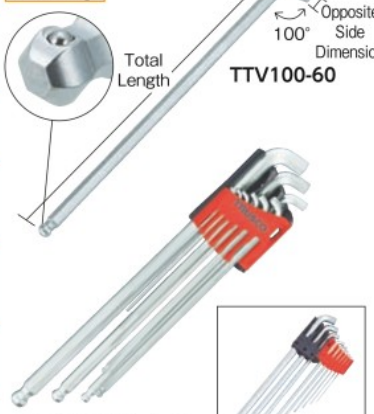

- Features**
- To prevent the fingertip from touching the bottom surface during use, the bending angle is widened to 100° from the conventional 90° to further enhance ease of use.
- Origin**
- Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (mm)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
330-4035	TTV100-15	¥ 685	¥ 740	1.5	4.5	90	10	1
330-4043	TTV100-20	¥ 685	¥ 740	2.0	4.5	100	10	3
330-4051	TTV100-25	¥ 703	¥ 760	2.5	5.5	112	10	5
330-4060	TTV100-30	¥ 787	¥ 850	3.0	7.0	126	10	8
330-4078	TTV100-40	¥ 824	¥ 890	4.0	8.0	142	10	16
330-4086	TTV100-50	¥ 926	¥ 1,000	5.0	9.0	160	10	25
330-4094	TTV100-60	¥ 1,157	¥ 1,250	6.0	12.0	180	10	48
330-4108	TTV100-80	¥ 1,454	¥ 1,570	8.0	15.0	200	10	90
330-4116	TTV100-100	¥ 1,999	¥ 2,160	10.0	17.5	224	10	160

Set Accessories • Holder

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (mm)	Set Contents (piece)	SPQ (set)	Weight (g/set)
330-4027	TTV100-9S	¥ 9,535	¥ 10,300	1.5, 2, 2.5, 3, 4, 5, 6, 8, 10	9	5	395

Contact us: 0120-509-849 <http://www.orange-book.com/>

**Warning**

- The opposite side dimension 1.5, 2, 2.5mm does not have catch ball.