

Hexagonal Wrenches (inch size)

Stock 991 Items

4-783

Prices displayed include 8% tax.



Stock 38,650 Items

Hexagonal Wrench (inch size)



- Features**
- By chamfering both ends, plugging in the hexagon hole is easy.
 - Provide stable quality by excellent heat treatment.
 - The surface is black dye.
- Materials**
- Chrome Vanadium Steel (Cr-V)
- Origin**
- Taiwan



Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (inch)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
445-6009	TRRI-0.05	¥ 93	¥100	0.05	12	72	50	1.0
445-6017	TRRI-1/16	¥102	¥110	1/16	14	77	50	1.6
445-6106	TRRI-5/64	¥102	¥110	5/64	15	82	50	2.6
445-6068	TRRI-3/32	¥102	¥110	3/32	17	88	50	4.1
445-6122	TRRI-7/64	¥111	¥120	7/64	18	92	50	5.9
445-6041	TRRI-1/8	¥111	¥120	1/8	19	96	50	8.0
445-6131	TRRI-9/64	¥130	¥140	9/64	20	101	50	10.6
445-6092	TRRI-5/32	¥130	¥140	5/32	21	105	50	13.7
445-6050	TRRI-3/16	¥139	¥150	3/16	24	114	50	21.6
445-6114	TRRI-7/32	¥158	¥170	7/32	26	124	50	31.9
445-6033	TRRI-1/4	¥193	¥208	1/4	28	135	40	45.4
445-6084	TRRI-5/16	¥231	¥250	5/16	32	151	30	79.8
445-6076	TRRI-3/8	¥325	¥352	3/8	35	170	20	128.6

- Set** Features
- The holder rotates, making it easy to put in and out wrenches of various sizes.
- Accessories
- Holder

Order Unit: 1 Set

(Price revision date: Jan, 2017)

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (inch)	Set Contents (piece)	SPQ (set)	Weight (g/set)
445-6149	TRRI-9S	¥1,782	¥1,925	5/64, 3/32, 1/8, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8	9	6	351
445-6025	TRRI-13S	¥2,074	¥2,240	0.050, 1/16, 5/64, 3/32, 7/64, 1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8	13	6	390



Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 394 Items

Hexpro Pivot Head Hexagonal Wrench (inch size)

- Features**
- The angle can be used at an angle of up to 180 degrees without fixing it to 90 degrees, so it will show its power in the presence of obstacles.
 - The surface treatment uses a special matte chrome finish to prevent corrosion.
 - Cloth pouch that contains the set can be folded with the wrench inside.
- Materials**
- Chrome Vanadium Steel
- Origin**
- Taiwan

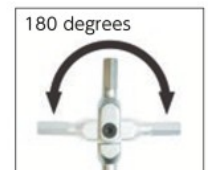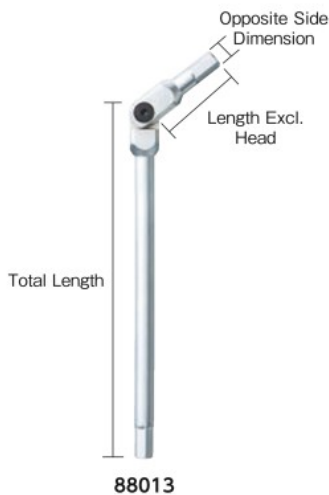

BONDHUS JAPAN

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Opposite Side Dimension (inch)	Length Excl. Head (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
495-7997	88007	¥1,609	-	1/8	23	96	10	14
495-8004	88008	¥1,609	-	9/64	23	96	10	14
495-8012	88009	¥1,717	-	5/32	23	106	10	19
495-8021	88010	¥1,717	-	3/16	25	116	10	36
495-8039	88011	¥1,825	-	7/32	25	128	10	61
495-8047	88012	¥1,932	-	1/4	30	138	10	67
495-8055	88013	¥2,040	-	5/16	33	162	10	119
495-8063	88014	¥2,146	-	3/8	30	177	10	208

Set

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Set Contents (inch)	Set Contents (piece)	SPQ (set)	Weight (g/set)
495-8233	HP5-IC-09	¥7,514	-	3/16, 7/32, 1/4, 5/16, 3/8	5	10	454
495-8250	HP8-IC-17	¥9,446	-	1/8, 9/64, 5/32, 3/16, 7/32, 1/4, 5/16, 3/8	8	10	503

Contact us:03-3639-2347 <http://www.bondhus-japan.co.jp/>



HP8-IC-17 (set)