

Hexagonal Wrenches(knife type)

Stock 991 Items

4-789

Prices displayed include 8% tax.



Stock 38,650 Items

Hexagonal Wrench Set



- Features
- You can draw out only necessary size like a pocket knife.
 - The holder also acts as a grip.
 - The hardness is HRC52 to 56.
- Origin
- Japan



GN6-310

Compact when folded.



GN7-156

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Set Contents (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|-------------------------|-------------|------------|
| 125-2119 | GN6-310 | ¥1,842 | ¥1,990 | 3, 4, 5, 6, 8, 10 | 10 | 400 |
| 125-2127 | GN7-156 | ¥1,583 | ¥1,710 | 1.5, 2, 2.5, 3, 4, 5, 6 | 10 | 145 |
| 125-2135 | GN6-258 | ¥1,722 | ¥1,860 | 2.5, 3, 4, 5, 6, 8 | 10 | 245 |

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Hexagonal Wrench Set



TN75

- Features
- Hex key and grip can be fixed at 90°, making work easier.
 - You can draw out only necessary size like a pocket knife.
 - Since it is a folding type, it is convenient for carrying.
 - The hardness is HRC50 to 58.
- Origin
- Taiwan

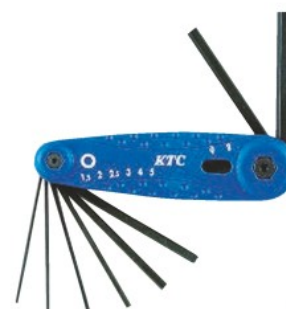

HLH8

- Features
- It can be used for eight sizes from 1.5 to 8mm
 - A light and easy to grip resin body.
 - France
- Origin



Warning
•Apply force in the rotating direction of the bolt. If forced is applied in the tilting direction of the shaft, the tip may be damaged.

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Set Contents (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|-------------------------|-------------|------------|
| 366-8991 | TN75 | ¥1,009 | ¥1,090 | 1.5, 2, 2.5, 3, 4, 5, 6 | 12 | 128 |

Contact us:0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece

KYOTO TOOL Co.Ltd.

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Set Contents (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|----------------------------|-------------|------------|
| 373-5478 | HLH8 | ¥3,509 | ¥3,790 | 1.5, 2, 2.5, 3, 4, 5, 6, 8 | 5 | 220 |

URL <http://ktc.jp/>



Stock 252 Items

Knife Type Hexagonal Wrench



- Features
- The newly adopted resin cover has a nice texture and is easy to grip.
 - The main body frame uses hard steel plate, so it is stronger to twists compared to existing knife types and can tighten strongly.
 - A product for "pro" that is designed and manufactured to exceed the ISO/JIS standard.
- Materials
- Wrench: Special Alloy Steel, SNCM+V (black dye parkerizing)
 - Main body frame: Hard steel plate
 - Cover: PP (polypropylene)
- Origin
- Japan



009-1N

Order Unit: 1 Piece

EIGHT TOOL Co.Ltd.

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Set Contents (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|-------------------------|-------------|------------|
| 401-2062 | 009-1N | ¥1,173 | ¥1,520 | 1.5, 2, 2.5, 3, 4, 5, 6 | 10 | 146.5 |
| 401-2089 | 009-2N | ¥1,358 | ¥1,760 | 2.5, 3, 4, 5, 6, 8 | 10 | 251.0 |
| 401-2101 | 009-3N | ¥1,466 | ¥1,900 | 3, 4, 5, 6, 8, 10 | 10 | 332.0 |

Contact us:06-6793-9025 <http://www.eight-tool.co.jp/>

Screwdrivers-Hexagonal Wrenches

Grip Screwdrivers

Screwdrivers with Plastic Handle

Stubby Screwdrivers

Screwdrivers with Wood Handle

Precision Screwdrivers

Electric Detection Screwdrivers

Interchangeable Screwdrivers

Ratchet Screwdrivers

Offset Ratchet Screwdrivers

Socket Screwdrivers

Impact Drivers (Manual Type)

Hexagon Driver

Hex Lobe Screwdrivers

Special-Purpose Screwdrivers

Ball-Point Hexagonal Wrenches

Hexagonal Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches

Hex Lobe Wrenches