

Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Nylon Shaft Wheel (shaft diameter 6mm)



UFN425-120 (outer diameter 40mm)



UFN425-240 (outer diameter 40mm)





UFN425-320 (outer diameter 40mm)



UFN425-600 (outer diameter 40mm)

- Features**
- Dual purpose for stainless steel, general metal.
 - Nylon textile acts as a cushion and prevents polishing material from being scraped too much.
 - The nylon fiber non-woven fabric is adhered with a special resin adhesive, and it is excellent in chemical resistance, water resistance, elasticity, etc.
 - New surface always appears due to autogenous action, so clogging is unlikely to occur, and the surface roughness of the finished surface is constant from the beginning to the end of polishing.
 - Lasts the shape for a long time. The edges will not crumble.
- Use**
- Paint removal, polishing before plating. Optimum for polishing stainless steel, iron, alloy, wood, plastic, etc.
 - Working Tool: Straight-type grinder.
 - Max Working Rotation Speed: 3000rpm
 - Japan
- Specs Origin**

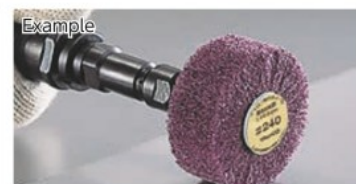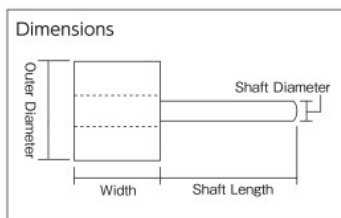

Polishing objective will be the polishing grain.

Outer Diameter 30mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 30 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥875

Outer Diameter 40mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 40 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥875

Order Unit: 1 Box (Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
768-3057	UFN325-120	¥4,374	¥5,400	120	23	5	20	145
768-3065	UFN325-180	¥4,374	¥5,400	180	22	5	20	152
768-3073	UFN325-240	¥4,374	¥5,400	240	22	5	20	137
768-3081	UFN325-320	¥4,374	¥5,400	320	23	5	20	137
768-3090	UFN325-400	¥4,374	¥5,400	400	23	5	20	135
768-3103	UFN325-600	¥4,374	¥5,400	600	24	5	20	135
768-3049	UFN325-1000	¥4,374	¥5,400	1000	24	5	20	135

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
173-0347	UFN425-120	¥4,374	¥5,400	120	23	5	20	217
768-3120	UFN425-180	¥4,374	¥5,400	180	22	5	20	208
173-0355	UFN425-240	¥4,374	¥5,400	240	22	5	20	190
173-0363	UFN425-320	¥4,374	¥5,400	320	23	5	20	190
768-3138	UFN425-400	¥4,374	¥5,400	400	23	5	20	183
173-0371	UFN425-600	¥4,374	¥5,400	600	24	5	20	182
768-3111	UFN425-1000	¥4,374	¥5,400	1000	24	5	20	180

Outer Diameter 50mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 50 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥875

Outer Diameter 60mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 60 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥978

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
173-0398	UFN525-120	¥4,374	¥5,400	120	36	5	20	304
768-3154	UFN525-180	¥4,374	¥5,400	180	30	5	20	266
173-0401	UFN525-240	¥4,374	¥5,400	240	31	5	20	251
173-0410	UFN525-320	¥4,374	¥5,400	320	33	5	20	257
768-3162	UFN525-400	¥4,374	¥5,400	400	33	5	20	238
173-0428	UFN525-600	¥4,374	¥5,400	600	40	5	20	250
768-3146	UFN525-1000	¥4,374	¥5,400	1000	40	5	20	236

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
173-0444	UFN625-120	¥4,892	¥6,040	120	36	5	10	346
768-3189	UFN625-180	¥4,892	¥6,040	180	30	5	10	300
173-0452	UFN625-240	¥4,892	¥6,040	240	31	5	10	270
173-0461	UFN625-320	¥4,892	¥6,040	320	33	5	10	277
768-3197	UFN625-400	¥4,892	¥6,040	400	33	5	10	256
173-0479	UFN625-600	¥4,892	¥6,040	600	40	5	10	260
768-3171	UFN625-1000	¥4,892	¥6,040	1000	40	5	10	252

Outer Diameter 80mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 80 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥1,133

Outer Diameter 100mm

Specs •Outer Diameter x W x Shaft Diameter x Shaft Length: 100 x 25 x 6 x 40mm

Estimated Unit Price per Piece ¥1,474

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
114-8290	UFN825-120	¥5,662	¥6,990	120	44	5	10	531
768-3219	UFN825-180	¥5,662	¥6,990	180	46	5	10	503
114-8303	UFN825-240	¥5,662	¥6,990	240	46	5	10	440
114-8311	UFN825-320	¥5,662	¥6,990	320	50	5	10	455
768-3227	UFN825-400	¥5,662	¥6,990	400	50	5	10	436
114-8320	UFN825-600	¥5,662	¥6,990	600	55	5	10	415
768-3201	UFN825-1000	¥5,662	¥6,990	1000	55	5	10	426

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Grain Size (#)	Layers of Non-Woven Fabric (sheet)	Q'ty Per Box (piece)	SPQ (box)	Weight (g/box)
114-8338	UFN1025-120	¥7,371	¥9,100	120	52	5	10	744
768-3022	UFN1025-180	¥7,371	¥9,100	180	46	5	10	630
114-8346	UFN1025-240	¥7,371	¥9,100	240	46	5	10	565
114-8494	UFN1025-320	¥7,371	¥9,100	320	50	5	10	575
768-3031	UFN1025-400	¥7,371	¥9,100	400	50	5	10	563
114-8508	UFN1025-600	¥7,371	¥9,100	600	55	5	10	516
768-3014	UFN1025-1000	¥7,371	¥9,100	1000	55	5	10	513

Contact us: 0120-509-849 <http://www.orange-book.com/>

Abrasives

Grinding Wheels

Disk Papers

Papers for Double Action Sander

Nylon Discs

Urethane Discs

Felt Discs

Diamond Wheels

Grinding Wheels

Dressers

Flap Wheels

Nylon Wheel with Shaft

Shank Mounted Felt Wheels with Shaft

Bands

Shank Mounted Stones

Carbide Bars

Diamond Bars

CBN Bars

Files

Diamond Files

Grinding Stones

Abrasives

Sheet Sanding Papers

Abrasive Belts

Cup Brushes

Wheel Brushes with Shank

Hand Brushes