 


Prices displayed include 8% tax.





Stock
38,650
Items

FB Super Fine Belt



#220 #320 #600 #1000
TFB-1009155

- Features**
- There is thickness by crimping nylon non-woven fabric on cloth base material.
 - Improved familiarity more than the usual nylon belts, less vibration during polish processing, further improve usability.
 - Suitable for curved surface and uneven surface.
 - Hairline processing of stainless steel and aluminum products.
 - Cleaning of adhered substances.
 - Rust removal, peel off paint film.
- Use**
- Abrasive material: #60 to #220 (silicone carbide abrasive grain (C)), #320 to #1000 (aluminum abrasive grain (A))
 - Nylon non woven fabric
- Origin**
- Japan

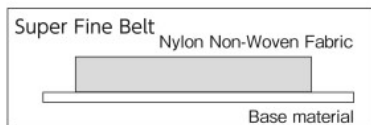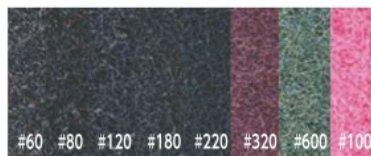

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Grain Size (#)	Color	W x L (mm)	SPQ (piece)	Weight (g)
299-6812	TFB-1009155-60	¥2,633	¥3,250	60	Black	100 x 915	1	300
299-6821	TFB-1009155-80	¥2,633	¥3,250	80	Black	100 x 915	1	300
299-6839	TFB-1009155-120	¥2,633	¥3,250	120	Black	100 x 915	1	300
299-6847	TFB-1009155-180	¥2,633	¥3,250	180	Black	100 x 915	1	300
299-6855	TFB-1009155-220	¥2,633	¥3,250	220	Black	100 x 915	1	300
299-6863	TFB-1009155-320	¥2,633	¥3,250	320	Purple	100 x 915	1	300
299-6871	TFB-1009155-600	¥2,633	¥3,250	600	Green	100 x 915	1	300
299-6880	TFB-1009155-1000	¥2,633	¥3,250	1000	Pink	100 x 915	1	300

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock
226
Items

Abrasive Resin Cloth Belt



- Features**
- An abrasive resin cloth belt that lightly polishes metal and resin, etc. by being attached to a compact electric belt sander or air tool.
- Use**
- Burring, bead removal, rust removal and scratch removal, etc.
- Origin**
- Japan



10 x 330mm

Materials

- Abrasive: #40/#60 to #120 (zirconia Z), #50/#150 to #1000 (aluminum A)

Order Unit: 50 Pieces

BELLSTAR ABRASIVE MFG.Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Grain Size (#)	W x L (mm)	Weight (g)
124-4477	BP10-40	¥108*	¥160*	50	40	10 x 330	5.6
124-4507	BP10-50	¥106*	¥156*	50	50	10 x 330	4.0
124-4531	BP10-60	¥102*	¥150*	50	60	10 x 330	4.0
124-4566	BP10-80	¥97*	¥144*	50	80	10 x 330	3.6
124-4591	BP10-100	¥95*	¥140*	50	100	10 x 330	3.4
124-4621	BP10-120	¥95*	¥140*	50	120	10 x 330	3.0
124-4655	BP10-150	¥95*	¥140*	50	150	10 x 330	2.8
124-4680	BP10-180	¥95*	¥140*	50	180	10 x 330	2.6
124-4710	BP10-240	¥95*	¥140*	50	240	10 x 330	2.4
124-4744	BP10-320	¥95*	¥140*	50	320	10 x 330	2.2
124-4779	BP10-400	¥95*	¥140*	50	400	10 x 330	2.0
124-4809	BP10-600	¥95*	¥140*	50	600	10 x 330	1.8
330-7492	BP10-800	¥95*	¥140*	50	800	10 x 330	1.8
330-7484	BP10-1000	¥95*	¥140*	50	1000	10 x 330	1.8

BP10
(10 x 330mm)



BP20
(20 x 520mm)

BP30
(30 x 540mm)

20 x 520mm

Materials

- Abrasives: #30, #50, #150 to #1000 (aluminum A), #36, #40, #60 to #120 (zirconia Z)

Order by package Q'ty

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Grain Size (#)	W x L (mm)	Weight (g)
124-4434	BP20-30	¥125*	¥186*	10	30	20 x 520	17.4
124-4451	BP20-36	¥120*	¥178*	10	36	20 x 520	16.4
124-4485	BP20-40	¥108*	¥160*	20	40	20 x 520	16.4
124-4515	BP20-50	¥106*	¥156*	20	50	20 x 520	15.0
124-4540	BP20-60	¥102*	¥150*	20	60	20 x 520	15.0
124-4574	BP20-80	¥97*	¥144*	20	80	20 x 520	13.5
124-4604	BP20-100	¥95*	¥140*	20	100	20 x 520	12.1
124-4639	BP20-120	¥95*	¥140*	20	120	20 x 520	11.5
124-4663	BP20-150	¥95*	¥140*	20	150	20 x 520	8.5
124-4698	BP20-180	¥95*	¥140*	20	180	20 x 520	8.5
124-4728	BP20-240	¥95*	¥140*	20	240	20 x 520	8.0
124-4752	BP20-320	¥95*	¥140*	20	320	20 x 520	7.9
124-4787	BP20-400	¥95*	¥140*	20	400	20 x 520	7.7
124-4817	BP20-600	¥95*	¥140*	20	600	20 x 520	6.2
330-7514	BP20-800	¥95*	¥140*	20	800	20 x 520	6.2
330-7506	BP20-1000	¥95*	¥140*	20	1000	20 x 520	6.2

30 x 540mm

Materials

- Abrasives: #30, #50, #150 to #1000 (aluminum A), #36, #40, #60 to #120 (zirconia Z)

Order by package Q'ty

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Q'ty Per Pack (piece)	Grain Size (#)	W x L (mm)	Weight (g)
124-4442	BP30-30	¥189*	¥280*	10	30	30 x 540	26.0
124-4469	BP30-36	¥181*	¥268*	10	36	30 x 540	23.8
124-4493	BP30-40	¥174*	¥258*	20	40	30 x 540	23.8
124-4523	BP30-50	¥163*	¥242*	20	50	30 x 540	23.0
124-4558	BP30-60	¥162*	¥240*	20	60	30 x 540	23.0
124-4582	BP30-80	¥154*	¥228*	20	80	30 x 540	21.0
124-4612	BP30-100	¥146*	¥216*	20	100	30 x 540	17.2
124-4647	BP30-120	¥146*	¥216*	20	120	30 x 540	14.3
124-4671	BP30-150	¥146*	¥216*	20	150	30 x 540	13.0
124-4701	BP30-180	¥146*	¥216*	20	180	30 x 540	13.0
124-4736	BP30-240	¥146*	¥216*	20	240	30 x 540	12.0
124-4761	BP30-320	¥146*	¥216*	20	320	30 x 540	11.2
124-4795	BP30-400	¥146*	¥216*	20	400	30 x 540	11.0
124-4825	BP30-600	¥146*	¥216*	20	600	30 x 540	9.8
330-7531	BP30-800	¥146*	¥216*	20	800	30 x 540	9.8
330-7522	BP30-1000	¥146*	¥216*	20	1000	30 x 540	9.8

Contact us: 0745-77-7115 <http://www.eonet.ne.jp/~bellstar/>

Please order items marked with * by no. of items in packet.