

Prices displayed include 8% tax.



Long-selling super standard spatter sheet  
"Deluxe"

Widely used at construction sites such as buildings, railways, stadiums and towers.

- "Flame resistant fiber" and "silicone resin double-sided processing" that have earned trust from our users are applied.
- Sheets without eyelets have no eyelet attached, so they are useful for preventing damage on parts at automobile sheet metal plants, repair shops, etc.

We can respond to your requests for sizes and shapes as custom orders. Feel free to contact us.

Stock inquiry




Stock 38,650 Items

Spatter Sheet "Deluxe" (double coated)



- Features**
- Flameproof gray fiber fabrics are coated with special silicone on both sides.
  - Type to repel received sparks and slag.
  - Hazardous fiber such as asbestos and RCF (refractory ceramic fiber) and glass fibers with skin irritation are not contained.
- Specs**
- JIS A 1323 Class A passing No. 08A3823
  - (foundation) Japan Fire Retardant Association Flame Retardant Performance Test compliant No. C2120018
  - Thickness: Approx. 1mm
- Materials**
- Flame Resistant Fiber Fabrics
  - Silicone Double-sided Processing
- Origin**
- Japan

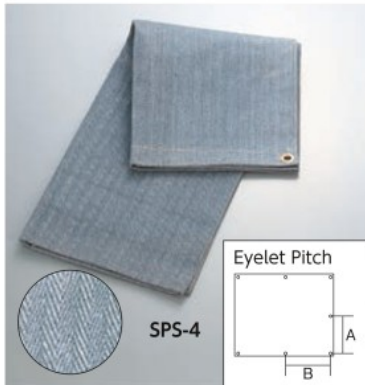

## Mini Size Type Use

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
					A	B			
786-8871	SPS-M61	¥4,166	¥4,500	None	-	-	610 x 610	30	0.3

## With eyelet type

Order Unit: 1 Sheet | Blue | Factory direct | Shipping not included

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
121-0122	SPS-1	¥ 6,387	¥ 6,900	No. 1	4	880	880	920 x 920	15	0.73
121-0131	SPS-2	¥ 12,775	¥ 13,800	No. 2	12	440	470	920 x 1920	8	1.46
121-0149	SPS-4	¥ 25,550	¥ 27,600	No. 4	16	470	470	1920 x 1920	4	2.92
121-0157	SPS-6	¥ 38,325	¥ 41,400	No. 6	20	470	480	1920 x 2920	3	4.38
824-6025	SPS-RDX	¥143,486	¥155,000	Roll	-	-	-	1000 x 30m	1	21.50
★837-1265	SPS-R-DXW	¥286,971	¥310,000	Roll	-	-	-	2000 x 30m	1	43.00

## No Eyelet Type Use

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
797-3608	SPS-1HN	¥ 5,739	¥ 6,200	No. 1	None	-	-	920 x 920	20	0.71
797-3616	SPS-2HN	¥11,479	¥12,400	No. 2	None	-	-	920 x 1920	10	1.42
797-3624	SPS-4HN	¥22,958	¥24,800	No. 4	None	-	-	1920 x 1920	5	2.84

## Sell by Piece Type

Features ● You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included


Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★455-1338	SPS-R-CUT	¥ 5,425	¥ 5,860	Cut	-	-	-	1000 x In meter unit	0.73
★402-7051	SPS-R-CUT-W	¥10,850	¥11,720	Cut	-	-	-	2000 x In meter unit	1.46

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 11 Items

Spatter Sheet CARMARON® Fabric Type (double coated)

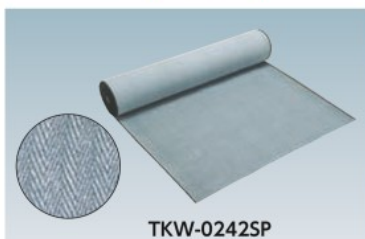

TKW-0242SP

- Features**
- Flameproof gray fiber fabrics are coated with special silicone on both sides.
  - Type to repel received sparks and slag.
  - It does not contain hazardous fibers like asbestos or glass fibers with skin irritation.
  - As a welding spark receiving sheet, fire proof cover, curing sheet, and duct cover.
- Use**
- Thickness: Approx. 1.0mm
  - Instantaneous heat resistant temperature: 1300° C
  - Continuous working temperature: 250° C
  - (foundation) Japan Fire Retardant Association Flame Retardant Performance Test No. C2170008
- Materials**
- Flame Resistant Fiber (Pyromex®)
  - Silicone Double-sided Processing
- Origin**
- Japan

Order Unit: 1 Roll

TEIKEN LIMITED.

Order Code	Item No.	Price (per roll)	MSRP (per roll)	Type	W x L (mm)	SPQ (roll)	Weight (kg)
858-5950	TKW-0242SP	¥145,800	¥157,500	Roll	1000 x 30m	1	21.5



- Warning**
- Not compliant with JIS A 1323 Class A.
  - Do not use for fusion cutting.