

TRUSCO



TRUSCO

Stock
38,650
Items

Spatter Sheet "Basic Double-sided" (double coated)

Made to
OrderHeavy
Caution

Repel

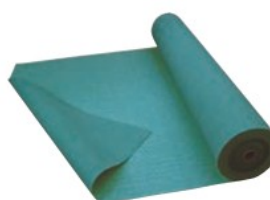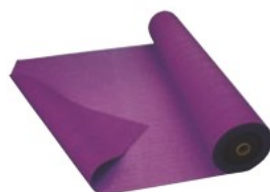Com
DrawingTSP-2BW
(gray)TSP-RBW
(roll/gray)TSP-2BWG
(green)TSP-RBWG
(roll/green)TSP-2BWP
(pink)TSP-RBWP
(roll/pink)

Features

- Excellent cost performance, highly versatile type.
- With 3 color variations, color coding is possible according to possession classification, work content, etc.
- Flame resistant fiber fabrics are coated with special silicone on both sides.
- Non-asbestos/non-ceramic safe product, also containing no fibers that induce skin irritation.
- A type to repel sparks, slag.

Use


 
- As a welding spark receiving sheet, fire proof curtain, and curing sheet.

Specs

- JIS A 1323 Class A Passing No. 03A0188
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test compliant No. CO050010

Origin

- Thickness: Approx. 1mm
- Japan

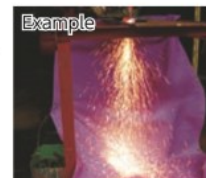

Gray Materials •Flame Resistant Fiber Fabrics •Silicone (white) Double-sided Processing

Order Unit: 1 Sheet | Blue Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
284-7167	TSP-1BW	¥ 6,110	¥ 6,600	No. 1	4	880	880	920 x 920	20	0.715
284-7175	TSP-2BW	¥ 12,034	¥ 13,000	No. 2	12	440	470	920 x 1920	10	1.430
284-7183	TSP-4BW	¥ 22,773	¥ 24,600	No. 4	16	470	470	1920 x 1920	5	2.860
284-7191	TSP-6BW	¥ 34,437	¥ 37,200	No. 6	20	470	480	1920 x 2920	5	4.290
284-7205	TSP-RBW	¥ 134,229	¥ 145,000	Roll	-	-	-	1000 x 30m	1	21.450
★855-8135	TSP-RBW-W	¥ 268,457	¥ 290,000	Roll	-	-	-	2000 x 30m	1	42.900

Sell by Piece Type Features •You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included |

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★284-7213	TSP-RBW-CUT	¥ 5,230	¥ 5,650	Cut	-	-	-	1000 x In meter unit	0.715
★467-4022	TSP-RBW-CUT-W	¥ 10,461	¥ 11,300	Cut	-	-	-	2000 x In meter unit	1.430

Green Materials •Flame Resistant Fiber Fabrics •Silicone (green) double-sided processing

Order Unit: 1 Sheet | Blue Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
856-3605	TSP-1BWG	¥ 6,110	¥ 6,600	No. 1	4	880	880	920 x 920	20	0.715
856-3607	TSP-2BWG	¥ 12,034	¥ 13,000	No. 2	12	440	470	920 x 1920	10	1.430
856-3609	TSP-4BWG	¥ 22,773	¥ 24,600	No. 4	16	470	470	1920 x 1920	5	2.860
856-3611	TSP-6BWG	¥ 34,437	¥ 37,200	No. 6	20	470	480	1920 x 2920	5	4.290
856-3613	TSP-RBWG	¥ 134,229	¥ 145,000	Roll	-	-	-	1000 x 30m	1	21.450
★856-3616	TSP-RBWG-W	¥ 268,457	¥ 290,000	Roll	-	-	-	2000 x 30m	1	42.900

Sell by Piece Type Features •You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included |

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★856-3614	TSP-RBWG-CUT	¥ 5,230	¥ 5,650	Cut	-	-	-	1000 x In meter unit	0.715
★856-3615	TSP-RBWG-CUT-W	¥ 10,461	¥ 11,300	Cut	-	-	-	2000 x In meter unit	1.430

Pink Materials •Flame Resistant Fiber Fabrics •Silicone (pink) double-sided processing

Order Unit: 1 Sheet | Blue Factory direct | No freight charge | Excluding remote islands |

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
856-3606	TSP-1BWP	¥ 6,110	¥ 6,600	No. 1	4	880	880	920 x 920	20	0.715
856-3608	TSP-2BWP	¥ 12,034	¥ 13,000	No. 2	12	440	470	920 x 1920	10	1.430
856-3610	TSP-4BWP	¥ 22,773	¥ 24,600	No. 4	16	470	470	1920 x 1920	5	2.860
856-3612	TSP-6BWP	¥ 34,437	¥ 37,200	No. 6	20	470	480	1920 x 2920	5	4.290
856-3617	TSP-RBWP	¥ 134,229	¥ 145,000	Roll	-	-	-	1000 x 30m	1	21.450
★856-3620	TSP-RBWP-W	¥ 268,457	¥ 290,000	Roll	-	-	-	2000 x 30m	1	42.900

Sell by Piece Type Features •You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included |

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★856-3618	TSP-RBWP-CUT	¥ 5,230	¥ 5,650	Cut	-	-	-	1000 x In meter unit	0.715
★856-3619	TSP-RBWP-CUT-W	¥ 10,461	¥ 11,300	Cut	-	-	-	2000 x In meter unit	1.430

Contact us: 0120-509-849 <http://www.orange-book.com/>