

Shielding Sunlight Sheets

The number next to the logo mark indicates items in stock for each brand.

Welding Machines

Engine Welders

Spot Welders

Plasma Cutting Machines

Welding Tables

Welding Rods

Accessories for Welding Equipment

Welding Scale Removers

Gas Torches

Gas Burners

Gas Cutting Equipments

Gas Regulators

Brazing Filler Metals

Welding Masks

Protective Eyewears for Welding

Protective Tools for Welding

Spatter Sheets

Protective Fences for Welding

Industrial Markers

TRUSCO **Stock 38,650 Items**

Heat Insulating Sheet "Super Platinum"



- Features**
- Excellent thermal reflectivity and heat resistance, and reflects radiant heat.
 - It is a composite product laminated with film with aluminum vapor deposited layer on both sides of polyester film of 6 micron and flame resistant saturated fabric (high density).
 - Non-asbestos/non-ceramic safe product, also containing no fibers that induce skin irritation.
- Use**
- As a heat shielding sheet.
- Specs**
- (foundation) Japan Fire Retardant Association Flame Retardant Performance Test No. CO040011
 - Thickness: Approx. 1.3mm
- Materials**
- Flame Resistant Fiber Fabrics (spatter sheet "platinum")
 - Aluminum-metallized Film
- Origin**
- Japan



Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	SPQ (sheet)	Weight (kg)
						A	B			
276-5691	TSS-SP1	¥10,646	¥11,500	No. 1	4	860	880	900 x 920	20	0.66
276-5705	TSS-SP2	¥21,291	¥23,000	No. 2	12	430	470	900 x 1920	10	1.32
276-5713	TSS-SP4	¥42,583	¥46,000	No. 4	16	450	470	1840 x 1920	5	2.64
276-5721	TSS-SP6	¥63,874	¥69,000	No. 6	20	450	480	1840 x 2920	5	3.96
276-5730	TSS-SPR	¥45,360	¥49,000	Roll	-	-	-	980 x 5m	1	3.30


TRUSCO NAKAYAMA CORPORATION

Sell by Piece Type | Features • You can order with your preferred length (m unit).

Order Unit: 1m | Factory direct | Shipping not included

Order Code	Item No.	Price (per m)	MSRP (per m)	Type	Number of Eyelets	Eyelet Pitch (mm)		W x L (mm)	Weight (kg/m)
						A	B		
★467-4103	TSS-SPR-CUT	¥9,627	¥10,400	Cut	-	-	-	980 x In meter unit	0.66

Contact us: 0120-509-849 <http://www.orange-book.com/>

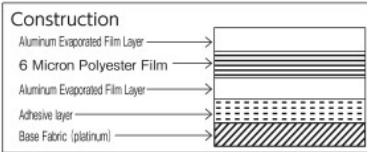

Repair and Maintenance

"NAOJIRO" <8 Services>

Repairing



We repair equipment such as electric tools, pneumatic tools, and hydraulic equipment. We also repair other products that are not listed in the Orange Book.

Regrinding



We regrind and recoat cutting tools.

Calibration



We inspect and calibrate measuring tools and equipment, and conduct periodic inspections of insulated products.

Reuse



We reuse various components such as recycling rechargeable batteries, plating restoration, and cleaning anti-dust respirator filter.

Processing



We provide a range of services, from assembling chain slings to tape processing, re-electroplating, and duplicating keys.

Assembling



We assemble various furniture for factories and offices such as shelves, workbenches, tool wagons, and storage sheds.

Construction/Setting



We install garages, partitions, LED lighting, etc.

Maintenance



We conduct maintenance and inspection on compressors, commercial air conditioners and other equipment. We also offer a variety of cleaning services.

"NAOJIRO" Services are only available for customers in Japan