


Spatter Felts

The number next to the logo mark indicates items in stock for each brand.



Stock 38,650 Items

"Spatter Felt 28CF"

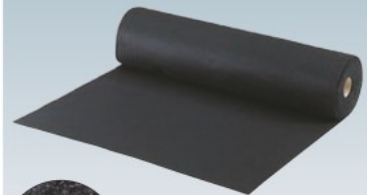

28CF Type

- Features**
- Spatter felt fabric is lightweight textile products.
 - Since there is no texture, it is difficult for slag to enter, and the attached slag is easy to remove.
 - The cut surface does not get frayed.
 - Hot rolling process keeps uniform thickness.
 - Safe with no asbestos/RCF.
- Use**
- For slag receiving work. (Becomes more effective by sprinkling water)
- Specs**
- **JIS A 1323 Class A Passing No. 01A0768**
 - Thickness: 2.8mm
- Materials**
- 100% Flame Resistant Fiber
- Origin**
- Japan



Compared to non-woven fabric, tensile strength and tear strength are exceptionally strong.

(Price revision date: Jan, 2016)

Order Unit: 1 Sheet | **Blue** Factory direct | No freight charge | Excluding remote islands | TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	W x L (mm)	SPQ (sheet)	Weight (kg)
217-2658	28CF-11	¥ 3,647	¥ 3,940	Cut	1000 x 1000	20	0.36
217-2666	28CF-12	¥ 7,294	¥ 7,880	Cut	1000 x 2000	12	0.72
217-2674	28CF-15	¥ 18,227	¥ 19,690	Cut	1000 x 5000	4	1.80
415-2255	28CF-22	¥ 14,580	¥ 15,750	Cut	2000 x 2000	6	1.44
837-1268	28CF-23	¥ 21,847	¥ 23,600	Cut	2000 x 3000	5	2.16
415-2263	28CF-25	¥ 36,454	¥ 39,380	Cut	2000 x 5000	3	3.60
217-2682	28CF-120	¥ 60,264	¥ 65,100	Roll	1000 x 20m	1	7.20
★837-1267	28CF-220	¥ 120,528	¥ 130,200	Roll	2000 x 20m	1	14.40

Contact us:0120-509-849 <http://www.orange-book.com/>


Warning

- Can not be used to prevent spark scattering of the grindstone cutting equipment.



Stock 38,650 Items

"Spatter Felt 50CF"

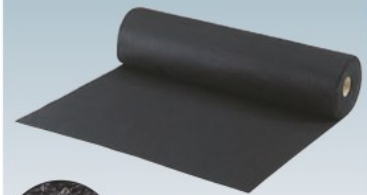

50CF Type

- Features**
- Spatter felt fabric is lightweight textile products.
 - Since there is no texture, it is difficult for slag to enter, and the attached slag is easy to remove.
 - The cut surface does not get frayed.
 - Safe with no asbestos/RCF.
- Use**
- For slag receiving work. (Becomes more effective by sprinkling water)
- Specs**
- **JIS A 1323 Class A Passing No. 01A1315**
 - Thickness: 5mm
- Materials**
- 100% Flame Resistant Fiber
- Origin**
- Japan



Compared to non-woven fabric, tensile strength and tear strength are exceptionally strong.

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Sheet

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	W x L (mm)	SPQ (sheet)	Weight (kg)
217-2739	50CF-11	¥ 6,943	¥ 7,500	Cut	1000 x 1000	12	0.68
217-2747	50CF-12	¥ 13,886	¥ 15,000	Cut	1000 x 2000	6	1.36
217-2755	50CF-15	¥ 34,696	¥ 37,480	Cut	1000 x 5000	2	3.40
415-2271	50CF-22	¥ 27,762	¥ 29,990	Cut	2000 x 2000	4	2.72
837-1269	50CF-23	¥ 41,565	¥ 44,900	Cut	2000 x 3000	2	4.08
415-2280	50CF-25	¥ 69,391	¥ 74,960	Cut	2000 x 5000	2	6.80
217-2763	50CF-120	¥ 58,598	¥ 63,300	Roll	1000 x 10m	1	6.80

Contact us:0120-509-849 <http://www.orange-book.com/>


Warning

- Can not be used to prevent spark scattering of the grindstone cutting equipment.




Stock 38,650 Items

"Spatter Felt 50EX"

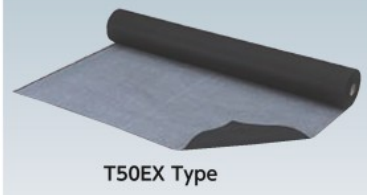

T50EX Type

 - Features**
- Coated with single-sided special flame retardant resin, spark repelling is good and the non-coated side on the back absorbs water and the safety aspect has improved.
 - Durability has been further improved.
- Specs**
- **JIS A 1323 Class A Passing No. 02A3662**
 - Thickness: 4.5mm
- Materials**
- Flame resistant fiber
 - Single-sided Special Flame Retardant Resin
- Origin**
- Japan



Warning

- Can not be used to prevent spark scattering of the grindstone cutting equipment.

Order Unit: 1 Sheet (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per sheet)	MSRP (per sheet)	Type	W x L (mm)	SPQ (sheet)	Weight (kg)
276-7139	T50EX-11	¥ 9,035	¥ 9,760	Cut	1000 x 1000	12	0.72
276-7147	T50EX-12	¥ 18,061	¥ 19,510	Cut	1000 x 2000	6	1.44
276-7155	T50EX-15	¥ 45,147	¥ 48,770	Cut	1000 x 5000	2	3.60
415-2298	T50EX-22	¥ 36,112	¥ 39,010	Cut	2000 x 2000	4	2.88
837-1270	T50EX-23	¥ 54,154	¥ 58,500	Cut	2000 x 3000	1	4.32
415-2301	T50EX-25	¥ 90,285	¥ 97,530	Cut	2000 x 5000	1	7.20
276-7163	T50EX-110	¥ 82,166	¥ 88,760	Roll	1000 x 10m	1	7.20

Contact us:0120-509-849 <http://www.orange-book.com/>