


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items

Threaded Type Coupling Elbow (outside x outside screw)



- Features**
- Those with male threads are subjected to sealing of all male screw thread parts.
- Use**
- For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: 0 to 100°C
 - Working Pressure: 14MPa
- Materials**
- Brass (C3771)
- Origin**
- Japan

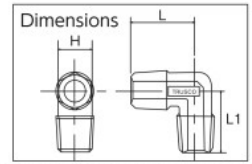

Order Unit: 1 Piece


(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6520	TN-01L	¥370	¥400	R1/8 x R1/8	10	18.5	18.5	10	20
257-6538	TN-02L	¥444	¥480	R1/4 x R1/4	12	22.0	22.0	10	25
257-6546	TN-03L	¥555	¥600	R3/8 x R3/8	14	26.0	26.0	5	45
257-6554	TN-04L	¥907	¥980	R1/2 x R1/2	18	32.5	32.5	5	90


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Threaded Coupling Elbow (outside x inside screw thread)

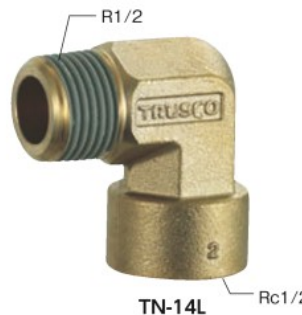

- Features**
- Those with male threads are subjected to sealing of all male screw thread parts.
- Use**
- For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: 0 to 100°C
 - Working Pressure: 14MPa
- Materials**
- Brass (C3771)
- Origin**
- Japan

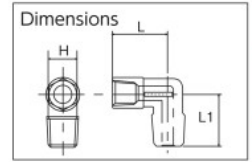

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6635	TN-11L	¥399	¥430	R1/8 x Rc1/8	12	21.0	21.0	10	30
257-6643	TN-12L	¥509	¥550	R1/4 x Rc1/4	14	25.0	25.0	10	45
257-6651	TN-13L	¥870	¥940	R3/8 x Rc3/8	18	30.5	30.5	5	100
257-6660	TN-14L	¥1,194	¥1,290	R1/2 x Rc1/2	22	33.0	33.0	5	145


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Threaded Type Coupling Elbow (inside x inside screw)



- Features**
- It is for holding external screw of threaded couplings.
- Use**
- For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: 0 to 100°C
 - Working Pressure: 14MPa
- Materials**
- Brass (C3771)
- Origin**
- Japan

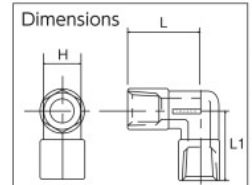

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6678	TN-21L	¥370	¥400	Rc1/8 x Rc1/8	12	21	21	10	30
257-6686	TN-22L	¥482	¥520	Rc1/4 x Rc1/4	14	25	25	10	50
257-6694	TN-23L	¥842	¥910	Rc3/8 x Rc3/8	18	30	30	5	110
257-6708	TN-24L	¥1,157	¥1,250	Rc1/2 x Rc1/2	22	33	33	5	160


Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Threaded Coupling Elbow (outside x inside screw thread/different diameter)



- Features**
- Those with male threads are subjected to sealing of all male screw thread parts.
- Use**
- For pipe and parts for pipe and fluid equipment such as tightness resistance connection.
- Specs**
- Working Fluid: Water, Air, Oil
 - Fluid Temperature: 0 to 100°C
 - Working Pressure: 14MPa
- Materials**
- Brass (C3771)
- Origin**
- Japan

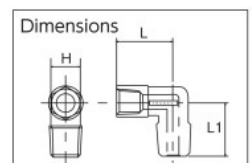

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nominal Diameter	Dimension (mm)			SPQ (piece)	Weight (g)
					H	L	L1		
257-6716	TN-0211L	¥389	¥420	R1/4 x Rc1/8	12	21	22	10	30
257-6724	TN-0322L	¥528	¥570	R3/8 x Rc1/4	14	25	26	10	50

Contact us: 0120-509-849 <http://www.orange-book.com/>