

Valves

Screwed
Type
Pipe
FittingsHigh
Pressure
JointsWelding
Fittings

Flanges

Flexible
Metal
HosesPiping
Joints for
Minor
DiametersSanitary
Pipe
CouplingsPVC
PipesPVC
Pipe
JointsPVC
ValvesJoints for
Water
PipingProtect
Accessories
for
PlumbingSupport
Accessories
for
PlumbingMaintenance
Accessories
for
PlumbingAir
Conditioning
MaterialsValve·Pipe
Identifying
GoodsSpray
Nozzles
Stock
38,650
 Items


Turbo Battledore for Suspend Band




TPS-BT50L-S



TPS-BT50L

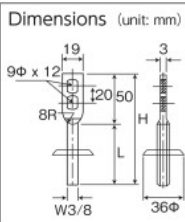

- Features •Flexible piping equipment are available by cutting during construction due to total screw thread machining.
 Use •Mounting foot bolt type for standing bands.
 Origin •China

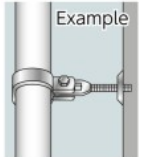

Example

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length H (mm)	Bolt Length L (mm)	Materials	SPQ (piece)	Weight (g)
285-9297	TPS-BT50L	¥139	¥150	100	50	Steel	10	47
285-9301	TPS-BT65L	¥148	¥160	115	65	Steel	10	53
285-9319	TPS-BT75L	¥158	¥170	125	75	Steel	10	56
285-9327	TPS-BT100L	¥176	¥190	150	100	Steel	10	67
285-9335	TPS-BT125L	¥176	¥190	175	125	Steel	10	77
285-9343	TPS-BT150L	¥194	¥210	200	150	Steel	10	89
285-9351	TPS-BT200L	¥213	¥230	250	200	Steel	10	110
285-9360	TPS-BT50L-S	¥306	¥330	100	50	Stainless Steel (SUS304)	10	46
285-9378	TPS-BT65L-S	¥342	¥370	115	65	Stainless Steel (SUS304)	10	53
285-9386	TPS-BT75L-S	¥379	¥410	125	75	Stainless Steel (SUS304)	10	56
285-9394	TPS-BT100L-S	¥426	¥460	150	100	Stainless Steel (SUS304)	10	67
285-9408	TPS-BT125L-S	¥454	¥490	175	125	Stainless Steel (SUS304)	10	77
285-9416	TPS-BT150L-S	¥518	¥560	200	150	Stainless Steel (SUS304)	10	88
285-9424	TPS-BT200L-S	¥583	¥630	250	200	Stainless Steel (SUS304)	10	109

Contact us:0120-509-849 <http://www.orange-book.com/>
Stock
38,650
 Items


Press T-Leg for Suspend Band




TPS-T100



TPS-T30

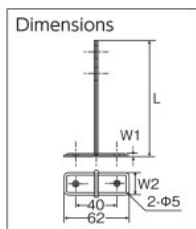

- Features •Used to fix the piping for the floor and the wall where the long object is made and the use is expanded. Can be used effectively by combining well with the hole angle.
 Use •Used for mounting vertical pipes.
 Materials •Steel (SPCC)
 Origin •Japan

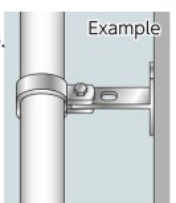

Example


Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Width W2 (mm)	Height L (mm)	Thickness W1 (mm)	Hole Number	SPQ (piece)	Weight (g)
282-0986	TPS-T30	¥83	¥90	25	30	3.2	1 Hole	10	26
282-0994	TPS-T50	¥111	¥120	25	50	3.2	2 Holes	10	37
282-1001	TPS-T65	¥120	¥130	25	65	3.2	2 Holes	10	46
282-1010	TPS-T75	¥130	¥140	25	75	3.2	2 Holes	10	51
282-1028	TPS-T100	¥148	¥160	25	100	3.2	2 Holes	10	67
282-1036	TPS-T125	¥176	¥190	25	125	3.2	2 Holes	10	80
282-1044	TPS-T150	¥213	¥230	25	150	3.2	2 Holes	10	99
282-1052	TPS-T200	¥269	¥290	25	200	3.2	2 Holes	10	122

Contact us:0120-509-849 <http://www.orange-book.com/>
Stock
216
 Items

Turbo Battledore for Suspend Band

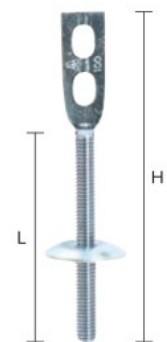

A10378 Type



A10395 Type

- Features •Threading type mounting feet with electro-galvanized finish for standing band.
 Use •Mounting feet for standing band.
 Origin •Japan

Order Unit: 1 Piece

AKAGI Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length H (mm)	Bolt Length L (mm)	Materials	SPQ (piece)	Weight (g)
442-0969	A10378-0018	¥210	—	90	45	Steel	400	43
442-0977	A10378-0022	¥233	—	105	60	Steel	400	49
442-0985	A10378-0037	¥241	—	115	70	Steel	350	52
442-0993	A10378-0041	¥288	—	140	95	Steel	300	63
442-1001	A10378-0056	¥302	—	165	120	Steel	250	73
442-1019	A10378-0075	¥321	—	190	145	Steel	200	83
442-1027	A10378-0080	¥463	—	240	195	Steel	180	103
442-1035	A10378-0094	¥771	—	290	245	Steel	130	124
442-1043	A10378-0107	¥1,159	—	340	295	Steel	100	143
442-1191	A10395-0019	¥1,245	—	90	45	Stainless Steel (SUS304)	400	42
442-1205	A10395-0023	¥1,335	—	105	60	Stainless Steel (SUS304)	400	48
442-1213	A10395-0038	¥1,468	—	115	70	Stainless Steel (SUS304)	350	52
442-1221	A10395-0042	¥1,691	—	140	95	Stainless Steel (SUS304)	300	63
442-1230	A10395-0057	¥1,955	—	165	120	Stainless Steel (SUS304)	250	74
442-1248	A10395-0061	¥2,135	—	190	145	Stainless Steel (SUS304)	200	84
442-1256	A10395-0076	¥2,445	—	240	195	Stainless Steel (SUS304)	180	104
442-1264	A10395-0095	¥2,647	—	290	245	Stainless Steel (SUS304)	130	124
442-1272	A10395-0108	¥2,916	—	340	295	Stainless Steel (SUS304)	100	146

URL <http://www.akagi-nt.co.jp/>