

Concrete Drills (SDS-plus shank)

For Hammer Drills, see p. 5-164 to 181

The number next to the logo mark indicates items in stock for each brand.




Stock 38,650 Items

Concrete Drill for Light Hammer Drill



Drills

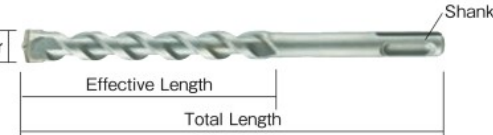

TCD-SDS Series

- Features**
- Candle shaped carbide tip and thinner blade edge sharply punch the work material and improved drilling speed.
 - The center point of cemented carbide tip provides outstanding positioning performance and drilling close to the perfect circle is possible.
 - The center point prevents core swing while punching and reduces vibration burden during work.
- Use**
- Work Material:** Concrete, Block, Mortar, Japanese Wall
- Specs**
- Shank: SDSplus
 - Compatible Model: Light Hammer Drill (SDSplus)
- Materials**
- Blade Part: Carbide Tip
- Origin**
- Vietnam
 - Japan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Diameter (mm)	Effective Length (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
391-1365	TCD-SDS-34	¥ 680	¥ 840	3.4	45	110	10	36
391-1373	TCD-SDS-34L	¥ 745	¥ 920	3.4	100	160	10	41
391-1381	TCD-SDS-35	¥ 680	¥ 840	3.5	45	110	10	36
391-1390	TCD-SDS-35L	¥ 745	¥ 920	3.5	100	160	10	41
391-1403	TCD-SDS-40	¥ 680	¥ 840	4.0	45	110	10	36
391-1411	TCD-SDS-43	¥ 680	¥ 840	4.3	45	110	10	36
391-1420	TCD-SDS-43L	¥ 745	¥ 920	4.3	100	160	10	42
391-1438	TCD-SDS-45	¥ 680	¥ 840	4.5	45	110	10	38
391-1446	TCD-SDS-45L	¥ 745	¥ 920	4.5	100	160	10	44
391-1454	TCD-SDS-48	¥ 680	¥ 840	4.8	45	110	10	40
391-1462	TCD-SDS-50	¥ 680	¥ 840	5.0	45	110	10	40
391-1471	TCD-SDS-50L	¥ 745	¥ 920	5.0	100	160	10	46
415-3375	TCD-SDS-53	¥ 680	¥ 840	5.3	45	110	10	40
391-1489	TCD-SDS-53L	¥ 745	¥ 920	5.3	100	160	10	46
391-1497	TCD-SDS-55	¥ 680	¥ 840	5.5	45	110	10	40
391-1501	TCD-SDS-55L	¥ 745	¥ 920	5.5	100	160	10	49
391-1519	TCD-SDS-60	¥ 680	¥ 840	6.0	45	110	10	42
391-1527	TCD-SDS-60L	¥ 745	¥ 920	6.0	100	160	10	50
415-3383	TCD-SDS-64	¥ 713	¥ 880	6.4	45	110	10	42
391-1535	TCD-SDS-64L	¥ 810	¥ 1,000	6.4	100	160	10	52
391-1543	TCD-SDS-65	¥ 810	¥ 1,000	6.5	100	160	10	54
391-1551	TCD-SDS-70	¥ 810	¥ 1,000	7.0	100	160	10	54
391-1560	TCD-SDS-75	¥ 810	¥ 1,000	7.5	100	160	10	56
391-1578	TCD-SDS-80	¥ 810	¥ 1,000	8.0	100	160	10	58
391-1586	TCD-SDS-85	¥ 835	¥ 1,030	8.5	100	160	10	62
768-4355	TCD-SDS-85L	¥ 1,175	¥ 1,450	8.5	150	210	1	82
415-3391	TCD-SDS-90	¥ 835	¥ 1,030	9.0	100	160	10	66
415-3405	TCD-SDS-95	¥ 900	¥ 1,110	9.5	100	160	10	66
391-1241	TCD-SDS-100	¥ 900	¥ 1,110	10.0	100	160	10	70
768-4223	TCD-SDS-100L	¥ 1,426	¥ 1,760	10.0	200	260	1	108
391-1250	TCD-SDS-105	¥ 900	¥ 1,110	10.5	100	160	10	74
768-4231	TCD-SDS-105L	¥ 1,483	¥ 1,830	10.5	200	260	1	114
415-3332	TCD-SDS-110	¥ 900	¥ 1,110	11.0	100	160	10	82
391-1268	TCD-SDS-120	¥ 988	¥ 1,220	12.0	100	160	10	84
768-4240	TCD-SDS-120L	¥ 1,612	¥ 1,990	12.0	200	260	1	136
391-1276	TCD-SDS-125	¥ 988	¥ 1,220	12.5	100	160	10	88
768-4258	TCD-SDS-125L	¥ 1,669	¥ 2,060	12.5	200	260	1	136
768-4274	TCD-SDS-125L-350	¥ 2,041	¥ 2,520	12.5	290	350	1	195
768-4266	TCD-SDS-125L-1000	¥ 5,249	¥ 6,480	12.5	200	1000	1	690
391-1284	TCD-SDS-127	¥ 988	¥ 1,220	12.7	100	160	10	88
768-4282	TCD-SDS-127L	¥ 1,669	¥ 2,060	12.7	200	260	1	148
768-4291	TCD-SDS-127L-450	¥ 2,471	¥ 3,050	12.7	390	450	1	240
415-3341	TCD-SDS-130	¥ 1,085	¥ 1,340	13.0	100	160	10	91
415-3359	TCD-SDS-140	¥ 1,207	¥ 1,490	14.0	100	160	10	100
391-1292	TCD-SDS-143	¥ 1,207	¥ 1,490	14.3	100	160	10	100
391-1306	TCD-SDS-145	¥ 1,207	¥ 1,490	14.5	100	160	10	100
768-4304	TCD-SDS-145L	¥ 1,976	¥ 2,440	14.5	200	260	1	168
415-3367	TCD-SDS-150	¥ 1,483	¥ 1,830	15.0	100	160	10	110
768-4312	TCD-SDS-150L	¥ 2,106	¥ 2,600	15.0	200	260	1	168
391-1314	TCD-SDS-160	¥ 1,580	¥ 1,950	16.0	100	160	6	114
391-1322	TCD-SDS-165	¥ 1,580	¥ 1,950	16.5	100	160	6	116
391-1331	TCD-SDS-170	¥ 1,733	¥ 2,140	17.0	100	160	6	132
391-1349	TCD-SDS-175	¥ 1,733	¥ 2,140	17.5	100	160	6	132
391-1357	TCD-SDS-180	¥ 1,920	¥ 2,370	18.0	100	160	6	133
768-4321	TCD-SDS-180L	¥ 2,657	¥ 3,280	18.0	200	260	1	238
768-4339	TCD-SDS-190L	¥ 3,029	¥ 3,740	19.0	200	260	1	278
768-4347	TCD-SDS-200L	¥ 3,216	¥ 3,970	20.0	200	260	1	278

Same size set

Order Unit: 1 Set


Order Code	Item No.	Price (per set)	MSRP (per set)	Cutting Diameter (mm)	Effective Length (mm)	Total Length (mm)	Qty Per Set (piece)	SPQ (set)	Weight (g/set)
415-3413	TCD-SDS-34-3P	¥ 1,791	¥ 2,210	3.4	45	110	3	5	102
415-3421	TCD-SDS-35-3P	¥ 1,791	¥ 2,210	3.5	45	110	3	5	102
415-3430	TCD-SDS-43-3P	¥ 1,791	¥ 2,210	4.3	45	110	3	5	106
415-3448	TCD-SDS-50-3P	¥ 1,791	¥ 2,210	5.0	45	110	3	5	109
415-3456	TCD-SDS-60-3P	¥ 1,791	¥ 2,210	6.0	45	110	3	5	118
415-3677	TCD-SDS-34L-3P	¥ 1,904	¥ 2,350	3.4	100	160	3	6	120
415-3685	TCD-SDS-35L-3P	¥ 1,904	¥ 2,350	3.5	100	160	3	6	120
415-3693	TCD-SDS-43L-3P	¥ 1,904	¥ 2,350	4.3	100	160	3	6	122

 Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Concrete Drill for Light Hammer Drill "SDS-plus UX"

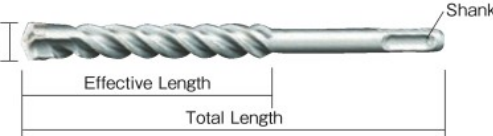

TCD-SDSUX Series

- Features**
- Can drill a hole close to a perfect circle for smooth anchor insertion.
 - The blade edge adopts a cross blade, so it is possible to drill through deck plates.
- Use**
- Work material:** Deck plate+concrete, block, brick, mortar, plaster board, marble.
- Specs**
- Shank: SDSplus
 - Compatible Model: Light Hammer Drill (SDSplus)
- Materials**
- Blade Part: Carbide Tip
- Origin**
- Vietnam

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Cutting Diameter (mm)	Effective Length (mm)	Total Length (mm)	SPQ (piece)	Weight (g)
415-3847	TCD-SDSUX-60	¥ 867	¥ 1,070	6.0	100	160	10	52
415-3855	TCD-SDSUX-64	¥ 867	¥ 1,070	6.4	100	160	10	53
415-3863	TCD-SDSUX-70	¥ 900	¥ 1,110	7.0	100	160	10	54
415-3871	TCD-SDSUX-75	¥ 900	¥ 1,110	7.5	100	160	10	60
415-3880	TCD-SDSUX-80	¥ 923	¥ 1,140	8.0	100	160	10	66
415-3898	TCD-SDSUX-85	¥ 867	¥ 1,070	8.5	100	160	10	57
415-3901	TCD-SDSUX-90	¥ 988	¥ 1,220	9.0	100	160	10	57
415-3910	TCD-SDSUX-95	¥ 1,053	¥ 1,300	9.5	100	160	10	57
415-3707	TCD-SDSUX-100	¥ 1,078	¥ 1,330	10.0	100	160	10	65
415-3715	TCD-SDSUX-105	¥ 972	¥ 1,200	10.5	100	160	10	71
415-3723	TCD-SDSUX-110	¥ 1,110	¥ 1,370	11.0	100	160	10	71
415-3731	TCD-SDSUX-120	¥ 1,062	¥ 1,310	12.0	100	160	10	84
415-3740	TCD-SDSUX-125	¥ 1,062	¥ 1,310	12.5	100	160	10	84
415-3758	TCD-SDSUX-127	¥ 1,062	¥ 1,310	12.7	100	160	10	85
415-3766	TCD-SDSUX-130	¥ 1,264	¥ 1,560	13.0	100	160	10	85
415-3774	TCD-SDSUX-140	¥ 1,418	¥ 1,750	14.0	100	160	10	85
415-3782	TCD-SDSUX-145	¥ 1,418	¥ 1,750	14.5	100	160	10	108
415-3791	TCD-SDSUX-150	¥ 1,604	¥ 1,980	15.0	100	160	6	108
415-3804	TCD-SDSUX-160	¥ 1,791	¥ 2,210	16.0	100	160	6	110
415-3812	TCD-SDSUX-165	¥ 1,855	¥ 2,290	16.5	100	160	6	112
415-3821	TCD-SDSUX-170	¥ 1,855	¥ 2,290	17.0	100	160	6	112
415-3839	TCD-SDSUX-180	¥ 2,098	¥ 2,590	18.0	100	160	6	135

Contact us:0120-509-849 <http://www.orange-book.com/>

68700 items in stock
11 cutting tool manufacturers