


Soft Buna-N Foam

Buna-N displays excellent strength and is the standard choice when oil resistance is required. This material also resists water and mild chemicals. Commonly found in applications related to automotive, engines, fuel systems, marine, and oil and gas. This Buna-N is lighter and easier to compress than other Neoprene foams.

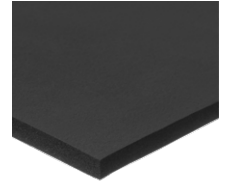

| Part Number | Shape | Cell Type | Material | Grade | Thickness | Width | Length | Color | Firmness | Backing Type | Texture | Specs Met |
|---------------|-------|-------------|----------|----------|-----------|-------|--------|-------|------------------------|------------------|---------|---------------------------|
| ZUSABSR-S-101 | Roll | Closed Cell | Buna-N | Standard | 1/16" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-111 | Roll | Closed Cell | Buna-N | Standard | 1/16" | 36" | 30 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-102 | Roll | Closed Cell | Buna-N | Standard | 1/8" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-112 | Roll | Closed Cell | Buna-N | Standard | 1/8" | 36" | 30 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-103 | Roll | Closed Cell | Buna-N | Standard | 1/4" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-113 | Roll | Closed Cell | Buna-N | Standard | 1/4" | 36" | 30 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-104 | Roll | Closed Cell | Buna-N | Standard | 3/8" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-114 | Roll | Closed Cell | Buna-N | Standard | 3/8" | 36" | 30 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-105 | Roll | Closed Cell | Buna-N | Standard | 1/2" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-115 | Roll | Closed Cell | Buna-N | Standard | 1/2" | 36" | 30 ft. | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-106 | Roll | Closed Cell | Buna-N | Standard | 1/16" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-107 | Roll | Closed Cell | Buna-N | Standard | 1/8" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-108 | Roll | Closed Cell | Buna-N | Standard | 1/4" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-109 | Roll | Closed Cell | Buna-N | Standard | 3/8" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-110 | Roll | Closed Cell | Buna-N | Standard | 1/2" | 36" | 10 ft. | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-201 | Sheet | Closed Cell | Buna-N | Standard | 1/16" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-206 | Sheet | Closed Cell | Buna-N | Standard | 1/16" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-202 | Sheet | Closed Cell | Buna-N | Standard | 1/8" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-207 | Sheet | Closed Cell | Buna-N | Standard | 1/8" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-203 | Sheet | Closed Cell | Buna-N | Standard | 1/4" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-208 | Sheet | Closed Cell | Buna-N | Standard | 1/4" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-204 | Sheet | Closed Cell | Buna-N | Standard | 3/8" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-209 | Sheet | Closed Cell | Buna-N | Standard | 3/8" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-205 | Sheet | Closed Cell | Buna-N | Standard | 1/2" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-210 | Sheet | Closed Cell | Buna-N | Standard | 1/2" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Plain | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-211 | Sheet | Closed Cell | Buna-N | Standard | 1/16" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-216 | Sheet | Closed Cell | Buna-N | Standard | 1/16" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-212 | Sheet | Closed Cell | Buna-N | Standard | 1/8" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-217 | Sheet | Closed Cell | Buna-N | Standard | 1/8" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-213 | Sheet | Closed Cell | Buna-N | Standard | 1/4" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-218 | Sheet | Closed Cell | Buna-N | Standard | 1/4" | 12" | 24" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |
| ZUSABSR-S-214 | Sheet | Closed Cell | Buna-N | Standard | 3/8" | 12" | 12" | Black | Extra Soft (0 - 4 psi) | Acrylic Adhesive | Smooth | ASTM D1056 2B1, FMVSS-302 |