


Weather Resistant EPDM Foam

EPDM Foam

EPDM is the most weather resistant foam, with a wide range of chemical compatibility, steam resistance, and good temperature range. Applications include anti-rattle and anti-skid applications, seals, flotation devices, and insulation.

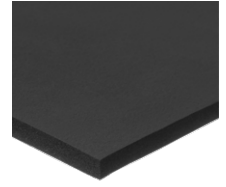

Part Number	Shape	Cell Type	Material	Grade	Thickness	Width	Length	Color	Firmness	Backing Type	Texture	Specs Met
ZUSAESR-101	Strip	Closed Cell	EPDM	Standard	1/16"	1/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-104	Strip	Closed Cell	EPDM	Standard	1/16"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-108	Strip	Closed Cell	EPDM	Standard	1/16"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-113	Strip	Closed Cell	EPDM	Standard	1/16"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-118	Strip	Closed Cell	EPDM	Standard	1/16"	1"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-102	Strip	Closed Cell	EPDM	Standard	1/8"	1/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-105	Strip	Closed Cell	EPDM	Standard	1/8"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-109	Strip	Closed Cell	EPDM	Standard	1/8"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-114	Strip	Closed Cell	EPDM	Standard	1/8"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-119	Strip	Closed Cell	EPDM	Standard	1/8"	1"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-103	Strip	Closed Cell	EPDM	Standard	1/4"	1/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-106	Strip	Closed Cell	EPDM	Standard	1/4"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-110	Strip	Closed Cell	EPDM	Standard	1/4"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-115	Strip	Closed Cell	EPDM	Standard	1/4"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-120	Strip	Closed Cell	EPDM	Standard	1/4"	1"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-107	Strip	Closed Cell	EPDM	Standard	3/8"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-111	Strip	Closed Cell	EPDM	Standard	3/8"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-116	Strip	Closed Cell	EPDM	Standard	3/8"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-121	Strip	Closed Cell	EPDM	Standard	3/8"	1"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-112	Strip	Closed Cell	EPDM	Standard	1/2"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-117	Strip	Closed Cell	EPDM	Standard	1/2"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-122	Strip	Closed Cell	EPDM	Standard	1/2"	1"	10 ft.	Black	Medium (9 - 13 psi)	Plain	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-1	Strip	Closed Cell	EPDM	Standard	1/16"	1/4"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-6	Strip	Closed Cell	EPDM	Standard	1/16"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-13	Strip	Closed Cell	EPDM	Standard	1/16"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-22	Strip	Closed Cell	EPDM	Standard	1/16"	5/8"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-32	Strip	Closed Cell	EPDM	Standard	1/16"	3/4"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-43	Strip	Closed Cell	EPDM	Standard	1/16"	1"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-55	Strip	Closed Cell	EPDM	Standard	1/16"	2"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-2	Strip	Closed Cell	EPDM	Standard	3/32"	1/4"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-7	Strip	Closed Cell	EPDM	Standard	3/32"	3/8"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-14	Strip	Closed Cell	EPDM	Standard	3/32"	1/2"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302
ZUSAESR-23	Strip	Closed Cell	EPDM	Standard	3/32"	5/8"	10 ft.	Black	Medium (9 - 13 psi)	Acrylic Adhesive	Smooth	ASTM D1056 2A3, FMVSS-302