


# Chemical Resistant Viton Foam

## Viton Foam

Viton is the most chemical resistant foam and can withstand extreme temperatures. It is the go to choice for the most extreme of applications.

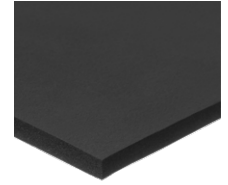

Part Number	Shape	Cell Type	Material	Grade	Thickness	Width	Length	Color	Firmness	Backing Type	Texture	Specs Met
ZUSAVSR-101	Strip	Closed Cell	Viton	Standard	1/8"	1/2"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVSR-103	Strip	Closed Cell	Viton	Standard	1/8"	1"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVSR-102	Strip	Closed Cell	Viton	Standard	1/4"	1/2"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVSR-104	Strip	Closed Cell	Viton	Standard	1/4"	1"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVSR-1	Strip	Closed Cell	Viton	Standard	1/8"	1/4"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-3	Strip	Closed Cell	Viton	Standard	1/8"	3/8"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-5	Strip	Closed Cell	Viton	Standard	1/8"	1/2"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-7	Strip	Closed Cell	Viton	Standard	1/8"	3/4"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-9	Strip	Closed Cell	Viton	Standard	1/8"	1"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-2	Strip	Closed Cell	Viton	Standard	1/4"	1/4"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-4	Strip	Closed Cell	Viton	Standard	1/4"	3/8"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-6	Strip	Closed Cell	Viton	Standard	1/4"	1/2"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-8	Strip	Closed Cell	Viton	Standard	1/4"	3/4"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVSR-10	Strip	Closed Cell	Viton	Standard	1/4"	1"	56"	Black	Soft (5 - 8 psi)	High Temperature Adhesive	Smooth	ASTM D1056 2B2
ZUSAVFS1	Sheet	Closed Cell	Viton	Standard	1/8"	6"	6"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS2	Sheet	Closed Cell	Viton	Standard	1/8"	12"	12"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS3	Sheet	Closed Cell	Viton	Standard	1/8"	12"	24"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS101	Sheet	Closed Cell	Viton	Standard	1/8"	24"	48"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS13	Sheet	Closed Cell	Viton	Standard	1/8"	28"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS4	Sheet	Closed Cell	Viton	Standard	1/4"	6"	6"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS5	Sheet	Closed Cell	Viton	Standard	1/4"	12"	12"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS6	Sheet	Closed Cell	Viton	Standard	1/4"	12"	24"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS102	Sheet	Closed Cell	Viton	Standard	1/4"	24"	48"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS14	Sheet	Closed Cell	Viton	Standard	1/4"	30"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS7	Sheet	Closed Cell	Viton	Standard	3/8"	6"	6"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS8	Sheet	Closed Cell	Viton	Standard	3/8"	12"	12"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS9	Sheet	Closed Cell	Viton	Standard	3/8"	12"	24"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS103	Sheet	Closed Cell	Viton	Standard	3/8"	24"	48"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS15	Sheet	Closed Cell	Viton	Standard	3/8"	30"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS10	Sheet	Closed Cell	Viton	Standard	1/2"	6"	6"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS11	Sheet	Closed Cell	Viton	Standard	1/2"	12"	12"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS12	Sheet	Closed Cell	Viton	Standard	1/2"	12"	24"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS104	Sheet	Closed Cell	Viton	Standard	1/2"	24"	48"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2
ZUSAVFS16	Sheet	Closed Cell	Viton	Standard	1/2"	30"	56"	Black	Soft (5 - 8 psi)	Plain	Smooth	ASTM D1056 2B2