


High Strength Neoprene Rubber

This formulation is stronger and more durable than standard Neoprene for more demanding applications. Neoprene has a good balance of properties and is suitable for oils, water, and refrigerants while remaining tough and weather resistant.

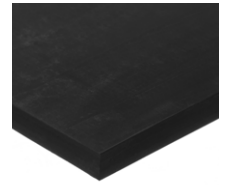

Part Number	Shape	Material	Grade	Durometer	Thickness	Width	Length	Color	Backing Type	Texture	Specs Met
BULK-RS-NHS30-43	Strip	Neoprene	High Strength	30A	1/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-60	Strip	Neoprene	High Strength	30A	1/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-74	Strip	Neoprene	High Strength	30A	1/16"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-45	Strip	Neoprene	High Strength	30A	3/32"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-61	Strip	Neoprene	High Strength	30A	3/32"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-76	Strip	Neoprene	High Strength	30A	3/32"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-47	Strip	Neoprene	High Strength	30A	1/8"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-62	Strip	Neoprene	High Strength	30A	1/8"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-77	Strip	Neoprene	High Strength	30A	1/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-49	Strip	Neoprene	High Strength	30A	3/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-64	Strip	Neoprene	High Strength	30A	3/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-79	Strip	Neoprene	High Strength	30A	3/16"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-51	Strip	Neoprene	High Strength	30A	1/4"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-66	Strip	Neoprene	High Strength	30A	1/4"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-81	Strip	Neoprene	High Strength	30A	1/4"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-53	Strip	Neoprene	High Strength	30A	3/8"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-68	Strip	Neoprene	High Strength	30A	3/8"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-83	Strip	Neoprene	High Strength	30A	3/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-54	Strip	Neoprene	High Strength	30A	1/2"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-70	Strip	Neoprene	High Strength	30A	1/2"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-56	Strip	Neoprene	High Strength	30A	3/4"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-58	Strip	Neoprene	High Strength	30A	1"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-72	Strip	Neoprene	High Strength	30A	1"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-78	Strip	Neoprene	High Strength	30A	1/16"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-90	Strip	Neoprene	High Strength	30A	1/16"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-98	Strip	Neoprene	High Strength	30A	1/16"	6"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-80	Strip	Neoprene	High Strength	30A	3/32"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-91	Strip	Neoprene	High Strength	30A	3/32"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-82	Strip	Neoprene	High Strength	30A	1/8"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-92	Strip	Neoprene	High Strength	30A	1/8"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-99	Strip	Neoprene	High Strength	30A	1/8"	6"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-84	Strip	Neoprene	High Strength	30A	3/16"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-93	Strip	Neoprene	High Strength	30A	3/16"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-85	Strip	Neoprene	High Strength	30A	1/4"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-94	Strip	Neoprene	High Strength	30A	1/4"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-86	Strip	Neoprene	High Strength	30A	3/8"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-95	Strip	Neoprene	High Strength	30A	3/8"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-87	Strip	Neoprene	High Strength	30A	1/2"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-96	Strip	Neoprene	High Strength	30A	1/2"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-100	Strip	Neoprene	High Strength	30A	1/2"	6"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-88	Strip	Neoprene	High Strength	30A	3/4"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-89	Strip	Neoprene	High Strength	30A	1"	2"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-97	Strip	Neoprene	High Strength	30A	1"	4"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS30-101	Strip	Neoprene	High Strength	30A	1"	6"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 BC 310
BULK-RS-NHS40-77	Strip	Neoprene	High Strength	40A	1/32"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-78	Strip	Neoprene	High Strength	40A	1/32"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-79	Strip	Neoprene	High Strength	40A	1/32"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-80	Strip	Neoprene	High Strength	40A	1/32"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-84	Strip	Neoprene	High Strength	40A	1/32"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-425	Strip	Neoprene	High Strength	40A	1/32"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-431	Strip	Neoprene	High Strength	40A	1/32"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-57	Strip	Neoprene	High Strength	40A	1/16"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-58	Strip	Neoprene	High Strength	40A	1/16"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-59	Strip	Neoprene	High Strength	40A	1/16"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-60	Strip	Neoprene	High Strength	40A	1/16"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-862	Strip	Neoprene	High Strength	40A	1/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-64	Strip	Neoprene	High Strength	40A	1/16"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-863	Strip	Neoprene	High Strength	40A	1/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 BC 410
BULK-RS-NHS40-426	Strip	Neoprene	High Strength	40A	1/16"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BC 410