


Oil Resistant Buna-N Rubber

Buna-N Rubber

Buna-N is ideal for oils, greases, fuels, and petroleum applications. It also works well with water and mild chemicals and has excellent physical properties making it tough and durable.

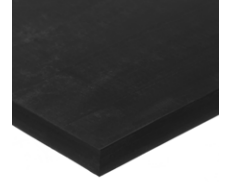

Part Number	Shape	Material	Grade	Durometer	Thickness	Width	Length	Color	Backing Type	Texture	Specs Met
BULK-RS-H40-77	Strip	Buna-N	Standard	40A	1/32"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-86	Strip	Buna-N	Standard	40A	1/32"	3/8"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-78	Strip	Buna-N	Standard	40A	1/32"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-79	Strip	Buna-N	Standard	40A	1/32"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-80	Strip	Buna-N	Standard	40A	1/32"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-82	Strip	Buna-N	Standard	40A	1/32"	1-1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-870	Strip	Buna-N	Standard	40A	1/32"	2"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-84	Strip	Buna-N	Standard	40A	1/32"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-420	Strip	Buna-N	Standard	40A	1/32"	3"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-879	Strip	Buna-N	Standard	40A	1/32"	4"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-426	Strip	Buna-N	Standard	40A	1/32"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-889	Strip	Buna-N	Standard	40A	1/32"	6"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-432	Strip	Buna-N	Standard	40A	1/32"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-57	Strip	Buna-N	Standard	40A	1/16"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-66	Strip	Buna-N	Standard	40A	1/16"	3/8"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-58	Strip	Buna-N	Standard	40A	1/16"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-59	Strip	Buna-N	Standard	40A	1/16"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-60	Strip	Buna-N	Standard	40A	1/16"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-62	Strip	Buna-N	Standard	40A	1/16"	1-1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-871	Strip	Buna-N	Standard	40A	1/16"	2"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-266	Strip	Buna-N	Standard	40A	1/16"	2"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-64	Strip	Buna-N	Standard	40A	1/16"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-421	Strip	Buna-N	Standard	40A	1/16"	3"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-880	Strip	Buna-N	Standard	40A	1/16"	4"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-276	Strip	Buna-N	Standard	40A	1/16"	4"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-427	Strip	Buna-N	Standard	40A	1/16"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-890	Strip	Buna-N	Standard	40A	1/16"	6"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-286	Strip	Buna-N	Standard	40A	1/16"	6"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-433	Strip	Buna-N	Standard	40A	1/16"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-400	Strip	Buna-N	Standard	40A	3/32"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-402	Strip	Buna-N	Standard	40A	3/32"	3/8"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-403	Strip	Buna-N	Standard	40A	3/32"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-410	Strip	Buna-N	Standard	40A	3/32"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-411	Strip	Buna-N	Standard	40A	3/32"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-412	Strip	Buna-N	Standard	40A	3/32"	1-1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-872	Strip	Buna-N	Standard	40A	3/32"	2"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-413	Strip	Buna-N	Standard	40A	3/32"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-422	Strip	Buna-N	Standard	40A	3/32"	3"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-881	Strip	Buna-N	Standard	40A	3/32"	4"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-428	Strip	Buna-N	Standard	40A	3/32"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-891	Strip	Buna-N	Standard	40A	3/32"	6"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-434	Strip	Buna-N	Standard	40A	3/32"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-97	Strip	Buna-N	Standard	40A	1/8"	1/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-106	Strip	Buna-N	Standard	40A	1/8"	3/8"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-98	Strip	Buna-N	Standard	40A	1/8"	1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-99	Strip	Buna-N	Standard	40A	1/8"	3/4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-100	Strip	Buna-N	Standard	40A	1/8"	1"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-102	Strip	Buna-N	Standard	40A	1/8"	1-1/2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-873	Strip	Buna-N	Standard	40A	1/8"	2"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-268	Strip	Buna-N	Standard	40A	1/8"	2"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-104	Strip	Buna-N	Standard	40A	1/8"	2"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-423	Strip	Buna-N	Standard	40A	1/8"	3"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-882	Strip	Buna-N	Standard	40A	1/8"	4"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-278	Strip	Buna-N	Standard	40A	1/8"	4"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-429	Strip	Buna-N	Standard	40A	1/8"	4"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-892	Strip	Buna-N	Standard	40A	1/8"	6"	36"	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-288	Strip	Buna-N	Standard	40A	1/8"	6"	5 ft.	Black	Plain	Smooth	ASTM D2000 BF 407
BULK-RS-H40-435	Strip	Buna-N	Standard	40A	1/8"	6"	10 ft.	Black	Plain	Smooth	ASTM D2000 BF 407