


Fabric-Reinforced SBR Rubber

These sheets have a fabric insert and stand up to high stress and flex. They are often used as flange gaskets, diaphragm packing, and in other applications with heavy compression. SBR is a good economical choice for general purpose use and offers good abrasion resistance.

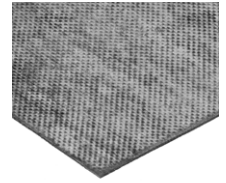

Part Number	Shape	Material	Grade	Durometer	Thickness	Width	Length	Color	Backing Type	Texture	Specs Met
BULK-RS-SBRFR75-69	Sheet	SBR	Fabric-Reinforced	75A	1/16"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-70	Sheet	SBR	Fabric-Reinforced	75A	1/16"	24"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-9	Sheet	SBR	Fabric-Reinforced	75A	1/16"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-13	Sheet	SBR	Fabric-Reinforced	75A	1/16"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-17	Sheet	SBR	Fabric-Reinforced	75A	1/16"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-71	Sheet	SBR	Fabric-Reinforced	75A	1/8"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-72	Sheet	SBR	Fabric-Reinforced	75A	1/8"	24"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-10	Sheet	SBR	Fabric-Reinforced	75A	1/8"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-14	Sheet	SBR	Fabric-Reinforced	75A	1/8"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-18	Sheet	SBR	Fabric-Reinforced	75A	1/8"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-11	Sheet	SBR	Fabric-Reinforced	75A	3/16"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-15	Sheet	SBR	Fabric-Reinforced	75A	3/16"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-19	Sheet	SBR	Fabric-Reinforced	75A	3/16"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-64	Sheet	SBR	Fabric-Reinforced	75A	1/4"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-66	Sheet	SBR	Fabric-Reinforced	75A	1/4"	12"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-65	Sheet	SBR	Fabric-Reinforced	75A	1/4"	24"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-67	Sheet	SBR	Fabric-Reinforced	75A	1/4"	24"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-12	Sheet	SBR	Fabric-Reinforced	75A	1/4"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-68	Sheet	SBR	Fabric-Reinforced	75A	1/4"	36"	12"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-16	Sheet	SBR	Fabric-Reinforced	75A	1/4"	36"	24"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-20	Sheet	SBR	Fabric-Reinforced	75A	1/4"	36"	36"	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-49	Sheet	SBR	Fabric-Reinforced	75A	1/16"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-50	Sheet	SBR	Fabric-Reinforced	75A	1/8"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-51	Sheet	SBR	Fabric-Reinforced	75A	3/16"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-52	Sheet	SBR	Fabric-Reinforced	75A	1/4"	36"	36"	Black	Acrylic Adhesive	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-21	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-25	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-29	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-33	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-37	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-41	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-45	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-1	Roll	SBR	Fabric-Reinforced	75A	1/16"	36"	50 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-22	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-26	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-30	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-34	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-38	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-42	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-46	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-2	Roll	SBR	Fabric-Reinforced	75A	1/8"	36"	60 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-23	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-27	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-31	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-35	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-39	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	8 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-43	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	9 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-47	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	10 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-3	Roll	SBR	Fabric-Reinforced	75A	3/16"	36"	60 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-24	Roll	SBR	Fabric-Reinforced	75A	1/4"	36"	4 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-28	Roll	SBR	Fabric-Reinforced	75A	1/4"	36"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-60	Roll	SBR	Fabric-Reinforced	75A	1/4"	36"	5 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-32	Roll	SBR	Fabric-Reinforced	75A	1/4"	36"	6 ft.	Black	Plain	Smooth	ASTM D2000 AA 706
BULK-RS-SBRFR75-36	Roll	SBR	Fabric-Reinforced	75A	1/4"	36"	7 ft.	Black	Plain	Smooth	ASTM D2000 AA 706