

Suspended Pipe Fittings

A10172 Anti-vibration hanging band (for SGP pipe) Confirm delivery

Anti-vibration supplementary hanging band for SGP pipe / With 10 mm rubber

Part number A10172 Anti-vibration hanging band (for SGP pipe) Units (mm)




Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	F
0013	15A	1/2	21.7	2.3	25	M 8×25	26	8
0028	20A	3/4	27.2	2.3	25	M 8×25	26	8
0032	25A	1	34.0	2.3	25	M 8×25	26	8
0047	32A	1 1/4	42.7	2.3	25	M 8×25	26	8
0051	40A	1 1/2	48.6	2.3	25	M 8×25	26	8
0066	50A	2	60.5	2.3	25	M 8×25	26	8
0085	65A	2 1/2	76.3	3.2	25	M10×30	26	8
0090	80A	3	89.1	3.2	25	M10×30	26	8
0102	100A	4	114.3	3.2	25	M10×30	26	8
0117	125A	5	139.8	4.5	32	M12×45	35	10
0121	150A	6	165.2	4.5	32	M12×45	35	10

The shape of the rubber may change for larger diameters.

A10214 Stainless steel anti-vibration hanging band with 10 t rubber Made to order

Anti-vibration supplementary hanging band for SGP pipe / With 10 mm rubber

Part number A10214 Stainless steel anti-vibration hanging band with 10 t rubber Units (mm)

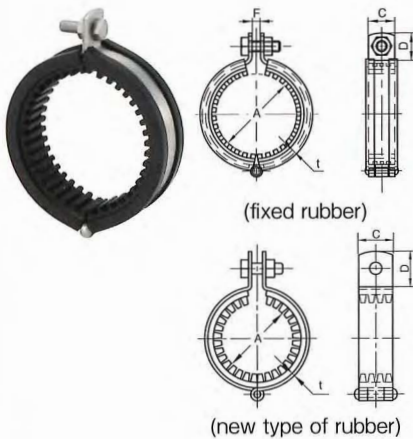


Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	F
0015	15A	1/2	21.7	2.0	25	M 8×25	26	8
0020	20A	3/4	27.2	2.0	25	M 8×25	26	8
0034	25A	1	34.0	2.0	25	M 8×25	26	8
0049	32A	1 1/4	42.7	2.0	25	M 8×25	26	8
0053	40A	1 1/2	48.6	2.0	25	M 8×25	26	8
0068	50A	2	60.5	2.0	25	M 8×25	26	8
0072	65A	2 1/2	76.3	2.0	25	M 8×25	26	8
0087	80A	3	89.1	2.0	25	M 8×25	26	8
0091	100A	4	114.3	2.0	25	M 8×25	26	8
0104	125A	5	139.8	3.0	32	M10×35	35	10
0119	150A	6	165.2	3.0	32	M12×45	35	10

The shape of the rubber may change for larger diameters.

A10174 Anti-vibration hanging band with lock Confirm delivery

Anti-vibration supplementary hanging band for SGP pipe / With 10 mm rubber

Part number A10174 Anti-vibration hanging band with lock Units (mm)

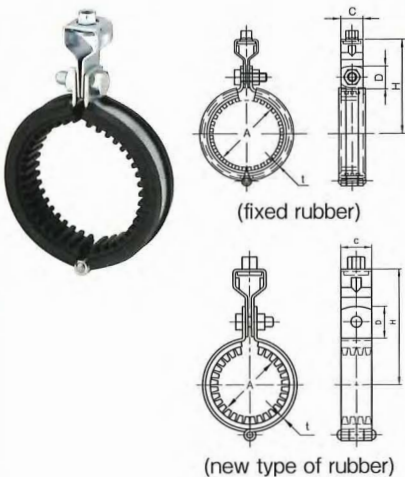

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	Tightening bolt Dia. x Length	D	H	Hanging bolt diameter
0018	15A	1/2	21.7	2.3	25	M 8×25	26	82	W 3/8
0022	20A	3/4	27.2	2.3	25	M 8×25	26	85	W 3/8
0037	25A	1	34.0	2.3	25	M 8×25	26	88	W 3/8
0041	32A	1 1/4	42.7	2.3	25	M 8×25	26	93	W 3/8
0056	40A	1 1/2	48.6	2.3	25	M 8×25	26	96	W 3/8
0075	50A	2	60.5	2.3	25	M 8×25	26	102	W 3/8
0080	65A	2 1/2	76.3	3.2	25	M10×30	26	109	W 3/8
0094	80A	3	89.1	3.2	25	M10×30	26	116	W 3/8
0107	100A	4	114.3	3.2	25	M10×30	26	128	W 3/8
0111	125A	5	139.8	4.5	32	M12×45	35	153	W 1/2
0126	150A	6	165.2	4.5	32	M12×45	35	166	W 1/2

The shape of the rubber may change for larger diameters.