


Vertical Pipe Fittings

A10379 Decorative threaded bracket (with flange)

Screw-in bracket for vertical bands

Part number A10379 Decorative threaded bracket (with flange) Units (mm)

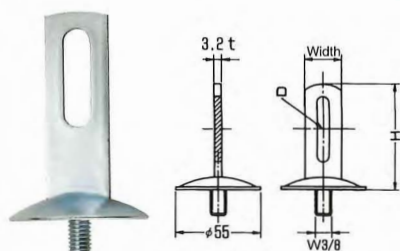

Size code	25 wide	
	H	D
0015	55	φ10 × 38
0020	60	φ10 × 38
0034	70	φ10 × 38
0049	80	φ10 × 38
0053	100	φ10 × 38
0068	120	φ10 × 38
0072	150	φ10 × 38
0087	200	φ10 × 38

Size code	32 wide	
	H	D
0091	55	φ10 × 38
0104	60	φ10 × 38
0119	70	φ10 × 38
0123	80	φ10 × 38
0138	100	φ10 × 38
0142	120	φ10 × 38
0157	150	φ10 × 38
0161	200	φ10 × 38


Size code	38 wide	
	H	D
0176	80	φ14 × 58
0195	100	φ14 × 58
0208	120	φ14 × 58
0212	150	φ14 × 58
0227	200	φ14 × 58

Size code	50 wide	
	H	D
0231	80	φ14 × 58
0246	100	φ14 × 58
0265	120	φ14 × 58
0270	150	φ14 × 58
0284	200	φ14 × 58

A10396 Stainless steel decorative threaded bracket (with flange)

Screw-in bracket for vertical bands

Part number A10396 Stainless steel decorative threaded bracket (with flange) Units (mm)

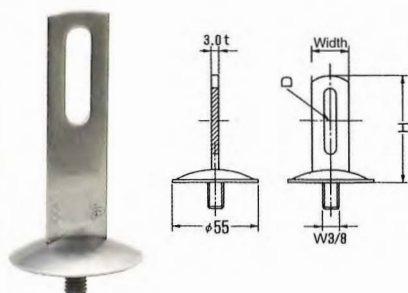

Size code	25 wide	
	H	D
0016	55	φ10 × 38
0035	60	φ10 × 38
0040	70	φ10 × 38
0054	80	φ10 × 38
0069	100	φ10 × 38
0073	120	φ10 × 38
0088	150	φ10 × 38
0092	200	φ10 × 38

Size code	32 wide	
	H	D
0105	55	φ10 × 38
0110	60	φ10 × 38
0124	70	φ10 × 38
0139	80	φ10 × 38
0143	100	φ10 × 38
0158	120	φ10 × 38
0162	150	φ10 × 38
0177	200	φ10 × 38


Size code	38 wide	
	H	D
0181	80	φ14 × 58
0196	100	φ14 × 58
0209	120	φ14 × 58
0213	150	φ14 × 58
0228	200	φ14 × 58

Size code	50 wide	
	H	D
0232	80	φ14 × 58
0247	100	φ14 × 58
0251	120	φ14 × 58
0266	150	φ14 × 58
0285	200	φ14 × 58

A11215 Dip-plated decorative threaded bracket (with flange)

Screw-in bracket for vertical bands

Part number A11215 Dip-plated decorative threaded bracket (with flange) Units (mm)

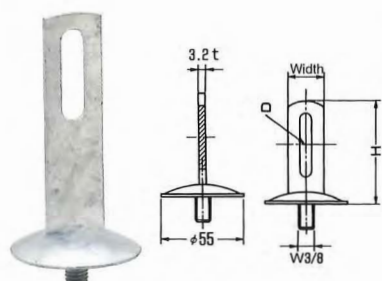

Size code	25 wide	
	H	D
0017	55	φ10 × 38
0021	60	φ10 × 38
0036	70	φ10 × 38
0055	80	φ10 × 38
0060	100	φ10 × 38
0074	120	φ10 × 38
0089	150	φ10 × 38
0093	200	φ10 × 38

Size code	32 wide	
	H	D
0106	55	φ10 × 38
0125	60	φ10 × 38
0130	70	φ10 × 38
0144	80	φ10 × 38
0159	100	φ10 × 38
0163	120	φ10 × 38
0178	150	φ10 × 38
0182	200	φ10 × 38

Size code	38 wide	
	H	D
0197	80	φ14 × 58
0200	100	φ14 × 58
0214	120	φ14 × 58
0229	150	φ14 × 58
0233	200	φ14 × 58

Size code	50 wide	
	H	D
0248	80	φ14 × 58
0252	100	φ14 × 58
0267	120	φ14 × 58
0271	150	φ14 × 58
0286	200	φ14 × 58

