

Floor Bands


Set floor

A13531 Set floor

Level adjustment band for drainage pipe (SGP/VP)

Part number A13531 Set floor

Units (mm)

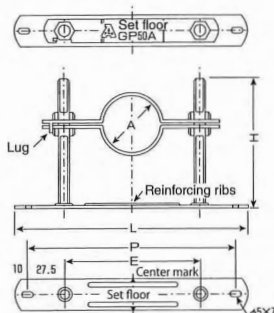


Diameter size (A)	Applicable pipe outer diameter	H	Size code	Level range	L	P	E
15A	21.7	120H	0124	20 to 110	138	118	63
		150H	0162	20 to 140			
20A	27.2	120H	0139	20 to 110	138	118	63
		150H	0177	20 to 140			
25A	34.0	120H	0143	25 to 110	138	118	63
		150H	0181	25 to 140			
32A	42.7	120H	0158	30 to 110	190	170	115
		150H	0196	30 to 140			
40A	48.6	120H	0016	33 to 110	190	170	115
		150H	0035	33 to 140			
50A	60.5	120H	0040	39 to 110	190	170	115
		150H	0054	39 to 140			
65A	76.3	120H	0069	47 to 110	190	170	115
		150H	0073	47 to 140			
80A	89.1	120H	0088	53 to 110	190	170	115
		150H	0092	53 to 140			
100A	114.3	120H	0105	62 to 110	225	205	150
		150H	0110	62 to 140			
125A	139.8	180H	0815	75 to 170	310	290	235
150A	165.2	180H	0820	88 to 170	310	290	235

A15367 Stainless steel set floor

Level adjustment band for drainage pipe (SGP/VP)

Part number A15367 Stainless steel set floor

Units (mm)

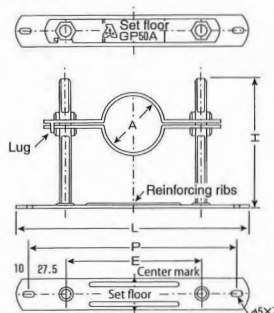

Diameter size (A)	Applicable pipe outer diameter	H	Size code	Level range	L	P	E
15A	21.7	120H	0017	20 to 110	138	118	63
		150H	0021	20 to 140			
20A	27.2	120H	0036	20 to 110	138	118	63
		150H	0055	20 to 140			
25A	34.0	120H	0060	25 to 110	138	118	63
		150H	0074	25 to 140			
32A	42.7	120H	0089	30 to 110	190	170	115
		150H	0093	30 to 140			
40A	48.6	120H	0106	33 to 110	190	170	115
		150H	0125	33 to 140			
50A	60.5	120H	0130	39 to 110	190	170	115
		150H	0144	39 to 140			
65A	76.3	120H	0159	47 to 110	190	170	115
		150H	0163	47 to 140			
80A	89.1	120H	0178	53 to 110	190	170	115
		150H	0182	53 to 140			
100A	114.3	120H	0197	62 to 110	225	205	150
		150H	0200	62 to 140			
125A	139.8	180H	0214	75 to 170	310	290	235
150A	165.2	180H	0229	88 to 170	310	290	235