

Saddle Bands


A10455 Stainless steel saddle for CL pipe

Saddle band for outer surface coated steel pipe

Part number A10455 Stainless steel saddle for CL pipe

Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	G	P
0019	15A	1/2	25.7	2.0	25	φ 5	54
0023	20A	3/4	31.2	2.0	25	φ 5	60
0038	25A	1	37.6	2.0	25	φ 5	66
0042	32A	1 1/4	46.3	2.0	25	φ 5	75
0057	40A	1 1/2	52.2	2.0	25	φ 5	81
0061	50A	2	64.1	2.0	25	φ 5	93
0076	65A	2 1/2	79.9	2.0	25	φ 5	116
0095	80A	3	92.7	2.0	25	φ 5	128
0108	100A	4	118.3	2.0	25	φ 5	153

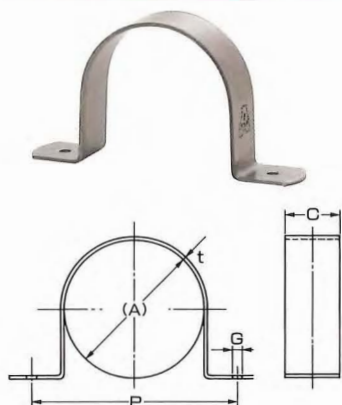

A10439 Saddle for TN pipe

Saddle band for fireproof double-layer pipe (FDP)

Part number A10439 Saddle for TN pipe

Units (mm)

Size code	Size	Applicable pipe outer diameter	t	C	G	P
0015	40	63	2.3	25	φ 5	94
0020	50	75 to 76	2.3	25	φ 5	106
0034	65	91 to 92	2.3	25	φ 5	122
0049	75	104 to 105	2.3	25	φ 5	135
0053	100	131 to 132	2.3	25	φ 5	162
0068	125	158 to 159	3.2	32	φ 11	193
0072	150	185 to 187	3.2	32	φ 11	221



A10456 Stainless steel saddle for TN pipe

Saddle band for fireproof double-layer pipe (FDP)

Part number A10456 Stainless steel saddle for TN pipe

Units (mm)

Size code	Size	Applicable pipe outer diameter	t	C	G	P
0016	40	63	2.0	25	φ 5	94
0035	50	75 to 76	2.0	25	φ 5	106
0040	65	91 to 92	2.0	25	φ 5	122
0054	75	104 to 105	2.0	25	φ 5	135
0069	100	131 to 132	2.0	25	φ 5	162
0073	125	158 to 159	3.0	32	φ 11	193
0088	150	185 to 187	3.0	32	φ 11	221



A10434 Dipped saddle

Saddle band for copper pipe / Soft PVC-coated type

Part number A10434 Dipped saddle

Units (mm)

Size code	Diameter size (A)	Nominal diameter (B)	Applicable pipe outer diameter	t	C	G	P
0019	10A	3/8	12.7	1.0	25	φ 5	45
0023	15A	1/2	15.88	1.0	25	φ 5	48
0038	20A	3/4	22.22	1.0	25	φ 5	54
0042	25A	1	28.58	1.0	25	φ 5	62

