


CL Combination Wrench, Metric

Code	mm	C mm	D mm	T ₁ mm	T ₂ mm	L mm	Weight g		Price ¥
CL0005	5.5	12.7	10.5	2.9	5	105	13	10	1,070
CL0006	6	13.5	11.0	2.9	5.1	110	15	10	1,070
CL0007	7	15.5	12.4	3.5	5	120	17	10	1,070
CL0008	8	17.5	12.7	3.5	5.7	130	20	10	1,070
CL0009	9	19.5	14	4.2	6.2	136	31	10	1,170
CL0010	10	21.5	15.3	4.8	6.5	152	40	10	1,170
CL0011	11	23.5	17.5	5	7	161	55	10	1,290
CL0012	12	25.5	18.5	5.5	7.5	175	70	10	1,290
CL0013	13	28.0	19.5	6.0	8.0	187	80	10	1,460
CL0014	14	29.5	22.0	6.0	8.5	197	100	10	1,510
CL0015	15	32.5	23.0	6.0	9.0	210	115	5	1,800
CL0016	16	34.5	23.7	6.0	9.5	220	130	5	1,800
CL0017	17	36.0	26.5	7.0	10.5	231	150	5	1,800
CL0018	18	38.0	27.5	7.3	11.0	245	180	5	2,050
CL0019	19	40.0	28.0	7.5	11.5	254	200	5	2,050
CL0021	21	44.5	31.0	8.0	12.5	290	290	5	2,760
CL0022	22	46.5	32.0	8.5	13.0	304	300	5	2,760
CL0024	24	50.5	35.0	9.0	15.0	337	380	5	3,260
CL0026	26	54.5	38.0	10.0	16.0	260	470	5	4,830
CL0027	27	56.0	39.5	10.5	16.0	370	495	5	4,830
CL0030	30	62.0	43.0	11.0	18.0	410	625	5	6,200
CL0032	32	65.5	47.0	11.5	18.5	420	765	5	7,140

• Nickel Chrome Plating

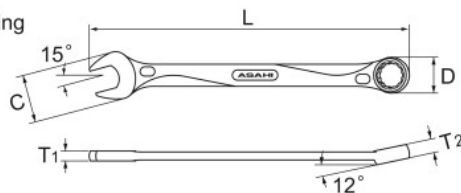

6Pcs.

Code **CLS060**

Price **¥8,300**

Set Contains

Combination Wrench CL- 8, 10, 12, 13, 14, 17

- Weight 490g
- Plastic Holder
- Storage Box 66 × 245 × 43mm



CLS060

10Pcs.

Code **CLS100**

Price **¥18,900**

Set Contains

Combination Wrench CL-8, 10, 12, 13, 14, 17, 19, 21, 22, 24

- Weight 1750g
- Storage Box 190 × 460 × 40mm



CLS100

14Pcs.


Code **CLS140**

Price **¥35,500**

Set Contains

Combination Wrench CL- 5.5, 7, 8, 10, 12, 13, 14, 17, 19, 22, 24, 27, 30, 32

- Weight 3580g
- Tool Roll 500 × 645mm

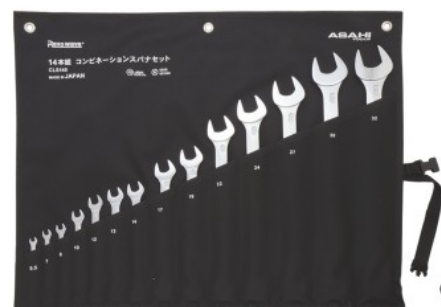

CLS140

Revowave®



Revowave features an innovative design, never seen before.
The curved surface of its distinctive neck fits the worker's hand perfectly, providing excellent workability.