


OF Offset Wrench, Metric

Code	mm	D ₁ mm	D ₂ mm	T ₁ mm	T ₂ mm	L mm	Weight g	Price ¥
OF0809	8×9	12.5	15.5	5.5	6.5	166	40	1,500
OF0810	8×10	12.5	15.5	5.5	6.5	166	40	1,500
OF1011	10×11	15.5	18.5	6.5	7.5	190	60	1,610
OF1012	10×12	15.5	19	6.5	7.5	190	60	1,510
OF1013	10×13	17	19.5	7.5	8	190	80	1,540
OF1113	11×13	17	19.5	7.5	8	190	80	1,620
OF1214	12×14	19	22	7.5	8.5	215	90	1,630
OF1317	13×17	21	25	8.5	10	243	140	1,810
OF1417	14×17	21	25	8.5	10	243	140	1,810
OF1719	17×19	25	28	10	11.5	276	190	2,020
OF1721	17×21	26.5	32	11.5	12	313	290	2,430
OF1921	19×21	28	32	11.5	12	314	310	2,560
OF1922	19×22	28	32	11.5	12	314	310	2,560
OF1924	19×24	29.5	34.5	12	13	332	340	2,710
OF2123	21×23	32	34.5	12	13	333	360	3,060
OF2126	21×26	32.5	38.5	13	13.5	365	450	3,310
OF2224	22×24	32	34.5	12	13	333	360	3,220
OF2326	23×26	34.5	38.5	13	13.5	366	450	3,610
OF2427	24×27	34.5	38.5	13	13.5	366	450	4,040
OF2430	24×30	38.5	46	13.5	16	392	660	4,150
OF2629	26×29	38.5	46	13.5	16	392	650	4,980
OF2632	26×32	38.5	46	13.5	16	392	600	4,730
OF2730	27×30	38.5	46	13.5	16	392	650	4,730
OF2932	29×32	46	51	16	17	428	870	5,290
OF3032	30×32	46	51	16	17	428	870	5,180
OF3235	32×35	46	51	16	17	428	870	5,860
OF3236	32×36	46	51	16	17	428	870	5,860
OF3541	35×41	51	58	17	18	455	1,120	7,400
OF3641	36×41	51	58	17	18	455	1,120	7,650

• Nickel Chrome Plating

JIS JQA (~ OF2427)

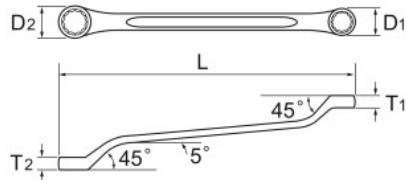

TOOL SETS

SPANNERS

STRIKING FACE WRENCHES

HOOK SPANNERS

DX2000 TOOLS
HEXAGON KEY WRENCHES

HEXAGON KEY WRENCHES

TORQUE WRENCHES

CROWFOOT WRENCHES

SOCKETS

OTHER TOOLS