



## DR Striking Face Ring Spanner, Metric

Code	mm	D mm	T mm	t mm	L mm	Weight g	Price ¥
DR0024	24	45	18	13.5	185	350	2 4,850
DR0027	27	45	18	13.5	185	340	2 4,910
DR0030	30	55	20	15	197	520	2 5,250
DR0032	32	55	20	15	197	520	2 5,360
DR0035	35	55	20	15	197	520	2 5,780
DR0036	36	66	22	16	223	940	2 5,990
<b>NEW</b> DR0038	38	66	22	16	223	940	2 6,620
DR0041	41	66	22	16	223	940	2 6,620
DR0046	46	80	27	18	250	1,330	2 7,770
DR0050	50	80	27	18	250	1,330	2 9,140
DR0054	54	90	27	19	275	1,830	2 11,900
DR0055	55	90	27	19	275	1,830	2 11,900
DR0058	58	90	27	19	275	1,830	2 13,500
DR0060	60	104	32	24	302	2,630	2 15,100
DR0063	63	104	32	24	302	2,630	2 17,000
DR0065	65	104	32	24	302	2,630	2 17,000
DR0067	67	104	32	24	302	2,630	2 18,800
DR0070	70	120	35	28	350	4,500	2 21,300
DR0071	71	120	35	28	350	4,500	2 24,200
DR0075	75	120	35	28	350	4,500	2 24,700
DR0077	77	120	35	28	350	4,500	2 29,600
DR0080	80	127	39	28	354	4,400	2 30,300
DR0085	85	144	41	31	397	7,000	2 32,000
DR0090	90	144	41	31	397	7,000	2 38,600
DR0095	95	157	50	34	419	8,500	- 38,600
DR0100	100	157	50	34	419	8,500	- 48,200
DR0105	105	183	55	36	441	11,200	- 55,000
DR0110	110	183	55	36	441	11,200	- 66,900
DR0115	115	183	55	36	441	11,200	- 77,600
DR0120	120	185	60	38	480	13,300	- -
DR0125	125	195	60	38	490	13,000	- -
DR0130	130	198	60	38	492	15,500	- -
DR0135	135	204	65	40	512	17,000	- -
DR0145	145	217	65	40	554	18,000	- -
DR0150	150	223	65	44	577	21,000	- -
DR0155	155	230	65	44	585	21,000	- -
DR0165	165	242	65	48	609	24,800	- -
DR0170	170	254	65	48	630	-	- -
DR0175	175	254	65	48	630	-	- -
DR0180	180	260	70	48	648	-	- -
DR0185	185	278	75	52	692	-	- -
DR0190	190	278	75	52	692	-	- -
DR0200	200	293	75	52	712	-	- -

- Cathodic Electrodeposition
- Special Order (0120 ~ )

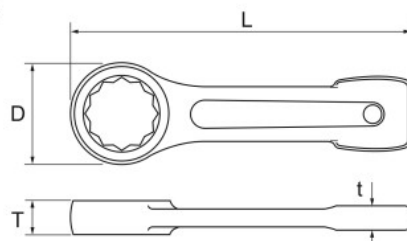

### [ How to use ]

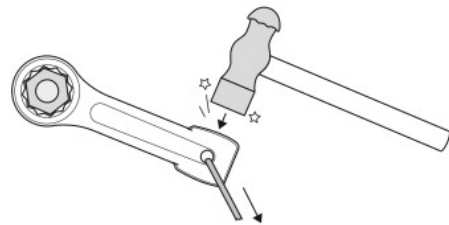

Thread a rope through the hole of the handle and pull it to a tightening direction hammering the striking surface of the spanner.