




 
FK Hook Spanner

Code	 mm	C mm	T mm	H mm	L mm	Weight g		Price ¥
FK0012	12~14	2	4	12	108	25	10	910
FK0016	16~20	2	4	12	108	25	10	910
FK0020	20~22	2	4	12	108	25	10	910
FK0025	25~28	2.3	5	21	136	50	10	910
FK0030	30~32	2.3	5	21	136	50	10	930
FK0034	34~38	2.5	6	28	160	100	10	1,020
FK0038	38~45	2.5	6	30	173	100	10	1,060
FK0040	40~42	2.5	6	30	173	100	10	1,060
FK0045	45~48	2.5	6.5	36	196	150	10	1,180
FK0045N	45~52	2.5	6.5	36	196	150	10	1,230
FK0052	50~55	2.5	6.5	41	208	155	10	1,430
FK0052N	52~58	2.5	6.5	41	208	155	10	1,520
FK0058	58~65	3	7.5	46	232	229	10	1,650
FK0065	65~70	3	7.5	46	232	229	10	1,700
FK0065N	65~75	3.5	8	52	247	275	10	1,880
FK0070	70~75	3.5	8	52	247	275	10	1,790
FK0075	75~80	3.5	8	52	247	275	10	1,860
FK0075N	75~85	3.5	8.5	62	271	390	10	2,230
FK0080	80~85	3.5	8.5	62	271	390	10	2,230
FK0085	85~92	3.5	8.5	62	271	390	10	2,420
FK0092	92~100	4	8.5	68	286	400	10	2,500
FK0098	98~110	4	10	82	333	710	5	3,420
FK0105	105~115	4	10	82	333	710	5	3,330
FK0120	120~130	4.5	10	82	333	710	5	3,630
FK0140	140~150	5.5	10.5	100	385	960	5	5,880
FK0155	155~165	5.5	10.5	100	385	960	5	6,410
FK0175	175~195	6.5	12	130	466	2,100	-	12,600
FK0200	200~220	7.5	12	130	466	2,100	-	13,900
FK0230	230~250	8.5	16	162	567	3,700	-	18,000
FK0260	260~280	8.5	16	162	567	3,700	-	18,500
FK0290	290~320	12	16	196	610	-	-	-
FK0320	320~345	12	16	215	640	-	-	-
FK0350	350~375	12	16	235	680	-	-	-
FK0380	380~400	14	19	255	741	-	-	-

- Cathodic Electrodeposition
- Special Order (0290 ~)

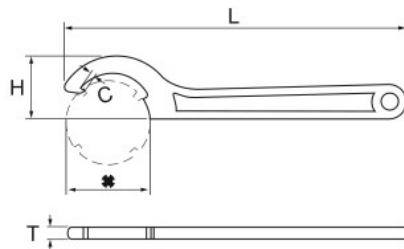

[How to use]



Attach the spanner into the groove of the ring nut.