


SN Single End Spanner, Metric


Code	mm	C mm	T mm	L mm	Weight g		Price ¥
SN0010	10	23.4	4	105	20	20	420
SN0012	12	27.5	4.5	125	40	20	420
SN0013	13	30	4.5	130	45	20	420
SN0014	14	33	5	140	45	20	500
SN0017	17	38	5.5	160	85	20	560
SN0019	19	41.5	6.5	180	115	20	700
SN0022	22	47	7.5	195	140	20	880
SN0024	24	50	8.5	215	200	20	1,100
SN0026	26	56	9.5	235	250	20	1,150
SN0027	27	56	9.5	235	250	20	1,220
SN0030	30	65	10.5	275	320	10	1,500
SN0032	32	65	10.5	275	370	10	1,620
SN0035	35	74	12	305	550	10	2,510
SN0036	36	74	12	305	550	10	2,490
SN0038	38	74	12	305	550	10	3,350
SN0041	41	83	14	345	820	10	3,000
SN0046	46	92	16	385	1,200	5	4,470
SN0050	50	97	17	415	1,260	5	5,460
SN0055	55	115	18	483	2,000	5	9,600
SN0060	60	115	18	483	2,000	5	12,700
SN0065	65	140	18	575	3,000	2	16,300
SN0070	70	140	18	575	3,000	2	22,000
SN0075	75	140	18	575	3,000	2	25,000

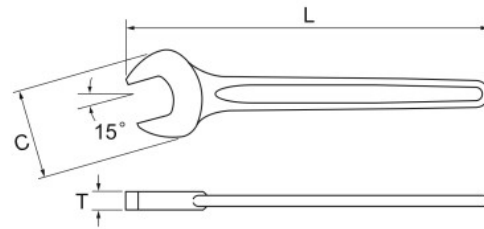

• Cathodic Electrodeposition JQA (~ 0070)

SN Double Open End Spanner, Metric

Code	mm	C ₁ mm	C ₂ mm	T mm	L mm	Weight g		Price ¥
SN0507	5.5×7	16	19	3.5	102	20	20	510
SN0607	6×7	16	19	3.5	102	20	20	510
SN0708	7×8	17	21	4	105	25	20	510
SN0809	8×9	19	21.5	4	115	30	20	510
SN0810	8×10	19	21.5	4	115	30	20	510
SN0910	9×10	19	21.5	4	115	30	20	510
SN1012	10×12	21.5	26	4.5	125	40	20	510
SN1013	10×13	23	27.5	5	130	50	20	510
SN1014	10×14	25	31.5	5.5	140	70	20	590
SN1113	11×13	23	27.5	5	130	50	20	550
SN1214	12×14	25	31.5	5.5	140	70	20	550
SN1317	13×17	32	37.5	6	160	100	20	610
SN1417	14×17	32	37.5	6	160	100	20	610
SN1618	16×18	37.5	41.5	6.5	180	100	20	690
SN1719	17×19	37.5	41.5	6.5	180	140	20	720
SN1921	19×21	40	46	7.5	195	170	20	910
SN1922	19×22	40	46	7.5	195	170	20	920
SN1924	19×24	44	50	8.5	215	220	20	1,080
SN2123	21×23	44	48.5	8	205	200	20	1,180
SN2126	21×26	46	55	9	225	280	10	1,180
SN2224	22×24	44	50	8.5	215	230	20	1,160
SN2326	23×26	46	55	9	225	280	10	1,500
SN2427	24×27	50	56	9.5	235	330	10	1,570
SN2430	24×30	50	60	9.5	257	360	10	1,740
SN2730	27×30	56	65	10.5	265	440	10	1,910
SN3032	30×32	63	66	11	275	510	10	2,510
SN3236	32×36	66	74	12	305	650	10	3,100
SN3541	35×41	74	83	14	345	930	5	3,910
SN3641	36×41	74	83	14	345	950	5	4,610
SN4146	41×46	87	97	16	385	1,450	5	6,570

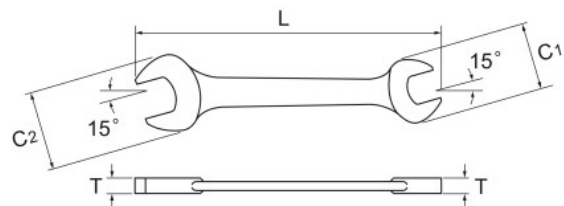

• Cathodic Electrodeposition JQA