


ソリッド ロングドリル 〈ストレートシャンク〉

Long Drill, Straight Shank

ADL

 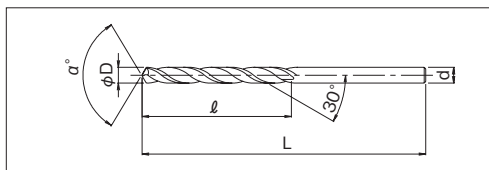


■ ADS標準ストレートシャンクドリルのロングタイプです。

Long type drill of ADS Standard Straight Shank Drill.

刃径公差：+0~-0.01

φD Tolerance



型番 CODE NUMBER	径 φD	刃長 ℓ	全長 L	定価 ¥
ADL-0030	0.30	10	60	4,430
ADL-0035	0.35	10	60	4,430
ADL-0040	0.4	10	60	4,430
ADL-0045	0.45	10	60	4,430
ADL-0050	0.5	10	60	3,930
ADL-0055	0.55	15	65	3,930
ADL-0060	0.6	15	65	3,930
ADL-0065	0.65	15	65	3,930
ADL-0070	0.7	15	65	3,930
ADL-0075	0.75	15	65	3,930
ADL-0080	0.8	20	75	3,680
ADL-0085	0.85	20	75	3,680
ADL-0090	0.9	20	75	3,680
ADL-0095	0.95	20	75	3,680
ADL-0100	1	25	75	3,080
ADL-0105	1.05	25	75	3,780
ADL-0110	1.1	25	75	3,080
ADL-0115	1.15	25	75	3,780
ADL-0120	1.2	25	75	3,080
ADL-0125	1.25	25	75	3,780
ADL-0130	1.3	25	75	3,080
ADL-0135	1.35	25	75	3,780
ADL-0140	1.4	30	75	3,150
ADL-0145	1.45	30	75	3,780
ADL-0150	1.5	30	75	3,150
ADL-0155	1.55	30	75	3,780

型番 CODE NUMBER	径 φD	刃長 ℓ	全長 L	定価 ¥
ADL-0160	1.6	30	75	3,150
ADL-0165	1.65	30	75	3,780
ADL-0170	1.7	30	75	3,150
ADL-0175	1.75	30	75	3,780
ADL-0180	1.8	30	75	3,150
ADL-0185	1.85	30	75	3,780
ADL-0190	1.90	30	75	3,150
ADL-0195	1.95	30	75	3,780
ADL-0200	2	30	75	4,670
ADL-0205	2.05	30	75	5,600
ADL-0210	2.1	30	75	4,670
ADL-0215	2.15	30	75	5,600
ADL-0220	2.2	30	75	4,670
ADL-0225	2.25	30	75	5,600
ADL-0230	2.3	30	75	4,670
ADL-0235	2.35	30	75	5,600
ADL-0240	2.4	35	100	5,830
ADL-0245	2.45	35	100	7,000
ADL-0250	2.5	35	100	5,830
ADL-0255	2.55	35	100	7,000
ADL-0260	2.6	35	100	5,830
ADL-0265	2.65	35	100	7,000
ADL-0270	2.7	35	100	5,830
ADL-0275	2.75	35	100	7,200
ADL-0280	2.8	35	100	6,000
ADL-0285	2.85	35	100	7,200