

# タッチスパイラルチューブ TPS


## POLYURETHANE SPIRAL TUBING TPS

型式表示例 / How To Order

# TPS - 8 - 30

標準色：BK (黒)

寸法図 / Dimensions

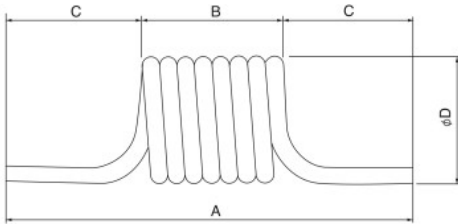

タッチスパイラルチューブ  
Polyurethane

チューブ外径 (mm)  
Tube O.D.

山数/No. of turns

型式 Model	使用チューブ Tube Used	使用範囲 Service Length (mm)	A (mm)	B (mm)	C (mm)	øD (mm)
* TPS-4-5	TE-4×2	500	420	20	200	21
* TPS-4-10	TE-4×2	600	440	40	200	21
TPS-4-15	TE-4×2	700	460	60	200	21
* TPS-4-20	TE-4×2	800	480	80	200	21
* TPS-4-25	TE-4×2	900	500	100	200	21
TPS-4-30	TE-4×2	1,000	520	120	200	21
* TPS-4-35	TE-4×2	1,100	540	140	200	21
* TPS-4-40	TE-4×2	1,200	560	160	200	21
* TPS-4-45	TE-4×2	1,300	580	180	200	21
* TPS-4-50	TE-4×2	1,400	600	200	200	21
* TPS-4-55	TE-4×2	1,500	620	220	200	21
* TPS-4-60	TE-4×2	1,600	640	240	200	21
* TPS-6-5	TE-6	550	430	30	200	38
* TPS-6-10	TE-6	700	460	60	200	38
TPS-6-15	TE-6	850	490	90	200	38
* TPS-6-20	TE-6	1,000	520	120	200	38
* TPS-6-25	TE-6	1,150	550	150	200	38
TPS-6-30	TE-6	1,300	580	180	200	38
* TPS-6-35	TE-6	1,450	610	210	200	38

材質の関係で若干の寸法違いが生ずる事があります。

All dimensions are calculated by computer, the actual dimensions will be slightly different from above.

型式 \* マークの有る商品は、受注生産品となります。通常在庫品に比べますと多少納期を戴く事があります。

\* marked items are not standard stock items. Please ask the delivery schedule to your local distributor.

型式 Model	使用チューブ Tube Used	使用範囲 Service Length (mm)	A (mm)	B (mm)	C (mm)	øD (mm)
* TPS-6-40	TE-6	1,600	640	240	200	38
TPS-6-45	TE-6	1,750	670	270	200	38
* TPS-6-50	TE-6	1,900	700	300	200	38
* TPS-6-55	TE-6	2,050	730	330	200	38
* TPS-6-60	TE-6	2,200	760	360	200	38
* TPS-8-5	TE-8	600	440	40	200	42
* TPS-8-10	TE-8	800	480	80	200	42
TPS-8-15	TE-8	1,000	520	120	200	42
* TPS-8-20	TE-8	1,200	560	160	200	42
* TPS-8-25	TE-8	1,400	600	200	200	42
TPS-8-30	TE-8	1,600	640	240	200	42
* TPS-8-35	TE-8	1,800	680	280	200	42
* TPS-8-40	TE-8	2,000	720	320	200	42
TPS-8-45	TE-8	2,200	760	360	200	42
* TPS-8-50	TE-8	2,400	800	400	200	42
* TPS-8-55	TE-8	2,600	840	440	200	42
* TPS-8-60	TE-8	2,800	880	480	200	42
* TPS-10-5	TE-10	650	450	50	200	52
* TPS-10-10	TE-10	900	500	100	200	52
TPS-10-15	TE-10	1,150	550	150	200	52
* TPS-10-20	TE-10	1,400	600	200	200	52
* TPS-10-25	TE-10	1,650	650	250	200	52
TPS-10-30	TE-10	1,900	700	300	200	52
* TPS-10-35	TE-10	2,150	750	350	200	52
* TPS-10-40	TE-10	2,400	800	400	200	52
TPS-10-45	TE-10	2,650	850	450	200	52
* TPS-10-50	TE-10	2,900	900	500	200	52
* TPS-10-55	TE-10	3,150	950	550	200	52
* TPS-10-60	TE-10	3,400	1,000	600	200	52
* TPS-12-5	TE-12	700	460	60	200	67
* TPS-12-10	TE-12	1,000	520	120	200	67
TPS-12-15	TE-12	1,300	580	180	200	67
* TPS-12-20	TE-12	1,600	640	240	200	67
* TPS-12-25	TE-12	1,900	700	300	200	67
TPS-12-30	TE-12	2,200	760	360	200	67
* TPS-12-35	TE-12	2,500	820	420	200	67
* TPS-12-40	TE-12	2,800	880	480	200	67
TPS-12-45	TE-12	3,100	940	540	200	67
* TPS-12-50	TE-12	3,400	1,000	600	200	67
* TPS-12-55	TE-12	3,700	1,060	660	200	67