



# タッチコネクターファイブ

## TOUCH CONNECTOR FIVE

### メイルランティ MALE RUN TEE




| 型式<br>Model        |                    | A    | B    | φC   | 適用<br>チューブ<br>外径<br>Tube O. D.<br>φD | 二面幅<br>Spanner<br>Flats<br>H | L    | ねじサイズ<br>Thread<br>T<br>(おねじ) | チューブ<br>挿入寸法<br>Tube<br>Insertion<br>Depth | 重量<br>Weight<br>(g) |
|--------------------|--------------------|------|------|------|--------------------------------------|------------------------------|------|-------------------------------|--------------------------------------------|---------------------|
| 本体色黒<br>Black body | 本体色白<br>White body |      |      |      |                                      |                              |      |                               |                                            |                     |
| F4-M5RT            | F4-M5RTW           | 14.8 | 19.0 | 10.0 | 4                                    | 10.0                         | 16.0 | M5×0.8                        | 12.0                                       | 7.2                 |
| F4-01RT            | F4-01RTW           | 14.8 | 22.5 | 10.0 | 4                                    | 10.0                         | 18.5 | R1/8                          | 12.0                                       | 10.6                |
| F4-02RT            | F4-02RTW           | 14.8 | 26.5 | 10.0 | 4                                    | 14.0                         | 20.5 | R1/4                          | 12.0                                       | 19.6                |
| F6-M5RT            | F6-M5RTW           | 15.8 | 20.0 | 12.0 | 6                                    | 12.0                         | 17.0 | M5×0.8                        | 12.5                                       | 8.4                 |
| F6-01RT            | F6-01RTW           | 15.8 | 24.5 | 12.0 | 6                                    | 12.0                         | 20.5 | R1/8                          | 12.5                                       | 12.1                |
| F6-02RT            | F6-02RTW           | 15.8 | 27.5 | 12.0 | 6                                    | 14.0                         | 21.5 | R1/4                          | 12.5                                       | 20.5                |
| F6-03RT            | F6-03RTW           | 15.8 | 29.5 | 12.0 | 6                                    | 17.0                         | 23.1 | R3/8                          | 12.5                                       | 31.8                |
| F8-01RT            | F8-01RTW           | 17.8 | 26.5 | 14.0 | 8                                    | 14.0                         | 22.5 | R1/8                          | 13.7                                       | 15.2                |
| F8-02RT            | F8-02RTW           | 17.8 | 29.5 | 14.0 | 8                                    | 14.0                         | 23.5 | R1/4                          | 13.7                                       | 19.7                |
| F8-03RT            | F8-03RTW           | 17.8 | 31.5 | 14.0 | 8                                    | 17.0                         | 25.1 | R3/8                          | 13.7                                       | 34.1                |
| F10-01RT           | F10-01RTW          | 19.8 | 29.5 | 17.0 | 10                                   | 17.0                         | 25.5 | R1/8                          | 14.6                                       | 21.3                |
| F10-02RT           | F10-02RTW          | 19.8 | 32.5 | 17.0 | 10                                   | 17.0                         | 26.5 | R1/4                          | 14.6                                       | 24.6                |
| F10-03RT           | F10-03RTW          | 19.8 | 33.5 | 17.0 | 10                                   | 17.0                         | 27.1 | R3/8                          | 14.6                                       | 30.7                |
| F10-04RT           | F10-04RTW          | 19.8 | 36.5 | 17.0 | 10                                   | 21.0                         | 28.5 | R1/2                          | 14.6                                       | 56.4                |
| F12-02RT           | F12-02RTW          | 22.3 | 35.0 | 20.0 | 12                                   | 19.0                         | 29.0 | R1/4                          | 15.4                                       | 27.0                |
| F12-03RT           | F12-03RTW          | 22.3 | 36.0 | 20.0 | 12                                   | 21.0                         | 29.6 | R3/8                          | 15.4                                       | 33.6                |
| F12-04RT           | F12-04RTW          | 22.3 | 39.0 | 20.0 | 12                                   | 21.0                         | 31.0 | R1/2                          | 15.4                                       | 53.5                |
| F16-03RT           | F16-03RTW          | 31.5 | 45.0 | 25.0 | 16                                   | 24.0                         | 38.6 | R3/8                          | 23.3                                       | 94.0                |
| F16-04RT           | F16-04RTW          | 31.5 | 48.0 | 25.0 | 16                                   | 24.0                         | 40.0 | R1/2                          | 23.3                                       | 101.2               |

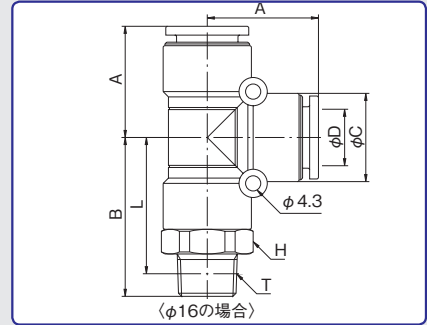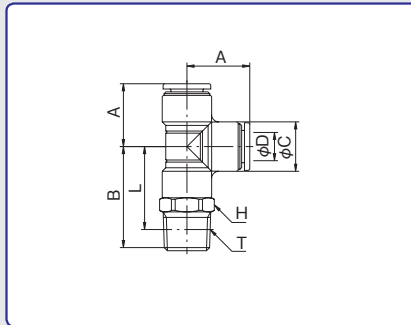

※ φ16にはホールド穴アリ

### メイルブランチワイ MALE BRANCH Y

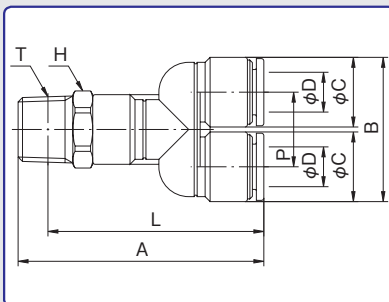

| 型式<br>Model        |                    | A    | B    | φC   | 適用<br>チューブ<br>外径<br>Tube O. D.<br>φD | 二面幅<br>Spanner<br>Flats<br>H | L    | P    | ねじサイズ<br>Thread<br>T<br>(おねじ) | チューブ<br>挿入寸法<br>Tube<br>Insertion<br>Depth | 重量<br>Weight<br>(g) |
|--------------------|--------------------|------|------|------|--------------------------------------|------------------------------|------|------|-------------------------------|--------------------------------------------|---------------------|
| 本体色黒<br>Black body | 本体色白<br>White body |      |      |      |                                      |                              |      |      |                               |                                            |                     |
| F4-M5MY            | F4-M5MYW           | 35.8 | 20.8 | 10.0 | 4                                    | 10.0                         | 32.8 | 10.8 | M5×0.8                        | 12.0                                       | 6.6                 |
| F4-01MY            | F4-01MYW           | 39.3 | 20.8 | 10.0 | 4                                    | 10.0                         | 35.3 | 10.8 | R1/8                          | 12.0                                       | 9.7                 |
| F4-02MY            | F4-02MYW           | 43.3 | 20.8 | 10.0 | 4                                    | 14.0                         | 37.3 | 10.8 | R1/4                          | 12.0                                       | 19.5                |
| F6-M5MY            | F6-M5MYW           | 38.4 | 25.0 | 12.0 | 6                                    | 12.0                         | 35.4 | 13.0 | M5×0.8                        | 12.5                                       | 9.1                 |
| F6-01MY            | F6-01MYW           | 42.9 | 25.0 | 12.0 | 6                                    | 12.0                         | 38.9 | 13.0 | R1/8                          | 12.5                                       | 12.2                |
| F6-02MY            | F6-02MYW           | 45.9 | 25.0 | 12.0 | 6                                    | 14.0                         | 39.9 | 13.0 | R1/4                          | 12.5                                       | 19.8                |
| F6-03MY            | F6-03MYW           | 47.9 | 25.0 | 12.0 | 6                                    | 17.0                         | 41.5 | 13.0 | R3/8                          | 12.5                                       | 33.0                |
| F8-01MY            | F8-01MYW           | 46.4 | 29.0 | 14.0 | 8                                    | 14.0                         | 42.4 | 15.0 | R1/8                          | 13.7                                       | 15.9                |
| F8-02MY            | F8-02MYW           | 49.4 | 29.0 | 14.0 | 8                                    | 14.0                         | 43.4 | 15.0 | R1/4                          | 13.7                                       | 19.8                |
| F8-03MY            | F8-03MYW           | 51.4 | 29.0 | 14.0 | 8                                    | 17.0                         | 45.0 | 15.0 | R3/8                          | 13.7                                       | 32.5                |
| F10-01MY           | F10-01MYW          | 52.7 | 35.0 | 17.0 | 10                                   | 17.0                         | 48.7 | 18.0 | R1/8                          | 14.6                                       | 25.4                |
| F10-02MY           | F10-02MYW          | 55.7 | 35.0 | 17.0 | 10                                   | 17.0                         | 49.7 | 18.0 | R1/4                          | 14.6                                       | 28.5                |
| F10-03MY           | F10-03MYW          | 56.7 | 35.0 | 17.0 | 10                                   | 17.0                         | 50.3 | 18.0 | R3/8                          | 14.6                                       | 34.5                |
| F10-04MY           | F10-04MYW          | 59.7 | 35.0 | 17.0 | 10                                   | 21.0                         | 51.7 | 18.0 | R1/2                          | 14.6                                       | 57.0                |
| F12-02MY           | F12-02MYW          | 59.3 | 41.0 | 20.0 | 12                                   | 19.0                         | 53.3 | 21.0 | R1/4                          | 15.4                                       | 39.4                |
| F12-03MY           | F12-03MYW          | 60.3 | 41.0 | 20.0 | 12                                   | 21.0                         | 53.9 | 21.0 | R3/8                          | 15.4                                       | 43.8                |
| F12-04MY           | F12-04MYW          | 63.3 | 41.0 | 20.0 | 12                                   | 21.0                         | 55.3 | 21.0 | R1/2                          | 15.4                                       | 58.0                |

※上記に表示されていない単位は全てmm