

▶ Socket Connector

FRC5-A026-3T0S-FA

Cover Style
 0 : Open-end
 A : Closed-end

Note) Closed-end cover for 64 contacts are not available

Number of Contact
 10, 14, 16, 20, 26,
 30, 34, 40, 50, 60, 64


Contact Plating
 1 : Au (0.8 μ m) over Ni Plating
 3 : Au (Flash) over Ni Plating

Plating (Termination Area)
 T : Sn-Ag Plating







FA : Lead Free

Strain Relief
 N : without Strain Relief
 S : with Strain Relief

Polarizing Key
 0 : 10 ······ No Key
 14, 16, 20, 26, 30, 34, 40 ······ 1 Key
 50, 60, 64 ······ 2 Keys (H=22.86mm)
 A : 50, 60, 64 ······ 1 Key
 C : 60, 64 ······ 2 Keys (H=27.94mm)
 D : 10 ······ 1 Key

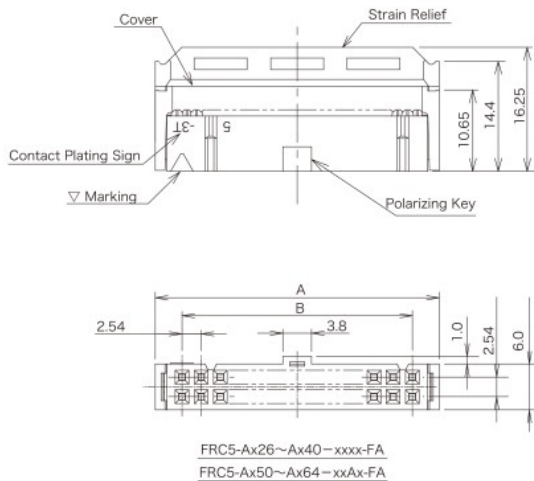

Part Number	Number of Contact	A	B
FRC5-AX10-XXXX-FA	10	17.27	10.16
FRC5-AX14-XXXX-FA	14	22.35	15.24
FRC5-AX16-XXXX-FA	16	24.89	17.78
FRC5-AX20-XXXX-FA	20	29.97	22.86
FRC5-AX26-XXXX-FA	26	37.59	30.48
FRC5-AX30-XXXX-FA	30	42.67	35.56
FRC5-AX34-XXXX-FA	34	47.75	40.64
FRC5-AX40-XXXX-FA	40	55.37	48.26
FRC5-AX50-XXXX-FA	50	68.07	60.96
FRC5-AX60-XXXX-FA	60	80.77	73.66
FRC5-AX64-XXXX-FA	64	85.85	78.74

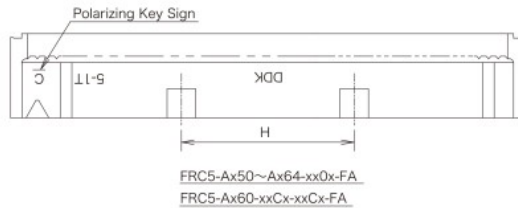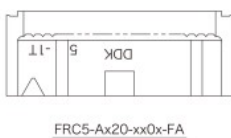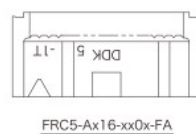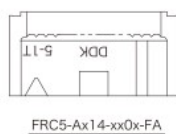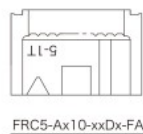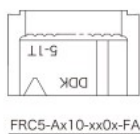

© Specifications and/or dimensions in this catalogue are subject to change without notice.
 Your catalogue checking the latest specifications with our drawings would be highly appreciated.