
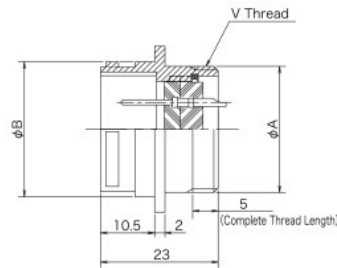


▶ WEBR (Box Receptacle)

WEBR2524M □ GS -D(R1)  
 ① ② ③ ④ ⑤ ⑥ ⑦ ⑧

WEBR2524M □ G -D  
 ① ② ③ ④ ⑤ ⑥ ⑧

① Connector Style	R : Box Receptacle
② Shell Size	13, 16, 21 and 25
③ Number of Contacts	03, 04, 05, 07, 10, 16, 19, 24, 28 and 32
④ Contact Style	M : Male Contact(Pin) F : Female Contact(Socket)
⑤ Alternate Insert Position	Omit : Standard Position X, Y, Z : Alternate Insert Position
⑥ Contact Plating	Omit : Silver Plating (Standard) G : Gold Plating
⑦ Flange Gasket	Omit : Less Gasket S : With Gasket (R and WR Only)
⑧ Finish	D : Trivalent Chromium Treatment (Black)

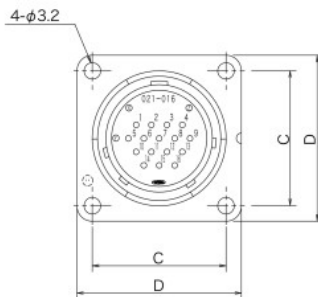

Shell Size	Number of Contacts	Part Number	φ A	φ B	C	D	V
13	3	WEBR1303 □□□□-D	16	18	20	26	M16
	5	WEBR1305 □□□□-D	16	18	20	26	M16
	7	WEBR1307 □□□□-D	16	18	20	26	M16
16	7	WEBR1607 □□□□-D	20	22	23	29	M20
	10	WEBR1610 □□□□-D	20	22	23	29	M20
21	4	WEBR2104 □□□□-D	24	26	26	32	M24
	7	WEBR2107 □□□□-D	24	26	26	32	M24
	10	WEBR2110 □□□□-D	24	26	26	32	M24
	16	WEBR2116 □□□□-D	24	26	26	32	M24
	19	WEBR2119 □□□□-D	24	26	26	32	M24
25	16	WEBR2516 □□□□-D	28	30	29	35	M28
	24	WEBR2524 □□□□-D	28	30	29	35	M28
	28	WEBR2528 □□□□-D	28	30	29	35	M28
	32	WEBR2532 □□□□-D	28	30	29	35	M28

© Specifications and/or dimensions in this catalog are subject to change without notice. © Your checking the latest specifications with our drawings would be highly appreciated.