

## PZ-32



## SCREW REMOVAL PLIERS JS


- Vertical serrations bite and grip a screw head without slippage
- Also good for Truss head screw. \*Truss: Lower-profile dome head
- Serrated side teeth lined consecutively, inter-meshed with each other
- Black oxide finish to increase rust-resistance!
- Owing to T-shaped forging handles, the handle sleeve will not twist or slip off during heavy duty use.



## PZM-30



## PLIERS MASK FOR PZ-32

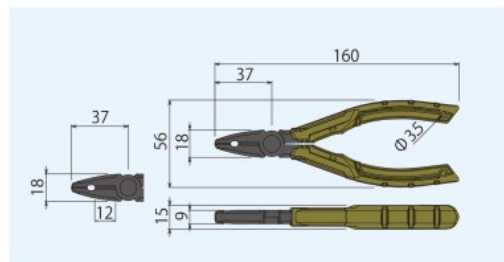

Item No.	Size	Material	Hardness	Cutting Capacity	Wgt.	Safety Hole
PZ-32	160mm	Body:Carbon Steel Handles:TPR	HRC60±2	φ3.2mm (copper wire)	125g	φ3.5mm

Inter-meshed,  
never let go.



Strap hole goes through  
the steel handle.



## ■ Screw head size

Top Jaws


φ3~φ9.5mm

## PZ-64•65•66



## SCREW REMOVAL LOCKING PLIERS


- Vertically serrated jaws bite a screw head while locking it securely.  
It helps to optimize your hand strength for twisting off stubborn screws.
- Also good for Truss head screw. \*Truss: Lower-profile dome head
- Quick release mechanism, just open the handles to unlock the gripping jaws
- Rubber handles provide you with a comfortable grip.

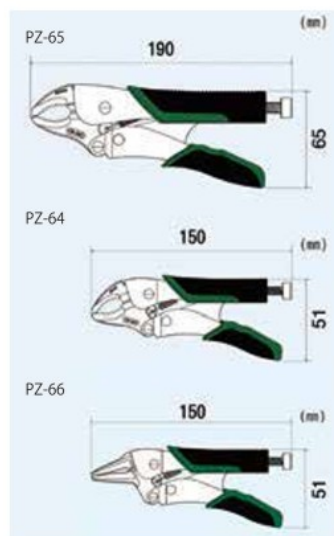

PZ-65



PZ-64

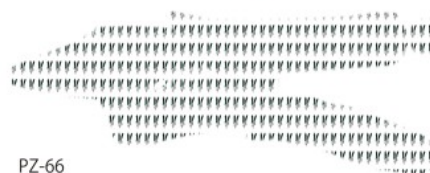

PZ-66

## PRODUCT VIDEO



Item No.	Max.Jaws	Holdable Round Bar	O.A. Length	Hardness (Jaws)	Wgt.	Material
PZ-64	38mm	Max. φ28mm	150mm	HRC57±3	205g	Body:Cr-Mo Handles:TPR
PZ-65	48mm	Max. φ40mm	190mm		400g	
PZ-66		Max. φ8mm	150mm		210g	

## ■ Screw head size

Item No.	Top Jaws
PZ-64	φ3~φ9.5mm
PZ-65	φ3~φ9.5mm
PZ-66	φ3~φ5.5mm