


PL-05·06  **LONG FLAT NOSE PLIERS**

Thin and flat edge for efficient work

- Jaws without serration
- Long-life box joint structure to avoid loosening
- Material: Stainless steel



PL-06

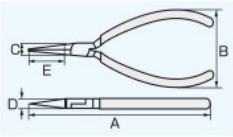


Item No.	SIZE	A	B	C	D	E
PL-05	125	143	50	11	7	40
PL-06	150	164	53	15	10	43

PM-06  **ROUND NOSE PLIERS**

Ideal for looping & coiling of steel wires

- Material: SCM440H

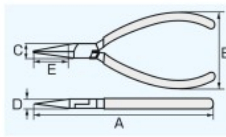


SIZE	A	B	C	D	E
150	145	53	15	8	35

PR-15·16  **LONG NOSE PLIERS**

General purpose pliers 

- Material: S58C
- Hardness: HRC 58±4

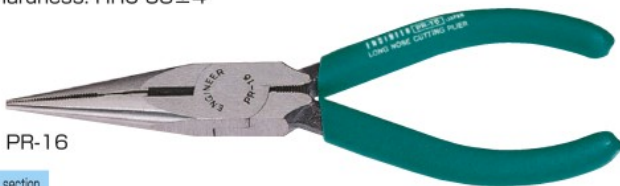

PR-16



Item No.	SIZE	A	B	C	D	E	Capacity
PR-15	125	142	51	17	10	43	Copper wire φ2.0mm
PR-16	150	160	55	17	10	49	Copper wire φ2.6mm

PR-26  **LONG NOSE PLIERS**


Professional type pliers 

- Material: S58C
- Hardness: HRC 58±4
- Capacity: copper wire φ2.6mm




SIZE	A	B	C	D	E
150	160	52	17	10	50

PR-36  **LONG NOSE PLIERS**

Multipurpose pliers with gripping jaws, cutter & wire stripper 

- Stripping Hole: φ1.2mm
- Material: S58C
- Hardness: HRC 58±4
- Capacity: copper wire φ2.6mm

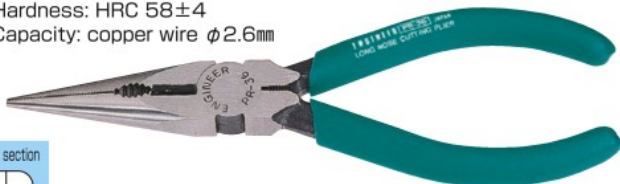


SIZE	A	B	C	D	E
150	160	51	17	10	50

PR-46  **NEEDLE NOSE PLIERS**

50mm-long slender nose ideal for work in deep area

- Material: S58C
- Hardness: HRC 58±4
- Capacity: copper wire φ2.6mm

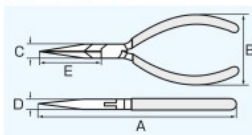

SIZE	A	B	C	D	E
160	160	51	13	8	50

PD SERIES

Features ● Durably constructed Electrician's Pliers

PD-06~08

 **SIDE CUTTING PLIERS**



PD-06




PD-07



Heavy duty professional-use pliers

- Material: S58C
- Hardness: HRC 60±4

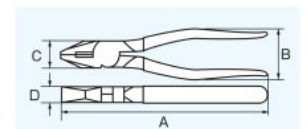

Item No.	Size	A	B	C	D	Capacity
PD-06	150	165	50	22	12	steel wire φ1.6
PD-07	175	185	52	24	13	steel wire φ1.8
PD-08	200	210	53	27	14	steel wire φ2.0