


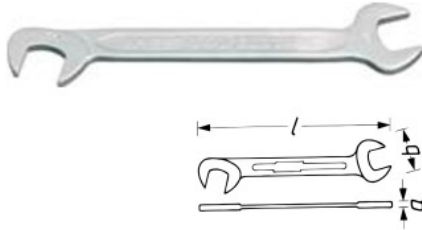

440 Double open-end wrench

Made in Germany

- Forged design
- Same wrench sizes
- Short, thin style
- Head set at: 15° x 75°
- Surface: chrome-plated



HAZET No.	l mm	a mm	b mm	EAN-No. 4000896+
440- 3.2	70	2	10.5	020119
440- 3.5	70	2	10.5	020126
440- 4	70	2	10.5	020133
440- 4.5	70	2	10.5	020140
440- 5	78	2	12.6	020157
440- 5.5	78	2	12.6	020164
440- 6	78	2	12.6	020171
440- 7	91	2	14.7	020188
440- 8	96	3	16.8	020195
440-10	105	3	21	020065
440-11	116	3	24.2	020072
440-12	116	3	24.2	020089
440-13	131	3	28.3	020096
440-14	131	3	28.3	020102

440 Double open-end wrench set

Made in Germany

- Plastic roll



440 • ●


3.2 • 3.5 • 4 • 4.5 • 5 • 5.5 • 6 • 7 • 8 • 10 • 11 • 12 • 13 • 14

HAZET No.	Quantity	EAN-No. 4000896+
440/14P	14	178759

279 Open-end wrench · adjustable

Adjustable wrench

- With scale
- Head set at: 15°
- Surface: phosphatised, mirror, highly polished, blank

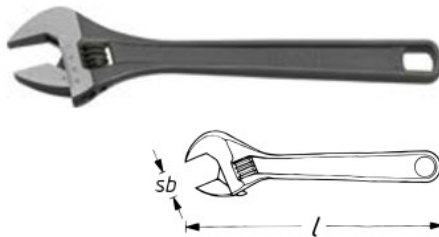


HAZET No.	l mm	sb mm	EAN-No. 4000896+
279- 4	108	17	018086
279- 6	157	24	018093
279- 8	206	29	018109
279-10	256	33	018048
279-12	306	38	018055
279-15	383	51	018062
279-18	461	60	018079

600 N Combination wrench

Made in Germany

- Long, slim design
- Slim heads
- Shank with sturdy HAZET double-T-profile
- Box-end head angled at 15°
- Surface: chrome-plated, head polished
- DIN 3113 form A, ISO 3318, ISO 7738

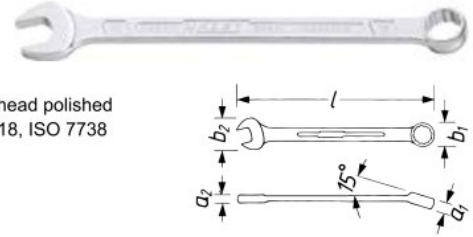

¹⁾ Not according to DIN

HAZET No.	l mm	a ₁ mm	a ₂ mm	b ₁ mm	b ₂ mm	EAN-No. 4000896+
600 N- 5.5 ¹⁾	105	6	4	9.6	15.5	023288
600 N- 6	105	6	4	9.6	15.5	023295
600 N- 7	118.5	6.6	4	10.9	17.5	023301
600 N- 8	130	7	4.5	12	18.5	023318
600 N- 9	143	8	4.5	13.7	21	023325
600 N-10	154.5	8	5	15	23	023028
600 N-11	168.5	8.4	5.5	15.9	25.5	023035
600 N-12	180.5	9	5.5	17.8	27.5	023042
600 N-13	193	10	6.3	19	29	023059
600 N-14	204.5	10	6.5	20.1	31	023073
600 N-15	218	11	7	21.4	32.5	023080
600 N-16	230.5	11.4	7	23.1	35	023097
600 N-17	242.5	12.4	7.5	24.5	37	023103
600 N-18	255	13	8	26	39	023110
600 N-19	268.5	13.5	8	27.5	41	023127
600 N-20 ¹⁾	279.5	13.5	8.5	29	43	023134
600 N-21	292	13.7	8.5	30	45	023141
600 N-22	304.5	14	8.5	31.5	47	023158
600 N-23 ¹⁾	328	14.3	9.5	33	49	023165
600 N-24	328	14.7	9.5	34.5	51	023172
600 N-25 ¹⁾	354	15	10	36	53.5	023189
600 N-26 ¹⁾	354	15.5	10	37.5	55	023196
600 N-27	380	16	10.5	39	57	023202
600 N-28 ¹⁾	380	16.5	11	40.5	59	023219
600 N-29 ¹⁾	380	17	11.5	41.5	60	023226
600 N-30	405.5	17.5	12.2	43	63	023233
600 N-32	420	18	12	45.5	66.5	023240
600 N-34	432	19	13	48.5	67	023257
600 N-36	460	20	13	51.8	75	023264
600 N-41	500	20.6	14	58.8	85	023271

¹⁾ Not according to DIN

HAZET No.	l mm	a ₁ mm	a ₂ mm	b ₁ mm	b ₂ mm	EAN-No. 4000896+
• Box-end head 10° offset						
• DIN 3113 form B, ISO 3318, ISO 7738						
600 N-46	520	24	15	69	95	048564
600 N-50	560	26	16.5	75	103	048571
600 N-55	610	28	18	84.5	113	048588
600 N-60	660	31	20	90	123	048595
600 N-65 ¹⁾	710	33	22	98	133	048601
600 N-70 ¹⁾	760	35	24	105	143	048618
600 N-75 ¹⁾	810	38	26	110	153	048625
600 N-80 ¹⁾	860	41	28	119	163	048632

