



Hand tools

Wrenches



610 N Double box-end wrench set

Made in Germany

- Surface: chrome-plated, head polished
- DIN 837 form B, ISO 10103



HAZET No.		EAN-No. 4000896+
610 N •		
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 21x22		
610 N/8	8	024995

Made in Germany

- Suitable for wall fixation
- Plastic tool holder
- Surface: chrome-plated, head polished
- DIN 837 form B, ISO 10103




HAZET No.	L x W x H mm		EAN-No. 4000896+
610 N •			
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 21x22			
610 N/8 RS	260x110x55	8	025008
• With carrying handle			
610 N •			
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 20x22 • 21x23 • 24x26 • 25x28 • 27x32			
610 N/12 RS	340x165x75	12	024988

630 Double box-end wrench

Made in Germany

- Deep offset
- Heads thin-walled
- Surface: chrome-plated, head polished
- DIN 838, ISO 10104

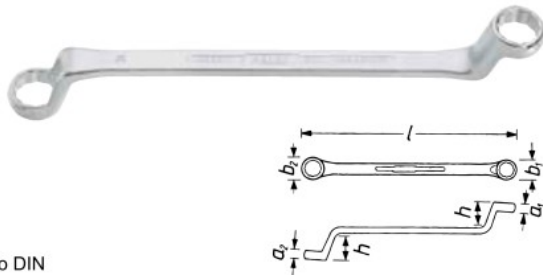

¹⁾ Not according to DIN

²⁾ Matt chrome-plated

HAZET No.	l mm	h mm	a ₁ mm	a ₂ mm	b ₁ mm	b ₂ mm	EAN-No. 4000896+
630- 6 x 7	165	18	6	6.5	10.5	12.2	026555
630- 8 x 9	180	20.5	7	7.5	13.1	14.6	026579
630-10 x 11	200	23.5	8	9	15.6	17.1	026227
630-12 x 13	220	25	9	9.5	18.4	19.9	026241
630-14 x 15	240	27	10	10.5	21.4	22.5	026296
630-16 x 17	255	29	11	11.3	24	25.5	026302
630-17 x 19	265	29	11.3	11.9	25.5	28.4	026326

630 Double box-end wrench

HAZET No.	l mm	h mm	a ₁ mm	a ₂ mm	b ₁ mm	b ₂ mm	EAN-No. 4000896+
630-18 x 19	265	31	11.6	11.9	26.9	28.4	026333
630-20 x 22 ¹⁾	295	32.5	12.2	12.9	29.3	32.2	026364
630-21 x 22	295	32.5	12.9	12.9	30.7	32.2	026371
630-21 x 23 ¹⁾	315	34	12.5	13.2	30.7	33.6	026388
630-24 x 26 ¹⁾	330	34	13.5	14.1	35.1	37.1	026401
630-24 x 27	340	35	13.5	14.4	35.1	38.5	026418
630-25 x 28 ¹⁾	350	35	13.8	14.7	36.5	39.9	026432
630-27 x 32	365	36.5	14.4	16	38.5	45.5	026463
630-30 x 32	365	36.5	15.4	16	42.7	45.5	026470
630-36 x 41 ²⁾	440	40	17.2	18.8	51.3	58.2	026517

630 Double box-end wrench set

Made in Germany

- Safety-Insert-System, 2-component soft foam insert. Insert also suitable for HAZET Assistant
- DIN 838, ISO 10104



HAZET No.	L x W mm		EAN-No. 4000896+
1/3+			

HAZET No.	L x W mm		EAN-No. 4000896+
Suitable for HAZET Assistant with a drawer depth of 398 mm: 173 · 179 · 179 N(X) · 179 W · 179 N W · 179 BIG-1 · 179 XL · 179 N XL · 179 XXL · 179 N XXL · 179 A XXL · 179 T XXL · 180			
630 •			
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 20x22 • 21x23			
163-518/9	392x172	9	218707

Made in Germany

- Surface: chrome-plated, head polished
- DIN 838, ISO 10104



HAZET No.		EAN-No. 4000896+
630 •		
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 21x22		
630/8	8	026654
630 •		
6x7 • 8x9 • 10x11 • 12x13 • 14x15 • 16x17 • 18x19 • 20x22 • 21x23 • 24x26 • 25x28 • 27x32		
630/12	12	026593